


12.5mm Dia., 1.1mm Thick, Uncoated, Dragontrail™ Chemically Strengthened Window

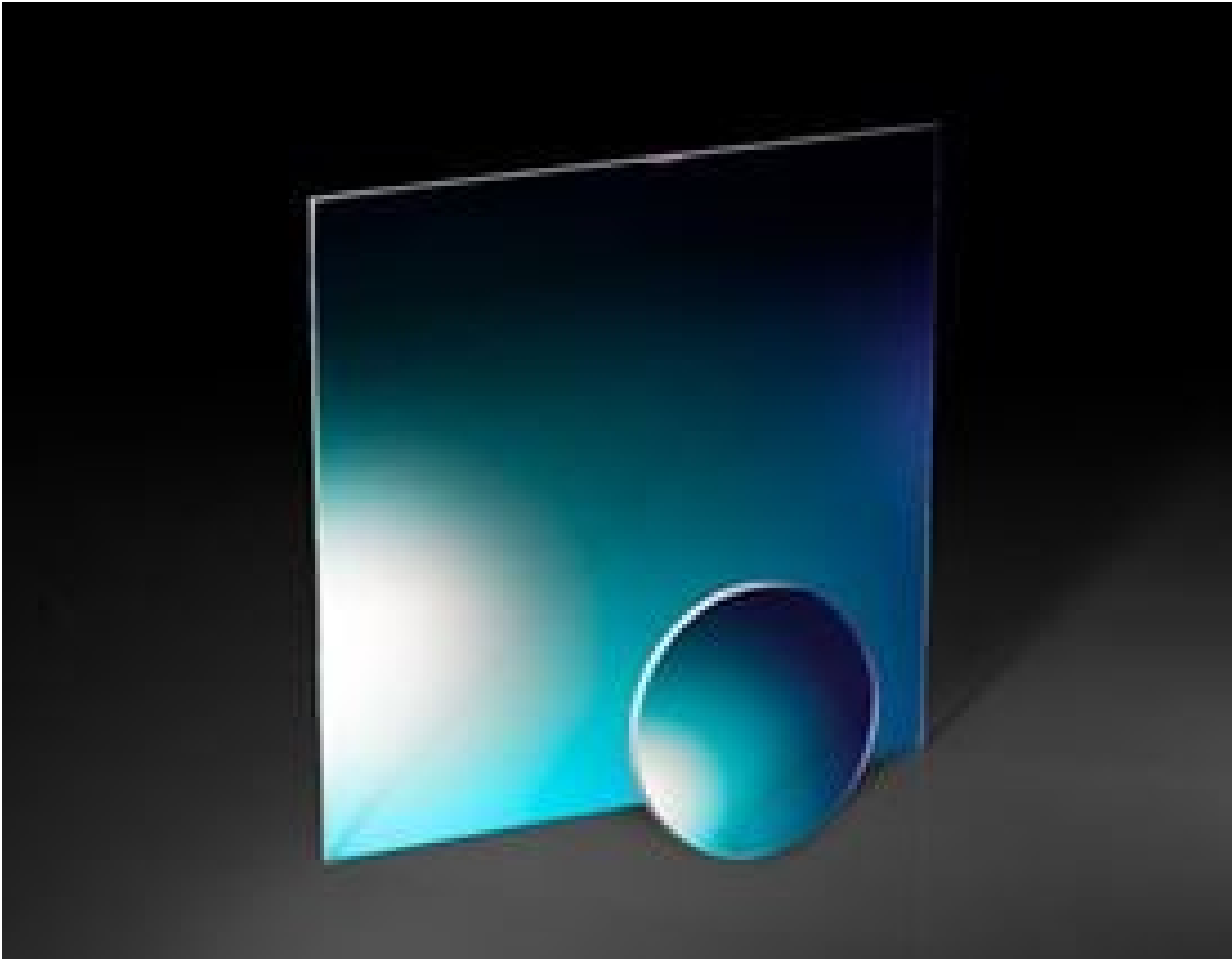

Stock **#17-256** [CONTACT US](#)

- 1 + **£16.15**

ADD TO CART

Qty 1-5
£16.15

Qty 6+
£12.96

Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Bevel:
Protective as needed

Chemical Strengthening Cycle (hours):
20

Clear Aperture (%):
90

Clear Aperture CA (mm):

11.25
Diameter (mm): 12.50 ±0.127
Thickness (mm): 1.10 Nominal
Coating: Uncoated
Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 9.8
Density (g/cm³): 2.48
Edges: Fine Ground
Index of Refraction n_d: 1.51
Poisson's Ratio: 0.23
Substrate: Dragontrail™
Surface Quality: 80-50
Type: Protective Window
Wavelength Range (nm): 350 - 2000
Young's Modulus (GPa): 74

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant