


TECHSPEC®

125mm, Side Drive, Thru-Hole, Metric Stage

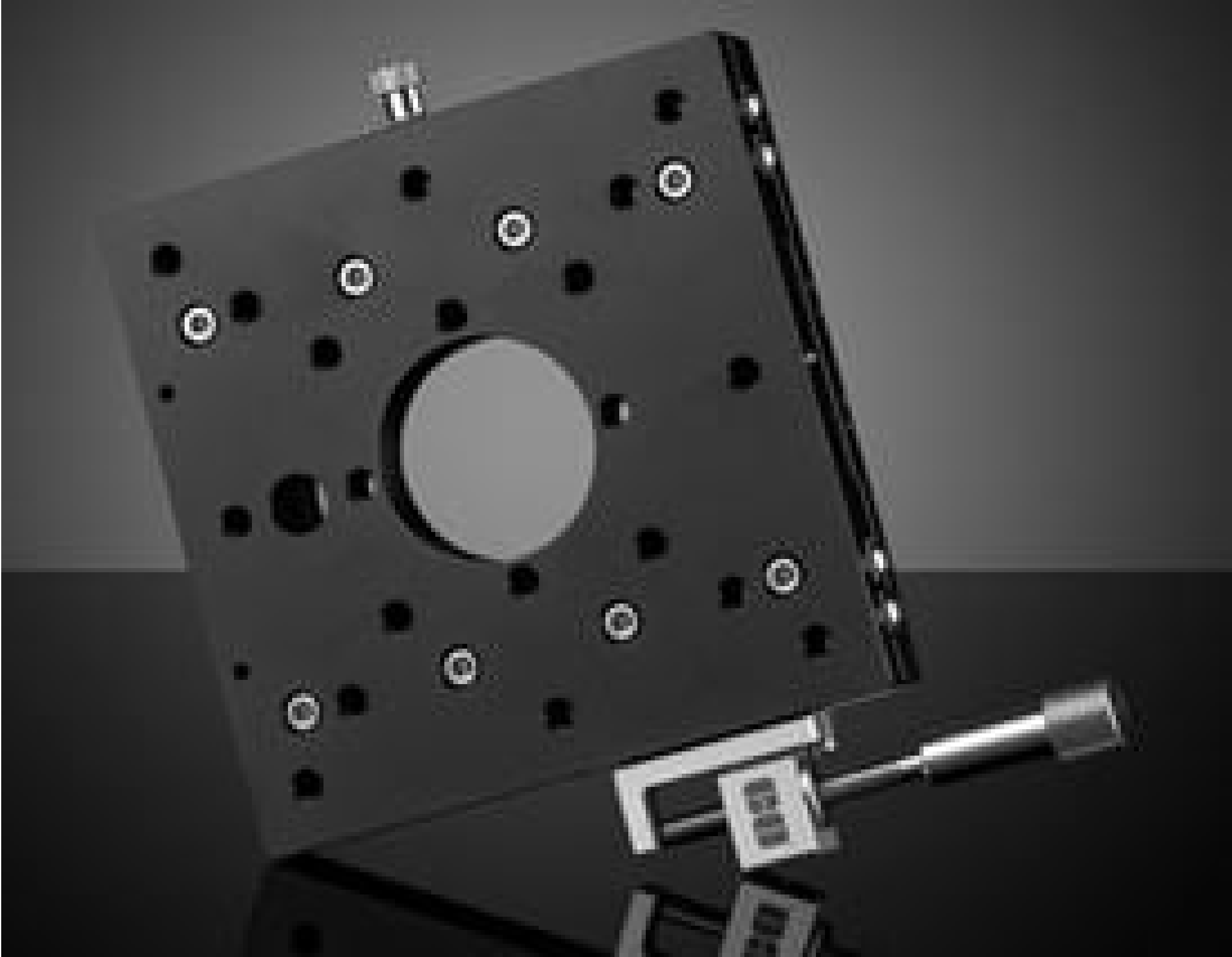

Stock #66-471 3-4 DAYS

-

1

+

£499.80

ADD TO CART

Qty 1-2
£499.80
Qty 3+
£435.96
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Type of Movement:
Linear (X)

Guide System:
Crossed Roller Bearing

Type of Drive:
Lead Screw

Drive Orientation:

Side Drive
Type: Metric
Stage Size (mm): 125 x 125
Travel (mm): 25
Center Hole: M42 x 0.75
Construction: Aluminium Stage
Leadscrew Pitch (mm): 0.5
Load Capacity (kg): 20
Mounting Threads: (1) M42 x 0.75, (20) M6 x 1
Stage Size (inches): 4.92 x 4.92
Straight Line Accuracy (µm): 2
Pitch (arcsec): 30
Yaw (arcsec): 25

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant
