 



25 x 25mm, 0.5mm Spacing, Glass Distortion Target

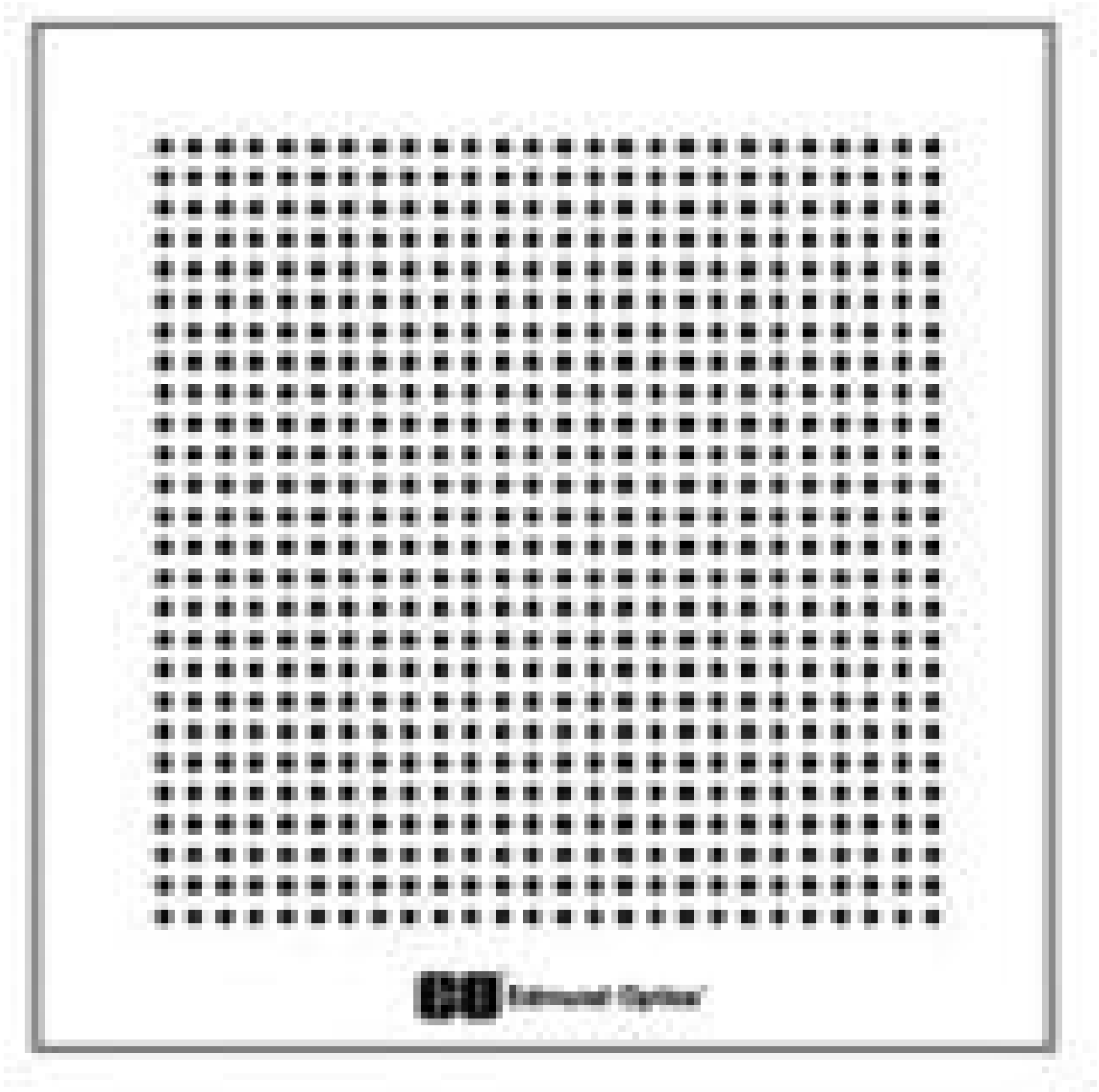

Stock #57-981 ☐ In Stock

-

1

+

£487.05

ADD TO CART

Qty 1-4

£487.05

Qty 5+

£462.82

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Coating:
Reflective First Surface Chromium
R_{abs} = 50% ±5% @ 550nm

Dot Diameter (mm):
0.250

Dot Spacing (mm): 0.500
Substrate: Soda Lime Float Glass
Optical Density OD (Average): >3.0
Overall Accuracy (mm): ±0.002
Pattern Size (mm): 25 x 25
Dimensions (inches): 2 x 2
Surface Quality: 40-20
Thickness (mm): 1.50
Type: Chrome on Glass
Dot Diameter Tolerance (mm): ± 0.002
Dot Spacing Tolerance (mm): ± 0.002 Center to Center
NIST Certification: Serialized NIST Traceable Certificate Included
Flatness (inches): 0.001

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View