


300mm, 1mm steps, Machine Vision Micrometer

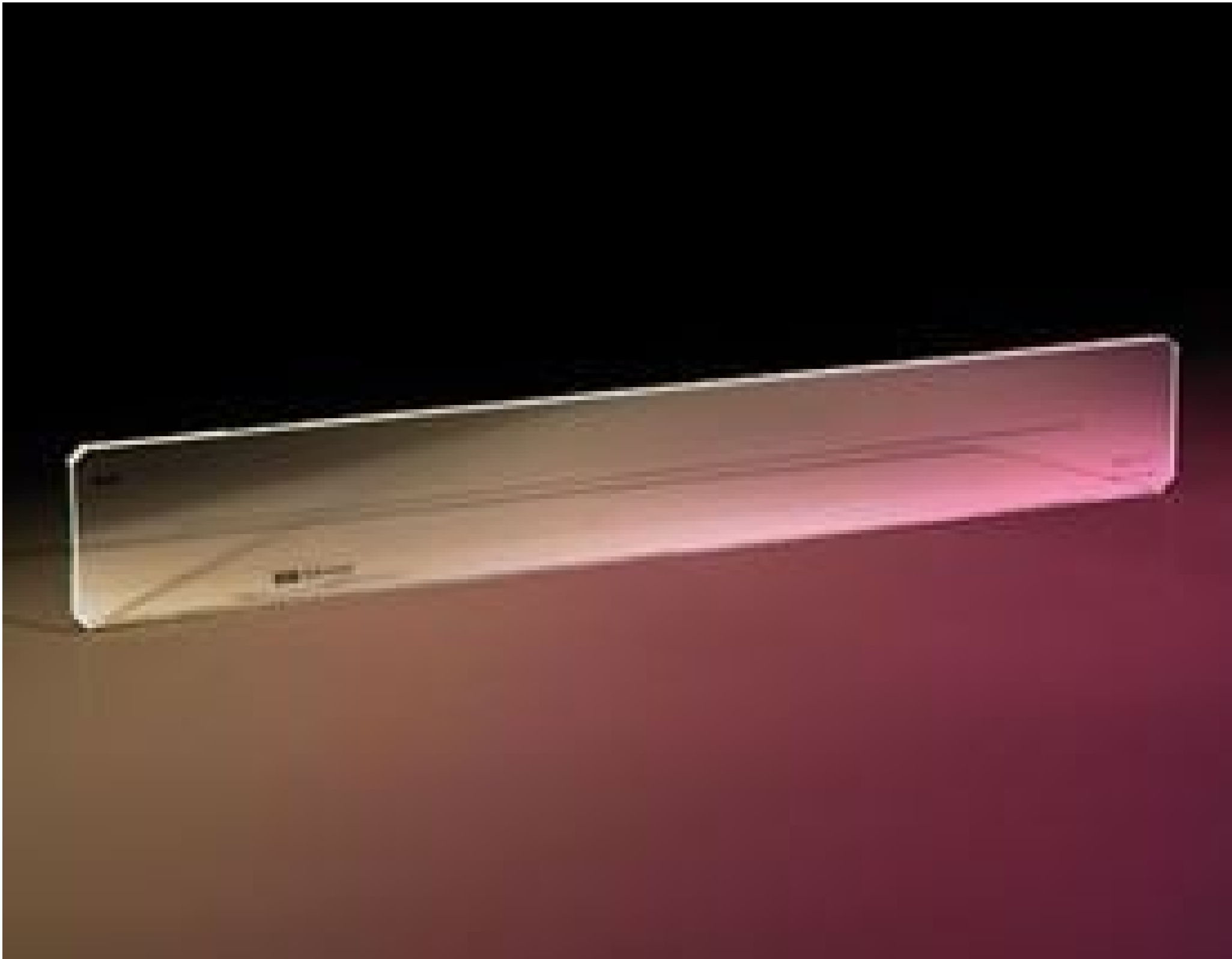

EO Machine Vision Stage Micrometer

Stock **#58-292** [CONTACT US](#)



1



£997.05

ADD TO CART

Qty 1-4

£997.05

Qty 5+

£947.67

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Coating:
First Surface Reflective Chromium, OD > 3.0
Reflectivity = 50% ±5% @ 550nm

Number of Divisions:
300.00

Substrate:
Float Glass

Line Width (mm): 0.125
Increments: 1mm
Scale Length (mm): 300.00
Dimensions (mm): 50.8 W x 338.1 L x 6.35 T
Surface Quality: 40-20 Over Pattern Area
Dimensional Tolerance (mm): ±1.27
Line Width Tolerance (mm): ±0.003
Accuracy (mm): ±0.003 up to 125mm; ±0.005 up to 300mm

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View
