


TECHSPEC[®] 30mm, Center Drive, Standard Top, 0.5" Travel, Metric Stage

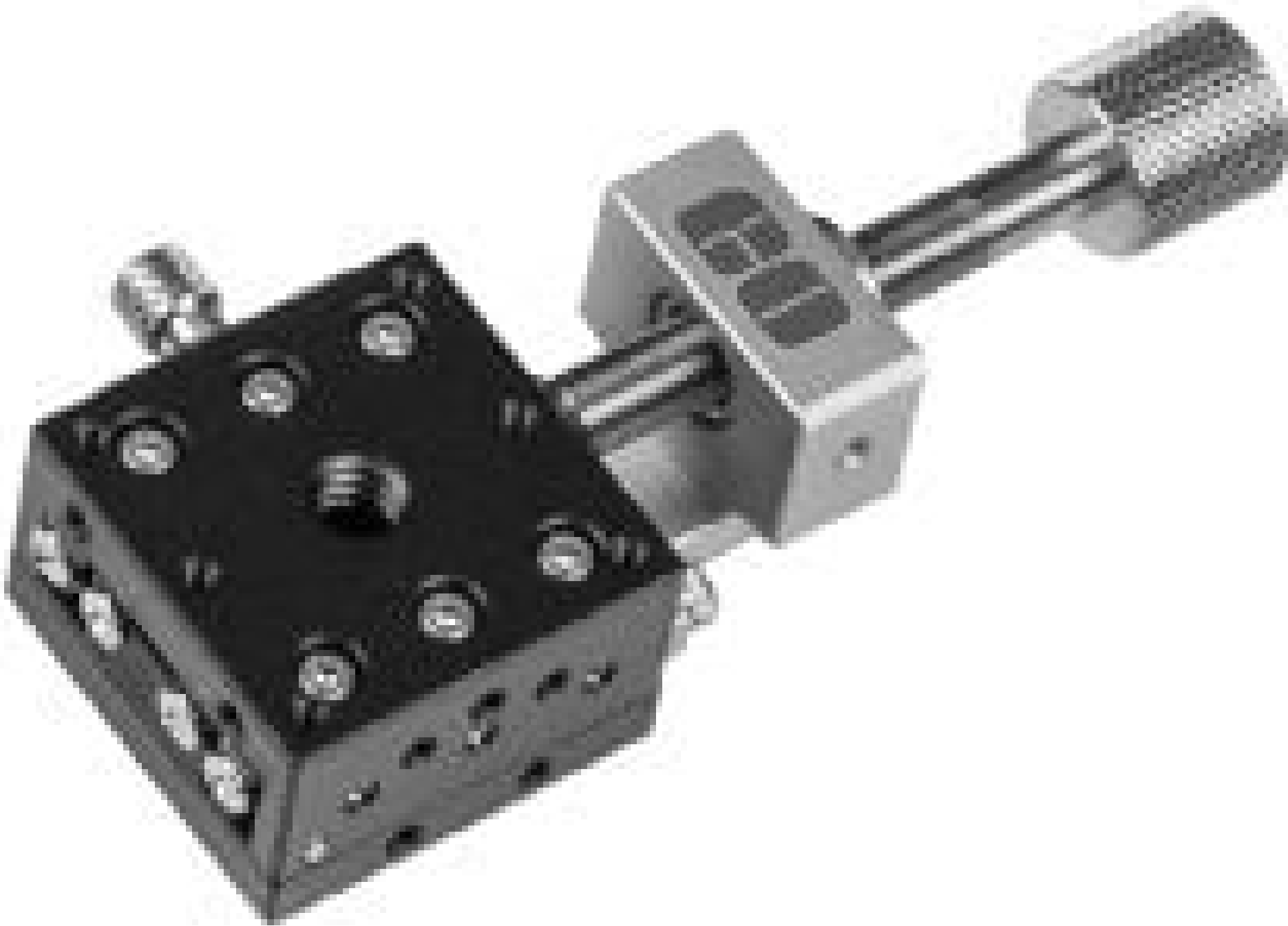

30mm, Center Drive, Solid Top, 0.5" Travel Stage

Stock #66-390 3-4 DAYS



1



£251.60

ADD TO CART

Qty 1-2

£251.60

Qty 3+

£219.98

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Type of Movement:
Linear (X)

Guide System:
Crossed Roller Bearing

Type of Drive:
Lead Screw

Drive Orientation: Center Drive
Type: Metric
Stage Size (mm): 30 x 30
Travel (mm): 13
Center Hole: M6 x 1
Construction: Aluminium Stage
Leadscrew Pitch (mm): 0.5
Load Capacity (kg): 3
Mounting Threads: (1) M6 x 1, (6) M2 x 0.4
Stage Size (inches): 1.18 x 1.18
Straight Line Accuracy (µm): 2
Pitch (arcsec): 30
Yaw (arcsec): 25

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant