


TECHSPEC[®] 40mm, Center Drive, Thru-Hole, English Extended Micrometer

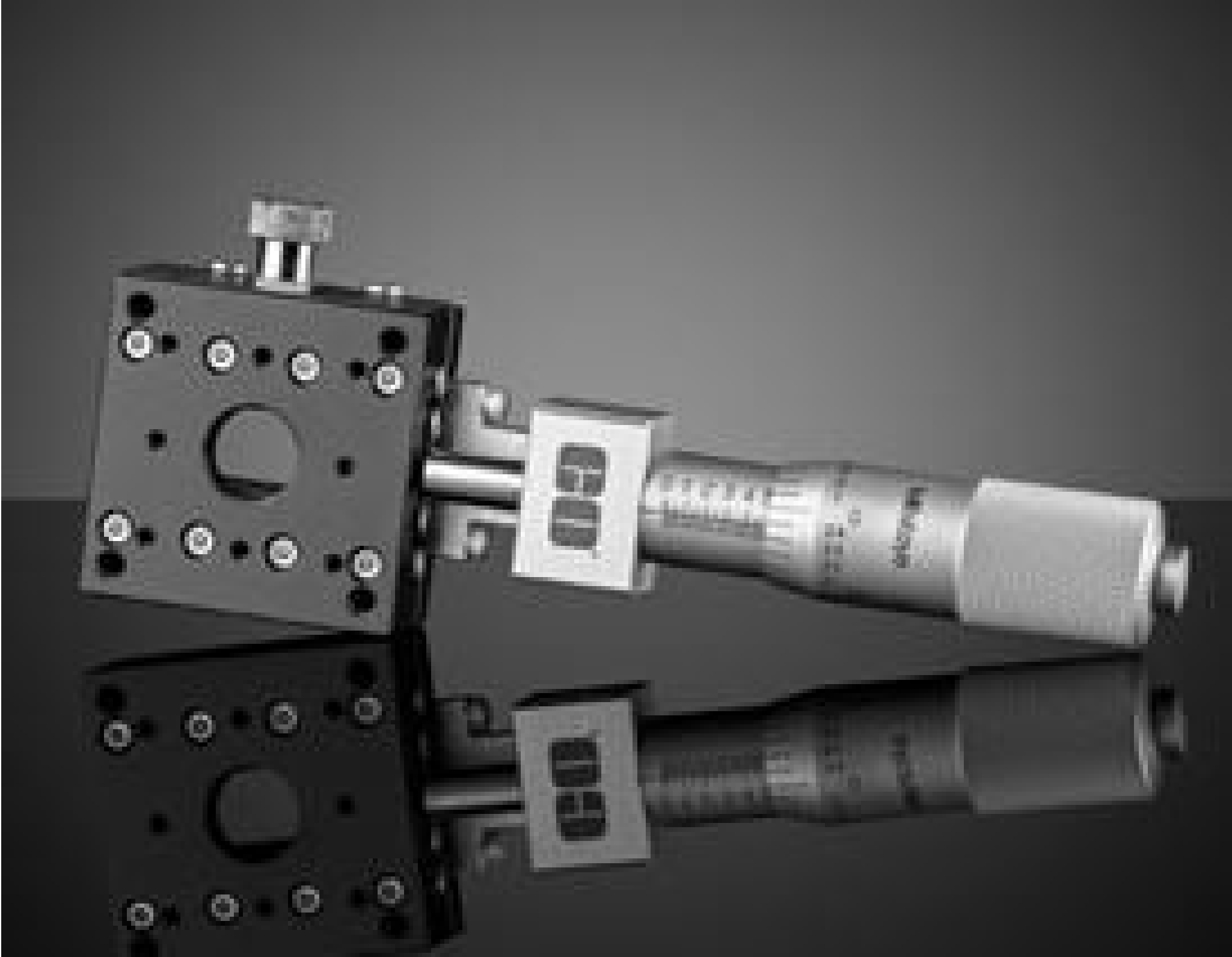

40mm, S-Mount (M12 x 0.5) Thread Centered, Micrometer Drive Stage (Center Drive)

Stock #66-416 3-4 DAYS



1



£353.60

ADD TO CART

Qty 1-2

£353.60

Qty 3+

£308.29

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Type of Movement:
Linear (X)

Guide System:
Crossed Roller Bearing

Type of Drive:
English Micrometer

Drive Orientation: Center Drive
Type: English
Stage Size (mm): 40 x 40
Travel (inches): 1
Center Hole: M12 x 0.5
Construction: Aluminium Stage
Leadscrew Pitch (mm): 0.635
Load Capacity (kg): 4
Mounting Threads: (1) M12 x 0.5, (4) 6-32, (8) 2-56
Stage Size (inches): 1.57 x 1.57
Straight Line Accuracy (µm): 2
Pitch (arcsec): 30
Yaw (arcsec): 25

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 233: Contains SVHC(s)