


TECHSPEC® 50 x 50mm Protected Gold, λ/20 Mirror

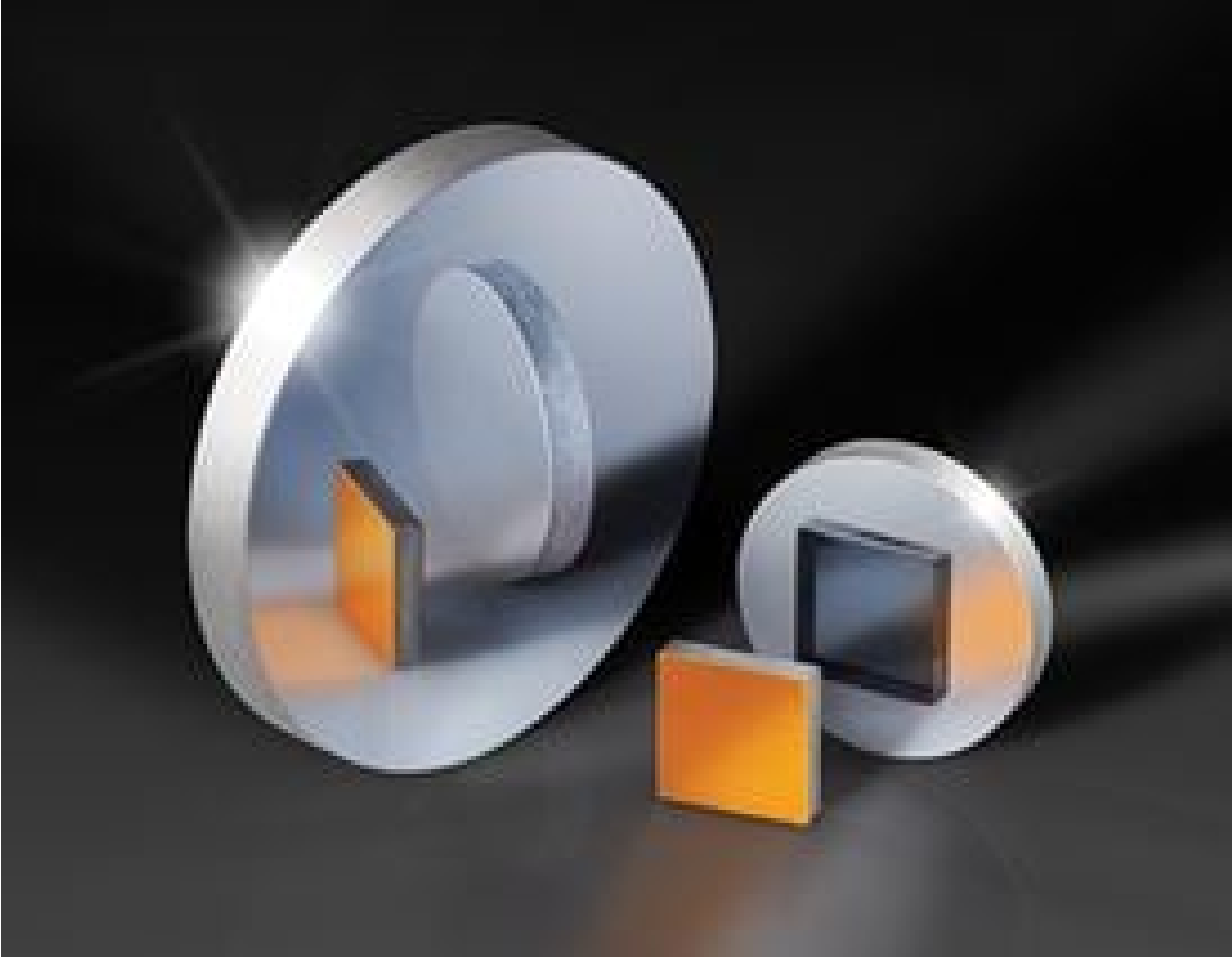

Stock #34-383 3-4 DAYS

-

1

+

£283.90

ADD TO CART

|                               |
|-------------------------------|
| Qty 1-5                       |
| £283.90                       |
| Qty 6+                        |
| £226.95                       |
| Volume Pricing                |
| <a href="#">Request Quote</a> |

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Flatness (P-V):  
λ/20 (flatness pre-coating)

Substrate: [Fused Silica](#) (Corning 7980)

Back Surface:  
Commercial Polish

|                                                                                                                  |
|------------------------------------------------------------------------------------------------------------------|
| <b>Surface Quality:</b><br>20-10                                                                                 |
| <b>Dimensions (mm):</b><br>50.0 x 50.0 +0.00/-0.20                                                               |
| <b>Coating Specification:</b><br>R <sub>avg</sub> >96% @ 700 - 2000nm<br>R <sub>avg</sub> >96% @ 2000 - 10,000nm |
| <b>Coating:</b><br>Protected Gold (700-10000nm)                                                                  |
| <b>Coating Type:</b><br>Metal                                                                                    |
| <b>Clear Aperture (%):</b><br>90.00                                                                              |
| <b>Edges:</b><br>Ground, protective bevel as needed                                                              |
| <b>Parallelism (arcsec):</b><br>30.00                                                                            |
| <b>Thickness (mm):</b><br>5.00                                                                                   |
| <b>Type:</b><br>Flat Mirror                                                                                      |
| <b>Wavelength Range (nm):</b><br>700 - 10000                                                                     |
| <b>Length (mm):</b><br>50.00                                                                                     |
| <b>Width (mm):</b><br>50.00                                                                                      |

Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |
| <b>Reach 235:</b><br><a href="#">Compliant</a>             |