 



SCHOTT BG42, 50mm Sq., 3mm Thick, Colored Glass Bandpass Filter

See More by [SCHOTT Optical Components](#)

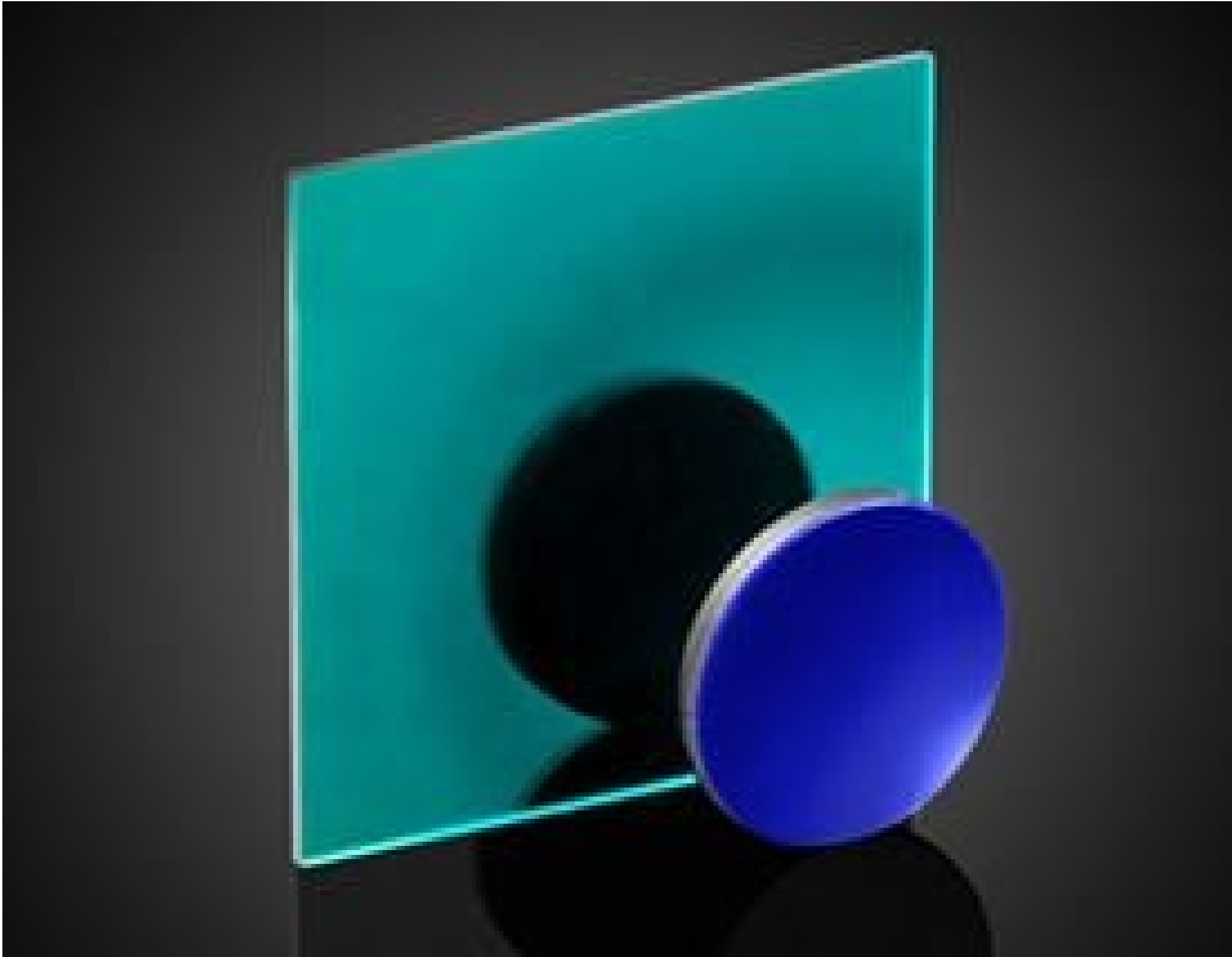

Stock **#14-426** ☐ In Stock

1 **£74.80**

ADD TO CART

Qty 1-10
£74.80
Qty 11+
£66.30
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Dimensions (mm):
50.0 x 50.0

Center Wavelength CWL (nm):
480.00

Density (g/cm³): 2.69
Glass/Filter Number: SCHOTT BG42
Length (mm): 50.00
Coating: Uncoated
Color: Blue-Green
Index of Refraction n _d : 1.54
Surface Quality: 60-40
Transformation Temperature (°C): 475
Thickness (mm): 3.00 ±0.2
Type: Bandpass Filter
Wavelength: UV-VIS
Width (mm): 50.00
Bevel: Protective as needed

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View