
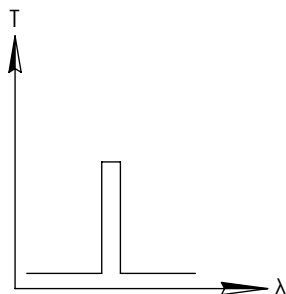
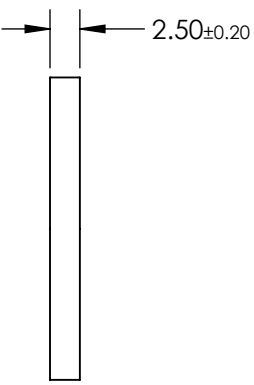
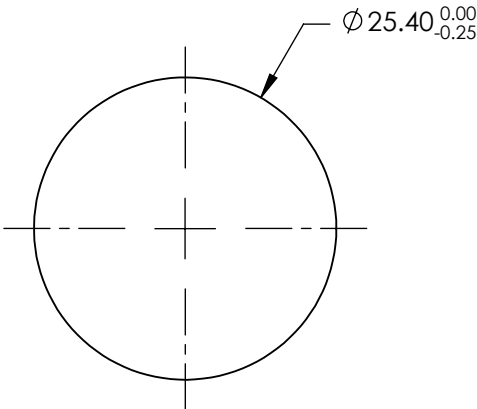


**FOR INFORMATION ONLY:  
DO NOT MANUFACTURE  
PARTS TO THIS DRAWING**

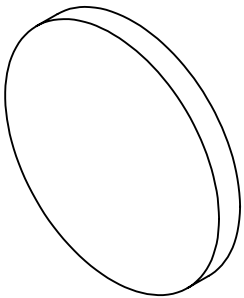

BANDPASS FILTER

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

	VALUE
SHAPE	PLANO
CENTER WAVELENGTH (nm)	340
FULL WIDTH HALF MAX (FWHM) (nm)	85
SURFACE QUALITY	60-40
COATING TYPE	Uncoated
BEVEL	PROTECTIVE AS NEEDED

**EO**® Edmund Optics®

THIRD ANGLE PROJECTION		TITLE	HOYA U-340 (UV) 25.4mm Dia., Colored Glass Bandpass Filter	
ALL DIMS IN	mm	DWG NO	46439	SHEET 1 OF 1