
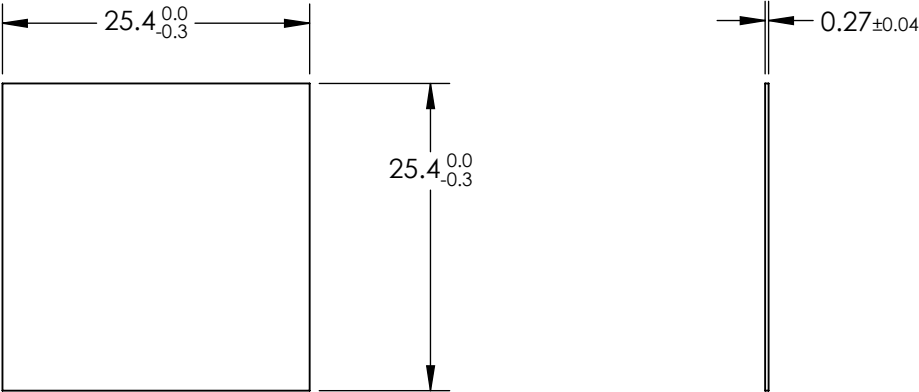


NOTES:


- 1. SUBSTRATE: PLASTIC
- 2. TYPE: RIGHT-HANDED CIRCULAR POLARIZER
- 3. OPERATING TEMPERATURE: -40 to +80 °C
- 4. WAVELENGTH RANGE: 400 - 700 nm
- 5. EFFICIENCY OF LINEAR COMPONENT: 99.98%
- 6. ROHS COMPLIANT

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

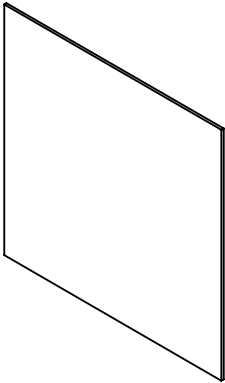

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

EO[®] Edmund Optics[®]

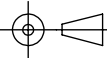THIRD ANGLE PROJECTION 		TITLE	25.4 x 25.4mm RIGHT-HANDED CIRCULAR POLARIZER	
ALL DIMS IN	mm	DWG NO	11047	SHEET 1 OF 1