


[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Flat Mirrors](#) / [Float Glass](#)

TECHSPEC®

First Surface Mirrors

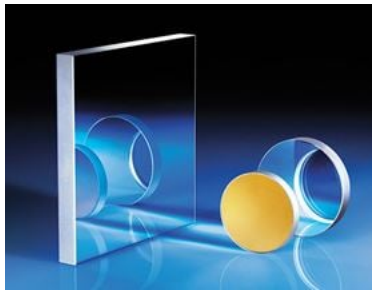


- Wide Variety of Shapes and Sizes Available
- Enhanced Aluminum, Protected Gold, and Protected Silver Coatings for high reflectivity from 450-10000nm
- [Contact Us](#) for Custom Sizes

Common Specifications

Optical Properties

Surface Flatness (P-V):	4 - 6λ	Substrate:	Float Glass
Surface Quality:	60-40	Coating Type:	Metal

Technical Information

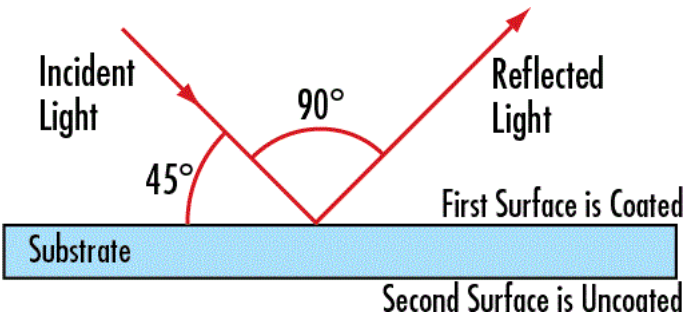

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Coating Specification	Surface Flatness (P-V)	Stock Number	Price	Buy
5.00	-	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#32-940	£22.33 Volume Pricing	20+ In Stock
-	6.0 x 6.0	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-866	£22.33 Volume Pricing	20+ In Stock
-	6.0 x 8.5	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-867	£22.33 Volume Pricing	20+ In Stock
6.35	-	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-610	£22.33 Volume Pricing	Contact Us
10.00	-	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#32-941	£22.33 Volume Pricing	20+ In Stock
-	10.0 x 10.0	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-517	£22.33 Volume Pricing	20+ In Stock
-	10.0 x 14.0	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#48-449	£22.33 Volume Pricing	20+ In Stock
12.50	-	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#32-942	£22.33 Volume Pricing	20+ In Stock
-	12.5 x 12.5	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-790	£22.33 Volume Pricing	20+ In Stock
-	12.5 x 17.5	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-869	£22.33 Volume Pricing	20+ In Stock
12.70	-	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-483	£22.33 Volume Pricing	20+ In Stock
-	12.7 x 12.7	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-484	£22.33 Volume Pricing	15 In Stock

15.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 45° 450 - 650nm @ 45°	4 - 6λ	#32-943	£22.33 Volume Pricing	20+ In Stock
-	15.0 x 15.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 45° 450 - 650nm @ 45°	4 - 6λ	#43-870	£22.33 Volume Pricing	20+ In Stock
-	15.0 x 21.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 45° 450 - 650nm @ 45°	4 - 6λ	#43-871	£22.33 Volume Pricing	20+ In Stock
18.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 45° 450 - 650nm @ 45°	4 - 6λ	#45-521	£22.33 Volume Pricing	12 In Stock
20.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 45° 450 - 650nm @ 45°	4 - 6λ	#32-944	£24.30 Volume Pricing	20+ In Stock
-	20.0 x 20.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 45° 450 - 650nm @ 45°	4 - 6λ	#43-872	£24.30 Volume Pricing	20+ In Stock
-	20.0 x 28.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 45° 450 - 650nm @ 45°	4 - 6λ	#43-873	£24.30 Volume Pricing	20+ In Stock
25.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 45° 450 - 650nm @ 45°	4 - 6λ	#32-945	£24.30 Volume Pricing	20+ In Stock
-	25.0 x 25.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 45° 450 - 650nm @ 45°	4 - 6λ	#43-792	£24.30 Volume Pricing	20+ In Stock
-	25.0 x 35.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 45° 450 - 650nm @ 45°	4 - 6λ	#43-875	£24.30 Volume Pricing	20+ In Stock
25.40	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 45° 450 - 650nm @ 45°	4 - 6λ	#83-485	£24.30 Volume Pricing	20+ In Stock
-	25.4 x 25.4	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 45° 450 - 650nm @ 45°	4 - 6λ	#83-486	£24.30 Volume Pricing	20+ In Stock
30.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 45° 450 - 650nm @ 45°	4 - 6λ	#46-025	£28.02 Volume Pricing	20+ In Stock
35.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 45° 450 - 650nm @ 45°	4 - 6λ	#46-027	£28.02 Volume Pricing	Contact Us

-	35.0 x 35.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-519	£28.02 Volume Pricing	20+ In Stock
-	35.0 x 50.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#48-450	£28.02 Volume Pricing	20+ In Stock
38.10	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-487	£28.02 Volume Pricing	20+ In Stock
-	38.1 x 38.1	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-488	£28.02 Volume Pricing	20+ In Stock
40.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-612	£35.90 Volume Pricing	20+ In Stock
50.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-614	£35.90 Volume Pricing	20+ In Stock
-	50.0 x 50.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-876	£35.90 Volume Pricing	20+ In Stock
-	50.0 x 75.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#48-451	£35.90 Volume Pricing	20+ In Stock
50.80	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-489	£35.90 Volume Pricing	7 In Stock
-	50.8 x 50.8	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-490	£35.90 Volume Pricing	20+ In Stock
-	60.0 x 85.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#64-410	£43.33 Volume Pricing	20+ In Stock
75.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-616	£43.33 Volume Pricing	20+ In Stock
-	75.0 x 75.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#48-452	£43.33 Volume Pricing	1 In Stock

-	75.0 x 100.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#48-453	£43.33 Volume Pricing	20+ In Stock
76.20	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-491	£43.33 Volume Pricing	14 In Stock
-	76.2 x 76.2	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-492	£43.33 Volume Pricing	20+ In Stock
100.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#18-920	£50.35 Volume Pricing	Contact Us
-	100.00 x 100.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#18-922	£50.35 Volume Pricing	Contact Us
101.60	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#18-924	£50.35 Volume Pricing	9 In Stock
-	101.60 x 101.60	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#18-926	£50.35 Volume Pricing	10 In Stock
125.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#18-928	£64.79 Volume Pricing	4 In Stock
-	125.00 x 125.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#18-930	£64.79 Volume Pricing	6 In Stock
127.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#18-932	£64.79 Volume Pricing	3 In Stock
-	127.00 x 127.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#18-934	£64.79 Volume Pricing	20+ In Stock
150.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#19-349	£80.55 Volume Pricing	20+ In Stock
-	150.00 x 150.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#19-350	£80.55 Volume Pricing	12 In Stock

200.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#19-351	£106.81 Volume Pricing	11 In Stock
-	200.00 x 200.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#19-352	£106.81 Volume Pricing	13 In Stock
5.00	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-728	£35.45 Volume Pricing	20+ In Stock
-	6.0 x 6.0	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-877	£35.45 Volume Pricing	20+ In Stock
-	6.0 x 8.5	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-878	£35.45 Volume Pricing	20+ In Stock
6.35	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-611	£35.45 Volume Pricing	20+ In Stock
10.00	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-729	£35.45 Volume Pricing	20+ In Stock
-	10.0 x 10.0	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-518	£35.45 Volume Pricing	4 In Stock
-	10.0 x 14.0	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#48-454	£35.45 Volume Pricing	16 In Stock
12.50	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-730	£35.45 Volume Pricing	20+ In Stock

-	12.5 x 12.5	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-791	£35.45 Volume Pricing	20+ In Stock
-	12.5 x 17.5	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-880	£35.45 Volume Pricing	9 In Stock
12.70	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-493	£35.45 Volume Pricing	Contact Us
-	12.7 x 12.7	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-494	£35.45 Volume Pricing	Contact Us
15.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-731	£35.45 Volume Pricing	Contact Us
-	15.0 x 15.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-881	£35.45 Volume Pricing	20+ In Stock
-	15.0 x 21.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-882	£35.45 Volume Pricing	20+ In Stock
18.00	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-522	£35.45 Volume Pricing	20+ In Stock
20.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-732	£42.02 Volume Pricing	20+ In Stock
-	20.0 x 20.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-883	£42.02 Volume Pricing	20+ In Stock
-	20.0 x 28.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-884	£42.02 Volume Pricing	20+ In Stock

25.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-733	£42.02 Volume Pricing	20+ In Stock
-	25.0 x 25.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-793	£42.02 Volume Pricing	14 In Stock
-	25.0 x 35.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-886	£42.02 Volume Pricing	20+ In Stock
25.40	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-495	£42.02 Volume Pricing	1 In Stock
-	25.4 x 25.4	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-496	£42.02 Volume Pricing	2 In Stock
30.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#46-026	£66.10 Volume Pricing	11 In Stock
35.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#46-028	£66.10 Volume Pricing	17 In Stock
-	35.0 x 35.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-520	£66.10 Volume Pricing	14 In Stock
-	35.0 x 50.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#48-455	£66.10 Volume Pricing	20+ In Stock
38.10	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-497	£66.10 Volume Pricing	5 In Stock
-	38.1 x 38.1	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-498	£66.10 Volume Pricing	20+ In Stock

40.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-613	£77.48 Volume Pricing	5 In Stock
50.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-615	£77.48 Volume Pricing	1 In Stock
-	50.0 x 50.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-887	£77.48 Volume Pricing	20+ In Stock
-	50.0 x 75.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#48-456	£77.48 Volume Pricing	Contact Us
50.80	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-499	£77.48 Volume Pricing	20+ In Stock
-	50.8 x 50.8	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-500	£77.48 Volume Pricing	2 In Stock
-	60.0 x 85.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#64-411	£102.43 Volume Pricing	20+ In Stock
75.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-617	£102.43 Volume Pricing	20+ In Stock
-	75.0 x 75.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#48-457	£102.43 Volume Pricing	14 In Stock
-	75.0 x 100.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#48-458	£102.43 Volume Pricing	13 In Stock
76.20	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-501	£102.43 Volume Pricing	20+ In Stock

-	76.2 x 76.2	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-502	£102.43 Volume Pricing	5 In Stock
100.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#22-431	£238.14 Volume Pricing	3 In Stock
-	100.0 x 100.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#22-432	£238.14 Volume Pricing	2 In Stock
#71-427 New								
-	100.00 x 140.00	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	£231.13 Volume Pricing	4 In Stock
-	85.00 x 120.00	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	#71-426	£184.73 Volume Pricing	5 In Stock
-	50.0 x 75.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-496	£43.33 Volume Pricing	20+ In Stock
-	50.0 x 50.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-495	£43.33 Volume Pricing	20+ In Stock
50.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-494	£43.33 Volume Pricing	17 In Stock

-	40.00 x 57.50	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	#71-424	£59.98 Volume Pricing	7 In Stock
-	35.0 x 50.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-490	£33.49 Volume Pricing	20+ In Stock
-	35.0 x 35.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-489	£33.49 Volume Pricing	20+ In Stock
35.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-488	£33.49 Volume Pricing	20+ In Stock
#71-423 New								
-	30.00 x 42.00	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	£43.33 Volume Pricing	11 In Stock
30.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-487	£33.49 Volume Pricing	20+ In Stock
-	25.0 x 35.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-484	£29.32 Volume Pricing	20+ In Stock
-	25.0 x 25.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-483	£29.32 Volume Pricing	20+ In Stock

25.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-482	£29.32 Volume Pricing	20+ In Stock
-	20.0 x 28.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-481	£29.32 Volume Pricing	20+ In Stock
-	20.0 x 20.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-480	£29.32 Volume Pricing	20+ In Stock
20.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-479	£29.32 Volume Pricing	7 In Stock
-	15.0 x 21.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-477	£26.05 Volume Pricing	20+ In Stock
-	15.0 x 15.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-476	£26.05 Volume Pricing	20+ In Stock
15.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-475	£26.05 Volume Pricing	11 In Stock
-	17.50 x 25.00	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	#71-422	£29.32 Volume Pricing	Contact Us
-	12.5 x 17.5	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-472	£26.05 Volume Pricing	20+ In Stock

-	12.5 x 12.5	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-471	£26.05 Volume Pricing	Contact Us
12.50	-	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-470	£26.05 Volume Pricing	20+ In Stock
-	10.0 x 14.0	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-469	£26.05 Volume Pricing	20+ In Stock
-	10.0 x 10.0	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-468	£26.05 Volume Pricing	12 In Stock
10.00	-	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-467	£26.05 Volume Pricing	20+ In Stock
-	8.00 x 11.50	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	#71-421	£26.05 Volume Pricing	14 In Stock
6.35	-	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-466	£26.05 Volume Pricing	17 In Stock
-	6.0 x 8.5	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-465	£26.05 Volume Pricing	20+ In Stock
-	6.0 x 6.0	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-464	£26.05 Volume Pricing	20+ In Stock
-	5.00 x 7.50	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	#71-420	£26.05 Volume Pricing	11 In Stock

-	5.00 x 5.00	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	#71-419	£26.05 Volume Pricing	13 In Stock
5.00	-	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-463	£26.05 Volume Pricing	5 In Stock
12.70	-	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-040	£26.05 Volume Pricing	20+ In Stock
-	12.7 x 12.7	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-041	£26.05 Volume Pricing	Contact Us
18.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-042	£26.05 Volume Pricing	1 In Stock
25.40	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-043	£29.32 Volume Pricing	20+ In Stock
-	25.4 x 25.4	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-044	£29.32 Volume Pricing	20+ In Stock
38.10	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-045	£33.49 Volume Pricing	20+ In Stock
-	38.1 x 38.1	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-046	£33.49 Volume Pricing	20+ In Stock
40.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-048	£43.33 Volume Pricing	20+ In Stock

50.80	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-049	£43.33 Volume Pricing	20+ In Stock
-	50.8 x 50.8	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-050	£43.33 Volume Pricing	20+ In Stock
-	60.0 x 85.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-051	£59.98 Volume Pricing	14 In Stock
-	63.50 x 88.90	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	#71-425	£70.04 Volume Pricing	6 In Stock
75.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-053	£59.98 Volume Pricing	20+ In Stock
-	75.0 x 75.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-054	£59.98 Volume Pricing	20+ In Stock
-	75.0 x 100.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-055	£59.98 Volume Pricing	20+ In Stock
76.20	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-056	£59.98 Volume Pricing	12 In Stock
-	76.2 x 76.2	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#36-057	£59.98 Volume Pricing	15 In Stock
100.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#22-443	£167.22 Volume Pricing	4 In Stock

-	100.0 x 100.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#22-444	£167.22 Volume Pricing	14 In Stock
-	125.0 x 125.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#22-448	£231.13 Volume Pricing	10 In Stock
-	150.0 x 150.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	#22-452	£323.06 Volume Pricing	7 In Stock
#22-454 New								
-	200.0 x 200.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	£507.79 Volume Pricing	3 In Stock
-	5.0 x 5.0	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-408	£22.33 Volume Pricing	8 In Stock
-	5.0 x 7.5	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-409	£22.33 Volume Pricing	9 In Stock
-	8.0 x 11.5	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-410	£22.33 Volume Pricing	20+ In Stock
-	17.5 x 25.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-411	£22.33 Volume Pricing	20+ In Stock
-	30.0 x 42.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-412	£28.02 Volume Pricing	20+ In Stock

-	40.0 x 57.5	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-413	£35.90 Volume Pricing	14 In Stock
-	63.5 x 88.9	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-414	£43.33 Volume Pricing	7 In Stock
-	85.0 x 120.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-415	£46.84 Volume Pricing	20+ In Stock
-	100.0 x 140.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-416	£64.79 Volume Pricing	20+ In Stock
-	125.00 x 175.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-413	£77.04 Volume Pricing	11 In Stock
225.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-414	£119.94 Volume Pricing	8 In Stock
-	225.00 x 225.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-415	£119.94 Volume Pricing	11 In Stock
250.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-416	£133.95 Volume Pricing	7 In Stock
-	250.00 x 250.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-417	£133.95 Volume Pricing	9 In Stock
-	250.00 x 350.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-418	£175.10 Volume Pricing	8 In Stock
300.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-419	£161.97 Volume Pricing	2 In Stock
-	300.00 x 300.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-420	£161.97 Volume Pricing	14 In Stock
-	400.0 x 400.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-417	£277.53 Volume Pricing	15 In Stock
-	500.0 x 500.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#71-418	£369.46 Volume Pricing	9 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

www.edmundoptics.com