

[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [UV and IR Windows](#)

TECHSPEC® Sapphire Windows



- Features Extreme Surface Hardness Chemical Resistance
- Transmits Wavelengths Ranging From UV to Mid-Infrared
- Thinner and Stronger than Standard Glass Windows
- Anti-Reflection Coating Options Covering 350 - 5000nm Available

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed	Clear Aperture (%):	≥90
Edges:	Fine Ground	Knoop Hardness (kg/mm²):	1,900.00
Poisson's Ratio:	0.27	Young's Modulus (GPa):	435



Optical Properties

Abbe Number (v_d):	72.24	Axis Orientation:	Random
Birefringence (n_o-n_e):	0.008 for Visible Light Orthogonal to Optical Axis	Index of Refraction (n_d):	1.77
Substrate:	Sapphire (Al ₂ O ₃)	Surface Quality:	80-50


Material Properties

Coefficient of Thermal Expansion CTE (10⁻⁶/°C):	5.4 (Parallel to C-Axis) 4.3 (Perpendicular to C-Axis)	Density (g/cm³):	3.97
---	---	------------------------------------	------


Technical Information

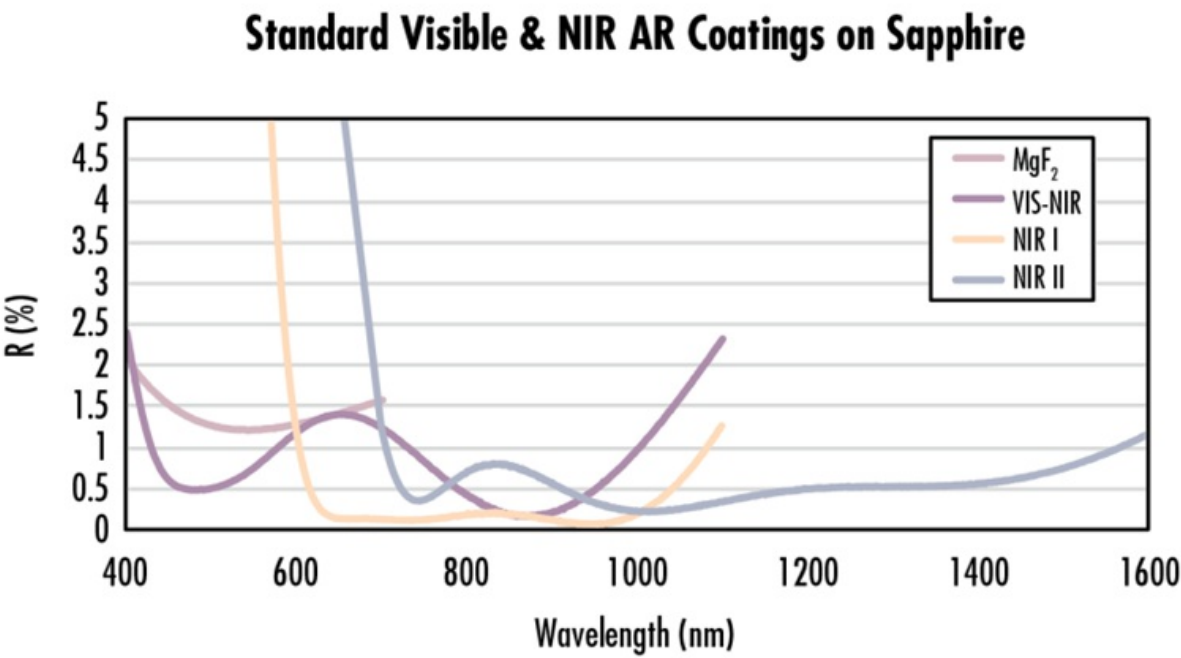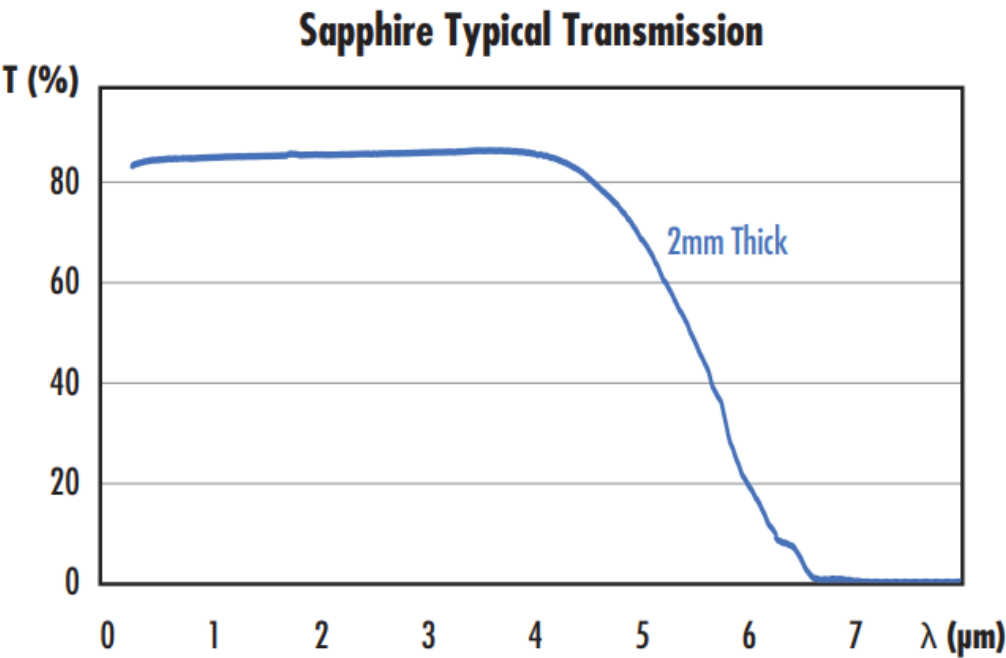

Infrared BBAR Coatings on Sapphire

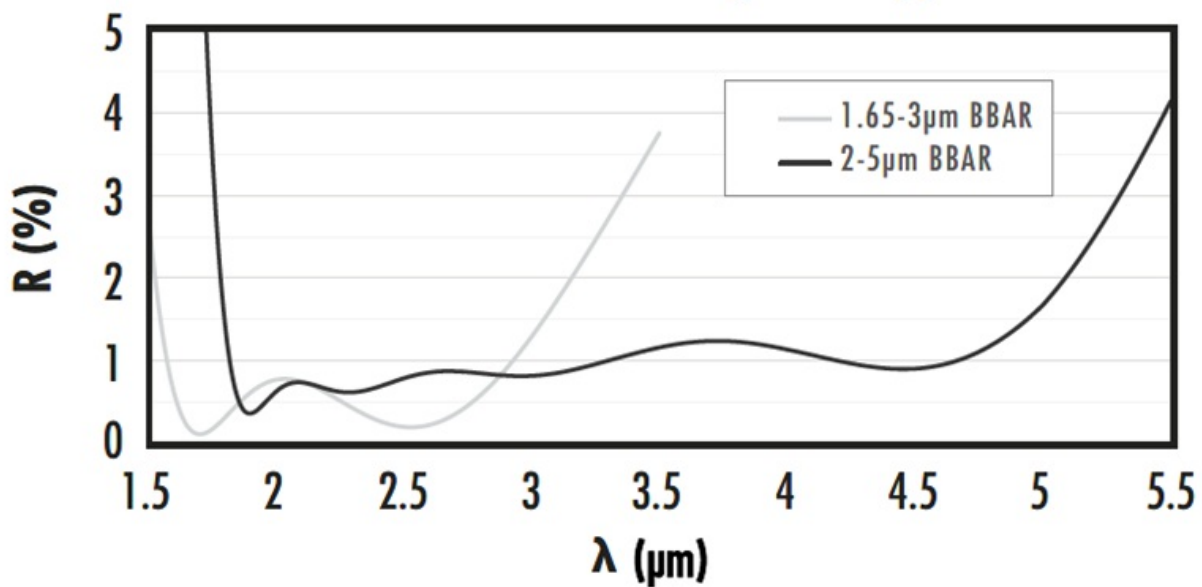

Infrared AR Coated Sapphire Windows 1mm Thickness

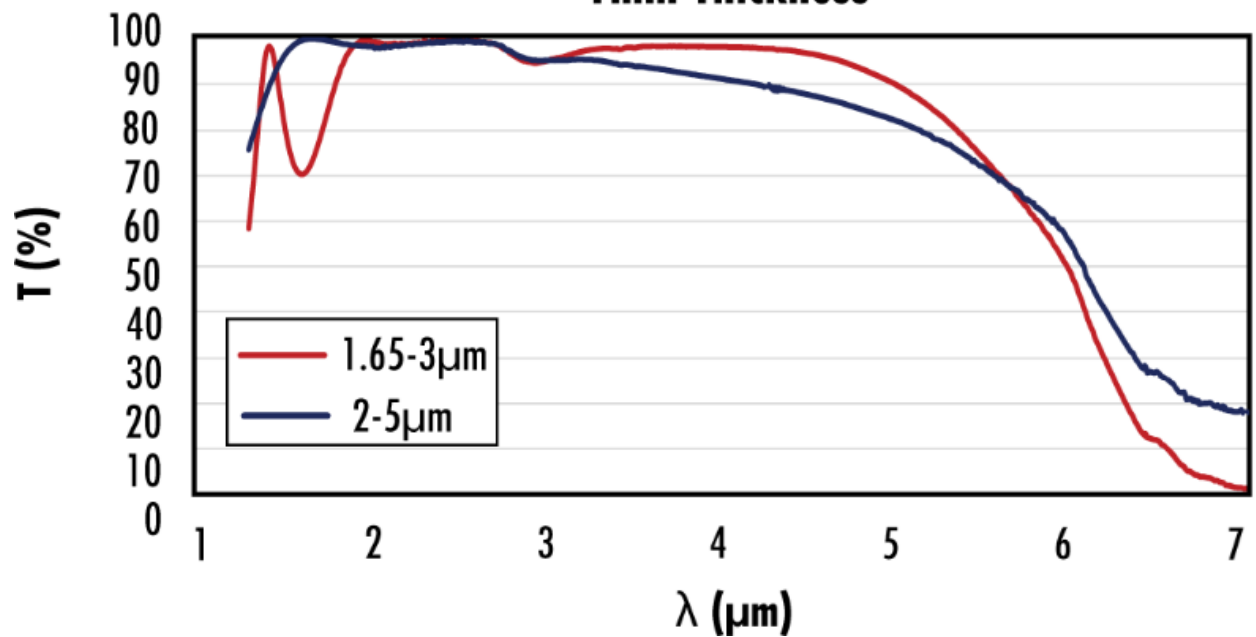

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
1.00	-	0.50	Uncoated	#17-216	£23.00 Volume Pricing	20+ In Stock
2.50	-	0.50	Uncoated	#43-627	£23.00 Volume Pricing	20+ In Stock
3.20	-	1.00	Uncoated	#17-217	£23.00 Volume Pricing	20+ In Stock
5.00	-	0.20	Uncoated	#71-217	£36.00 Volume Pricing	20+ In Stock
5.00	-	0.50	Uncoated	#17-218	£31.00 Volume Pricing	20+ In Stock
5.00	-	1.00	Uncoated	#43-365	£32.00 Volume Pricing	17 In Stock
5.00	-	2.00	Uncoated	#25-376	£31.00 Volume Pricing	20+ In Stock
5.00	-	3.00	Uncoated	#25-377	£31.00 Volume Pricing	20+ In Stock
5.00	-	0.50	MgF ₂ (400-700nm)	#20-623	£46.00 Volume Pricing	7 In Stock
5.00	-	1.00	MgF ₂ (400-700nm)	#36-197	£46.00 Volume Pricing	8 In Stock
5.00	-	2.00	MgF ₂ (400-700nm)	#25-386	£46.00 Volume Pricing	3 In Stock
5.00	-	3.00	MgF ₂ (400-700nm)	#25-387	£46.00 Volume Pricing	1 In Stock
5.00	-	0.50	VIS-EXT (350-700nm)	#28-512	£51.00 Volume Pricing	7 In Stock
5.00	-	1.00	VIS-EXT (350-700nm)	#28-513	£51.00 Volume Pricing	20+ In Stock

5.00	-	2.00	VIS-EXT (350-700nm)	#28-514	£51.00 Volume Pricing	5 In Stock
5.00	-	3.00	VIS-EXT (350-700nm)	#28-515	£51.00 Volume Pricing	10 In Stock
5.00	-	0.50	VIS-NIR (400-1000nm)	#20-741	£53.00 Volume Pricing	3 In Stock
5.00	-	1.00	VIS-NIR (400-1000nm)	#36-577	£51.00 Volume Pricing	4 In Stock
5.00	-	2.00	VIS-NIR (400-1000nm)	#25-396	£51.00 Volume Pricing	1 In Stock
5.00	-	3.00	VIS-NIR (400-1000nm)	#25-397	£53.00 Volume Pricing	Contact Us
5.00	-	0.50	NIR I (600-1050nm)	#20-838	£51.00 Volume Pricing	Contact Us
5.00	-	1.00	NIR I (600-1050nm)	#36-477	£51.00 Volume Pricing	10 In Stock
5.00	-	2.00	NIR I (600-1050nm)	#25-406	£53.00 Volume Pricing	4 In Stock
5.00	-	3.00	NIR I (600-1050nm)	#25-407	£51.00 Volume Pricing	2 In Stock
5.00	-	0.50	NIR II (750-1550nm)	#20-904	£51.00 Volume Pricing	10 In Stock
5.00	-	1.00	NIR II (750-1550nm)	#36-562	£51.00 Volume Pricing	3 In Stock
5.00	-	2.00	NIR II (750-1550nm)	#25-416	£51.00 Volume Pricing	9 In Stock
5.00	-	3.00	NIR II (750-1550nm)	#25-417	£51.00 Volume Pricing	2 In Stock

5.00	-	0.50	BBAR (1650-3000nm)	#20-974	£65.00 Volume Pricing	7 In Stock
5.00	-	1.00	BBAR (1650-3000nm)	#15-988	£65.00 Volume Pricing	20+ In Stock
5.00	-	2.00	BBAR (1650-3000nm)	#25-426	£65.00 Volume Pricing	4 In Stock
5.00	-	3.00	BBAR (1650-3000nm)	#25-427	£65.00 Volume Pricing	5 In Stock
5.00	-	0.50	BBAR (2000-5000nm)	#21-011	£65.00 Volume Pricing	5 In Stock
5.00	-	1.00	BBAR (2000-5000nm)	#16-000	£65.00 Volume Pricing	5 In Stock
5.00	-	2.00	BBAR (2000-5000nm)	#25-436	£65.00 Volume Pricing	4 In Stock
5.00	-	3.00	BBAR (2000-5000nm)	#25-437	£67.00 Volume Pricing	5 In Stock
6.35	-	0.20	Uncoated	#71-218	£36.00 Volume Pricing	20+ In Stock
6.35	-	0.50	Uncoated	#45-567	£31.00 Volume Pricing	20+ In Stock
6.35	-	1.00	Uncoated	#17-219	£31.00 Volume Pricing	20+ In Stock
6.35	-	2.00	Uncoated	#17-220	£31.00 Volume Pricing	20+ In Stock
6.35	-	0.50	MgF ₂ (400-700nm)	#39-231	£46.00 Volume Pricing	20+ In Stock
6.35	-	1.00	MgF ₂ (400-700nm)	#20-627	£46.00 Volume Pricing	1 In Stock
6.35	-	2.00	MgF ₂ (400-700nm)	#20-629	£46.00 Volume Pricing	2 In Stock

6.35	-	0.50	VIS-EXT (350-700nm)	#28-516	£51.00 Volume Pricing	6 In Stock
6.35	-	1.00	VIS-EXT (350-700nm)	#28-517	£51.00 Volume Pricing	14 In Stock
6.35	-	2.00	VIS-EXT (350-700nm)	#28-518	£51.00 Volume Pricing	5 In Stock
6.35	-	0.50	VIS-NIR (400-1000nm)	#39-246	£51.00 Volume Pricing	5 In Stock
6.35	-	1.00	VIS-NIR (400-1000nm)	#20-760	£53.00 Volume Pricing	2 In Stock
6.35	-	2.00	VIS-NIR (400-1000nm)	#20-763	£53.00 Volume Pricing	2 In Stock
6.35	-	0.50	NIR I (600-1050nm)	#39-252	£51.00 Volume Pricing	9 In Stock
6.35	-	1.00	NIR I (600-1050nm)	#20-839	£51.00 Volume Pricing	Contact Us
6.35	-	2.00	NIR I (600-1050nm)	#20-841	£51.00 Volume Pricing	12 In Stock
6.35	-	0.50	NIR II (750-1550nm)	#39-262	£51.00 Volume Pricing	Contact Us
6.35	-	1.00	NIR II (750-1550nm)	#20-908	£51.00 Volume Pricing	Contact Us
6.35	-	2.00	NIR II (750-1550nm)	#20-913	£51.00 Volume Pricing	1 In Stock
6.35	-	0.50	BBAR (1650-3000nm)	#15-989	£65.00 Volume Pricing	11 In Stock
6.35	-	1.00	BBAR (1650-3000nm)	#20-976	£65.00 Volume Pricing	7 In Stock

6.35	-	2.00	BBAR (1650-3000nm)	#20-977	£65.00 Volume Pricing	5 In Stock
6.35	-	0.50	BBAR (2000-5000nm)	#16-001	£65.00 Volume Pricing	4 In Stock
6.35	-	1.00	BBAR (2000-5000nm)	#21-013	£65.00 Volume Pricing	2 In Stock
6.35	-	2.00	BBAR (2000-5000nm)	#21-015	£65.00 Volume Pricing	4 In Stock
7.50	-	0.40	Uncoated	#43-628	£31.00 Volume Pricing	20+ In Stock
9.50	-	0.50	Uncoated	#43-629	£31.00 Volume Pricing	20+ In Stock
10.00	-	0.20	Uncoated	#71-221	£43.00 Volume Pricing	20+ In Stock
10.00	-	0.50	Uncoated	#17-221	£43.00 Volume Pricing	20+ In Stock
10.00	-	1.00	Uncoated	#43-366	£43.00 Volume Pricing	20+ In Stock
10.00	-	2.00	Uncoated	#25-378	£43.00 Volume Pricing	20+ In Stock
10.00	-	3.00	Uncoated	#25-379	£43.00 Volume Pricing	20+ In Stock
10.00	-	0.50	MgF ₂ (400-700nm)	#20-633	£58.00 Volume Pricing	3 In Stock
10.00	-	1.00	MgF ₂ (400-700nm)	#36-201	£58.00 Volume Pricing	9 In Stock
10.00	-	2.00	MgF ₂ (400-700nm)	#25-388	£58.00 Volume Pricing	4 In Stock
10.00	-	3.00	MgF ₂ (400-700nm)	#25-389	£58.00 Volume Pricing	1 In Stock
10.00	-	0.50	VIS-EXT (350-700nm)	#28-519	£63.00 Volume Pricing	7 In Stock

10.00	-	1.00	VIS-EXT (350-700nm)	#28-553	£63.00 Volume Pricing	1 In Stock
10.00	-	2.00	VIS-EXT (350-700nm)	#28-554	£63.00 Volume Pricing	4 In Stock
10.00	-	3.00	VIS-EXT (350-700nm)	#28-555	£63.00 Volume Pricing	12 In Stock
10.00	-	0.50	VIS-NIR (400-1000nm)	#20-765	£64.00 Volume Pricing	4 In Stock
10.00	-	1.00	VIS-NIR (400-1000nm)	#36-578	£63.00 Volume Pricing	1 In Stock
10.00	-	0.50	NIR I (600-1050nm)	#20-848	£63.00 Volume Pricing	2 In Stock
10.00	-	1.00	NIR I (600-1050nm)	#36-487	£63.00 Volume Pricing	6 In Stock
10.00	-	0.50	NIR II (750-1550nm)	#20-914	£63.00 Volume Pricing	5 In Stock
10.00	-	1.00	NIR II (750-1550nm)	#36-566	£63.00 Volume Pricing	8 In Stock
10.00	-	2.00	VIS-NIR (400-1000nm)	#25-398	£64.00 Volume Pricing	Contact Us
10.00	-	3.00	VIS-NIR (400-1000nm)	#25-399	£64.00 Volume Pricing	11 In Stock
10.00	-	2.00	NIR I (600-1050nm)	#25-408	£63.00 Volume Pricing	5 In Stock
10.00	-	3.00	NIR I (600-1050nm)	#25-409	£63.00 Volume Pricing	16 In Stock
10.00	-	2.00	NIR II (750-1550nm)	#25-418	£63.00 Volume Pricing	20+ In Stock

10.00	-	3.00	NIR II (750-1550nm)	#25-419	£63.00 Volume Pricing	3 In Stock
10.00	-	0.50	BBAR (1650-3000nm)	#20-981	£77.00 Volume Pricing	3 In Stock
10.00	-	1.00	BBAR (1650-3000nm)	#15-990	£77.00 Volume Pricing	2 In Stock
10.00	-	2.00	BBAR (1650-3000nm)	#25-428	£77.00 Volume Pricing	2 In Stock
10.00	-	3.00	BBAR (1650-3000nm)	#25-429	£77.00 Volume Pricing	4 In Stock
10.00	-	0.50	BBAR (2000-5000nm)	#21-016	£77.00 Volume Pricing	Contact Us
10.00	-	1.00	BBAR (2000-5000nm)	#16-002	£77.00 Volume Pricing	Contact Us
10.00	-	2.00	BBAR (2000-5000nm)	#25-438	£79.00 Volume Pricing	5 In Stock
10.00	-	3.00	BBAR (2000-5000nm)	#25-439	£79.00 Volume Pricing	5 In Stock
12.50	-	1.00	VIS-EXT (350-700nm)	#28-556	£65.00 Volume Pricing	2 In Stock
12.50	-	1.00	Uncoated	#36-252	£45.00 Volume Pricing	20+ In Stock
12.50	-	1.00	MgF ₂ (400-700nm)	#36-202	£60.00 Volume Pricing	10 In Stock
12.50	-	1.00	VIS-NIR (400-1000nm)	#36-579	£65.00 Volume Pricing	20+ In Stock
12.50	-	1.00	NIR I (600-1050nm)	#36-488	£65.00 Volume Pricing	16 In Stock

12.50	-	1.00	NIR II (750-1550nm)	#36-567	£65.00 Volume Pricing	9 In Stock
12.50	-	1.00	BBAR (1650-3000nm)	#15-991	£79.00 Volume Pricing	Contact Us
12.50	-	1.00	BBAR (2000-5000nm)	#16-003	£79.00 Volume Pricing	Contact Us
-	12.50 x 12.50	1.00	Uncoated	#39-228	£46.00 Volume Pricing	20+ In Stock
12.70	-	0.20	Uncoated	#71-224	£46.00 Volume Pricing	20+ In Stock
12.70	-	0.50	Uncoated	#17-222	£48.00 Volume Pricing	20+ In Stock
12.70	-	1.00	Uncoated	#17-223	£48.00 Volume Pricing	20+ In Stock
12.70	-	2.00	Uncoated	#17-224	£48.00 Volume Pricing	20+ In Stock
12.70	-	3.18	Uncoated	#68-157	£46.00 Volume Pricing	20+ In Stock
12.70	-	0.50	MgF ₂ (400-700nm)	#20-634	£62.00 Volume Pricing	5 In Stock
12.70	-	1.00	MgF ₂ (400-700nm)	#20-635	£62.00 Volume Pricing	1 In Stock
12.70	-	2.00	MgF ₂ (400-700nm)	#20-638	£62.00 Volume Pricing	6 In Stock
12.70	-	3.18	MgF ₂ (400-700nm)	#39-232	£62.00 Volume Pricing	2 In Stock
12.70	-	1.00	VIS-EXT (350-700nm)	#28-558	£66.00 Volume Pricing	11 In Stock
12.70	-	2.00	VIS-EXT (350-700nm)	#28-559	£66.00 Volume Pricing	14 In Stock
12.70	-	3.18	VIS-EXT (350-700nm)	#28-560	£66.00 Volume Pricing	14 In Stock

12.70	-	0.50	VIS-NIR (400-1000nm)	#20-766	£68.00 Volume Pricing	20+ In Stock
12.70	-	1.00	VIS-NIR (400-1000nm)	#20-771	£68.00 Volume Pricing	5 In Stock
12.70	-	2.00	VIS-NIR (400-1000nm)	#20-788	£68.00 Volume Pricing	5 In Stock
12.70	-	3.18	VIS-NIR (400-1000nm)	#39-247	£66.00 Volume Pricing	17 In Stock
12.70	-	0.50	NIR I (600-1050nm)	#20-850	£66.00 Volume Pricing	5 In Stock
12.70	-	1.00	NIR I (600-1050nm)	#20-857	£66.00 Volume Pricing	15 In Stock
12.70	-	2.00	NIR I (600-1050nm)	#20-859	£66.00 Volume Pricing	Contact Us
12.70	-	3.18	NIR I (600-1050nm)	#39-253	£66.00 Volume Pricing	1 In Stock
12.70	-	0.50	NIR II (750-1550nm)	#20-918	£66.00 Volume Pricing	6 In Stock
12.70	-	1.00	NIR II (750-1550nm)	#20-926	£66.00 Volume Pricing	12 In Stock
12.70	-	2.00	NIR II (750-1550nm)	#20-927	£66.00 Volume Pricing	6 In Stock
12.70	-	3.18	NIR II (750-1550nm)	#39-263	£66.00 Volume Pricing	11 In Stock
12.70	-	0.50	BBAR (1650-3000nm)	#21-000	£80.00 Volume Pricing	5 In Stock
12.70	-	0.50	VIS-EXT (350-700nm)	#28-557	£66.00 Volume Pricing	5 In Stock

12.70	-	1.00	BBAR (1650-3000nm)	#21-001	£80.00 Volume Pricing	Contact Us
12.70	-	2.00	BBAR (1650-3000nm)	#21-002	£80.00 Volume Pricing	5 In Stock
12.70	-	3.18	BBAR (1650-3000nm)	#15-992	£80.00 Volume Pricing	1 In Stock
12.70	-	0.50	BBAR (2000-5000nm)	#21-017	£80.00 Volume Pricing	10 In Stock
12.70	-	1.00	BBAR (2000-5000nm)	#21-018	£80.00 Volume Pricing	Contact Us
12.70	-	2.00	BBAR (2000-5000nm)	#21-019	£80.00 Volume Pricing	13 In Stock
12.70	-	3.18	BBAR (2000-5000nm)	#16-004	£80.00 Volume Pricing	20+ In Stock
12.75	-	1.00	Uncoated	#43-631	£46.00 Volume Pricing	Contact Us
13.00	-	0.50	Uncoated	#43-632	£46.00 Volume Pricing	20+ In Stock
15.00	-	0.20	Uncoated	#71-225	£58.00 Volume Pricing	12 In Stock
15.00	-	0.50	Uncoated	#17-225	£60.00 Volume Pricing	14 In Stock
15.00	-	1.00	Uncoated	#17-226	£60.00 Volume Pricing	20+ In Stock
15.00	-	2.00	Uncoated	#43-367	£58.00 Volume Pricing	20+ In Stock
15.00	-	0.50	MgF ₂ (400-700nm)	#20-642	£74.00 Volume Pricing	5 In Stock
15.00	-	1.00	MgF ₂ (400-700nm)	#20-647	£74.00 Volume Pricing	3 In Stock
15.00	-	2.00	MgF ₂ (400-700nm)	#36-206	£74.00 Volume Pricing	6 In Stock

15.00	-	0.50	VIS-EXT (350-700nm)	#28-561	£78.00 Volume Pricing	5 In Stock
15.00	-	1.00	VIS-EXT (350-700nm)	#28-562	£78.00 Volume Pricing	2 In Stock
15.00	-	2.00	VIS-EXT (350-700nm)	#28-563	£78.00 Volume Pricing	Contact Us
15.00	-	0.50	VIS-NIR (400-1000nm)	#20-792	£78.00 Volume Pricing	9 In Stock
15.00	-	1.00	VIS-NIR (400-1000nm)	#20-793	£78.00 Volume Pricing	20+ In Stock
15.00	-	2.00	VIS-NIR (400-1000nm)	#36-580	£78.00 Volume Pricing	7 In Stock
15.00	-	0.50	NIR I (600-1050nm)	#20-867	£78.00 Volume Pricing	5 In Stock
15.00	-	1.00	NIR I (600-1050nm)	#20-870	£78.00 Volume Pricing	9 In Stock
15.00	-	2.00	NIR I (600-1050nm)	#36-492	£78.00 Volume Pricing	Contact Us
15.00	-	0.50	NIR II (750-1550nm)	#20-936	£81.00 Volume Pricing	4 In Stock
15.00	-	1.00	NIR II (750-1550nm)	#20-939	£81.00 Volume Pricing	4 In Stock
15.00	-	2.00	NIR II (750-1550nm)	#36-571	£78.00 Volume Pricing	20+ In Stock
15.00	-	0.50	BBAR (1650-3000nm)	#21-003	£93.00 Volume Pricing	6 In Stock
15.00	-	1.00	BBAR (1650-3000nm)	#21-004	£93.00 Volume Pricing	3 In Stock

15.00	-	2.00	BBAR (1650-3000nm)	#15-993	£93.00 Volume Pricing	2 In Stock
15.00	-	0.50	BBAR (2000-5000nm)	#21-020	£93.00 Volume Pricing	5 In Stock
15.00	-	1.00	BBAR (2000-5000nm)	#21-021	£93.00 Volume Pricing	12 In Stock
15.00	-	2.00	BBAR (2000-5000nm)	#16-005	£93.00 Volume Pricing	20+ In Stock
17.25	-	1.00	Uncoated	#71-226	£58.00 Volume Pricing	11 In Stock
17.25	-	2.00	Uncoated	#43-633	£58.00 Volume Pricing	20+ In Stock
20.00	-	0.20	Uncoated	#71-227	£73.00 Volume Pricing	20+ In Stock
20.00	-	0.50	Uncoated	#17-227	£73.00 Volume Pricing	20+ In Stock
20.00	-	1.00	Uncoated	#17-228	£73.00 Volume Pricing	20+ In Stock
20.00	-	2.00	Uncoated	#43-368	£73.00 Volume Pricing	20+ In Stock
20.00	-	3.00	Uncoated	#25-380	£73.00 Volume Pricing	20+ In Stock
20.00	-	0.50	MgF ₂ (400-700nm)	#20-660	£88.00 Volume Pricing	5 In Stock
20.00	-	1.00	MgF ₂ (400-700nm)	#20-663	£88.00 Volume Pricing	1 In Stock
20.00	-	2.00	MgF ₂ (400-700nm)	#36-457	£88.00 Volume Pricing	20+ In Stock
20.00	-	3.00	MgF ₂ (400-700nm)	#25-390	£88.00 Volume Pricing	1 In Stock
20.00	-	0.50	VIS-EXT (350-700nm)	#28-564	£93.00 Volume Pricing	5 In Stock

20.00	-	1.00	VIS-EXT (350-700nm)	#28-565	£93.00 Volume Pricing	4 In Stock
20.00	-	2.00	VIS-EXT (350-700nm)	#28-566	£93.00 Volume Pricing	1 In Stock
20.00	-	3.00	VIS-EXT (350-700nm)	#28-572	£93.00 Volume Pricing	10 In Stock
20.00	-	0.50	VIS-NIR (400-1000nm)	#20-797	£93.00 Volume Pricing	2 In Stock
20.00	-	1.00	VIS-NIR (400-1000nm)	#20-798	£93.00 Volume Pricing	1 In Stock
20.00	-	2.00	VIS-NIR (400-1000nm)	#36-581	£95.00 Volume Pricing	8 In Stock
20.00	-	3.00	VIS-NIR (400-1000nm)	#25-400	£95.00 Volume Pricing	3 In Stock
20.00	-	0.50	NIR I (600-1050nm)	#20-873	£93.00 Volume Pricing	2 In Stock
20.00	-	1.00	NIR I (600-1050nm)	#20-874	£93.00 Volume Pricing	5 In Stock
20.00	-	2.00	NIR I (600-1050nm)	#36-498	£93.00 Volume Pricing	17 In Stock
20.00	-	0.50	NIR II (750-1550nm)	#20-941	£95.00 Volume Pricing	9 In Stock
20.00	-	1.00	NIR II (750-1550nm)	#20-945	£95.00 Volume Pricing	20+ In Stock
20.00	-	2.00	NIR II (750-1550nm)	#36-573	£93.00 Volume Pricing	1 In Stock
20.00	-	3.00	NIR I (600-1050nm)	#25-410	£93.00 Volume Pricing	5 In Stock

20.00	-	3.00	NIR II (750-1550nm)	#25-420	£93.00 Volume Pricing	3 In Stock
20.00	-	0.50	BBAR (1650-3000nm)	#21-005	£107.00 Volume Pricing	6 In Stock
20.00	-	1.00	BBAR (1650-3000nm)	#21-006	£107.00 Volume Pricing	10 In Stock
20.00	-	2.00	BBAR (1650-3000nm)	#15-994	£107.00 Volume Pricing	20+ In Stock
20.00	-	3.00	BBAR (1650-3000nm)	#25-430	£107.00 Volume Pricing	2 In Stock
20.00	-	0.50	BBAR (2000-5000nm)	#21-022	£107.00 Volume Pricing	Contact Us
20.00	-	1.00	BBAR (2000-5000nm)	#21-023	£107.00 Volume Pricing	20+ In Stock
20.00	-	2.00	BBAR (2000-5000nm)	#16-007	£107.00 Volume Pricing	13 In Stock
20.00	-	3.00	BBAR (2000-5000nm)	#25-440	£110.00 Volume Pricing	4 In Stock
22.00	-	1.00	Uncoated	#43-634	£73.00 Volume Pricing	20+ In Stock
23.00	-	1.50	Uncoated	#23-290	£75.00 Volume Pricing	20+ In Stock
23.75	-	1.00	Uncoated	#43-635	£73.00 Volume Pricing	20+ In Stock
25.00	-	0.20	Uncoated	#71-229	£99.00 Volume Pricing	20+ In Stock
25.00	-	0.50	Uncoated	#17-229	£95.00 Volume Pricing	20+ In Stock
25.00	-	1.00	Uncoated	#17-230	£95.00 Volume Pricing	20+ In Stock
25.00	-	2.30	Uncoated	#43-369	£95.00 Volume Pricing	20+ In Stock

25.00	-	0.50	MgF ₂ (400-700nm)	#20-676	£110.00 Volume Pricing	6 In Stock
25.00	-	1.00	MgF ₂ (400-700nm)	#20-681	£110.00 Volume Pricing	3 In Stock
25.00	-	2.30	MgF ₂ (400-700nm)	#36-460	£110.00 Volume Pricing	3 In Stock
25.00	-	0.50	VIS-EXT (350-700nm)	#28-688	£114.00 Volume Pricing	3 In Stock
25.00	-	1.00	VIS-EXT (350-700nm)	#28-689	£114.00 Volume Pricing	14 In Stock
25.00	-	2.30	VIS-EXT (350-700nm)	#28-690	£117.00 Volume Pricing	5 In Stock
25.00	-	0.50	VIS-NIR (400-1000nm)	#20-810	£114.00 Volume Pricing	3 In Stock
25.00	-	1.00	VIS-NIR (400-1000nm)	#20-815	£114.00 Volume Pricing	15 In Stock
25.00	-	2.30	VIS-NIR (400-1000nm)	#36-582	£117.00 Volume Pricing	4 In Stock
25.00	-	0.50	NIR I (600-1050nm)	#20-880	£114.00 Volume Pricing	13 In Stock
25.00	-	1.00	NIR I (600-1050nm)	#20-886	£114.00 Volume Pricing	4 In Stock
25.00	-	2.30	NIR I (600-1050nm)	#36-550	£114.00 Volume Pricing	3 In Stock
25.00	-	0.50	NIR II (750-1550nm)	#20-951	£117.00 Volume Pricing	6 In Stock
25.00	-	1.00	NIR II (750-1550nm)	#20-955	£117.00 Volume Pricing	20+ In Stock

25.00	-	2.30	NIR II (750-1550nm)	#36-576	£114.00 Volume Pricing	20+ In Stock
25.00	-	0.50	BBAR (1650-3000nm)	#21-007	£134.00 Volume Pricing	8 In Stock
25.00	-	1.00	BBAR (1650-3000nm)	#21-008	£134.00 Volume Pricing	13 In Stock
25.00	-	2.30	BBAR (1650-3000nm)	#15-995	£134.00 Volume Pricing	9 In Stock
25.00	-	0.50	BBAR (2000-5000nm)	#21-024	£134.00 Volume Pricing	3 In Stock
25.00	-	1.00	BBAR (2000-5000nm)	#21-060	£134.00 Volume Pricing	11 In Stock
25.00	-	2.30	BBAR (2000-5000nm)	#16-008	£134.00 Volume Pricing	16 In Stock
25.40	-	0.20	Uncoated	#71-230	£99.00 Volume Pricing	20+ In Stock
25.40	-	0.50	Uncoated	#17-231	£95.00 Volume Pricing	20+ In Stock
25.40	-	1.00	Uncoated	#17-232	£95.00 Volume Pricing	20+ In Stock
25.40	-	2.25	Uncoated	#43-636	£95.00 Volume Pricing	20+ In Stock
25.40	-	5.00	Uncoated	#25-381	£95.00 Volume Pricing	17 In Stock
25.40	-	0.50	MgF ₂ (400-700nm)	#20-689	£110.00 Volume Pricing	1 In Stock
25.40	-	1.00	MgF ₂ (400-700nm)	#20-690	£110.00 Volume Pricing	2 In Stock
25.40	-	2.30	MgF ₂ (400-700nm)	#39-233	£110.00 Volume Pricing	5 In Stock
25.40	-	5.00	MgF ₂ (400-700nm)	#25-391	£110.00 Volume Pricing	Contact Us

25.40	-	0.50	VIS-EXT (350-700nm)	#28-691	£117.00 Volume Pricing	1 In Stock
25.40	-	1.00	VIS-EXT (350-700nm)	#28-692	£117.00 Volume Pricing	3 In Stock
25.40	-	2.30	VIS-EXT (350-700nm)	#28-693	£117.00 Volume Pricing	5 In Stock
25.40	-	5.00	VIS-EXT (350-700nm)	#28-694	£117.00 Volume Pricing	10 In Stock
25.40	-	0.50	VIS-NIR (400-1000nm)	#20-834	£114.00 Volume Pricing	Contact Us
25.40	-	1.00	VIS-NIR (400-1000nm)	#20-836	£114.00 Volume Pricing	5 In Stock
25.40	-	2.30	VIS-NIR (400-1000nm)	#39-248	£114.00 Volume Pricing	Contact Us
25.40	-	5.00	VIS-NIR (400-1000nm)	#25-401	£117.00 Volume Pricing	6 In Stock
25.40	-	0.50	NIR I (600-1050nm)	#20-901	£114.00 Volume Pricing	7 In Stock
25.40	-	1.00	NIR I (600-1050nm)	#20-903	£114.00 Volume Pricing	5 In Stock
25.40	-	2.30	NIR I (600-1050nm)	#39-254	£114.00 Volume Pricing	9 In Stock
25.40	-	5.00	NIR I (600-1050nm)	#25-411	£114.00 Volume Pricing	5 In Stock
25.40	-	0.50	NIR II (750-1550nm)	#20-963	£117.00 Volume Pricing	5 In Stock
25.40	-	1.00	NIR II (750-1550nm)	#20-971	£114.00 Volume Pricing	11 In Stock

25.40	-	2.30	NIR II (750-1550nm)	#39-264	£114.00 Volume Pricing	10 In Stock
25.40	-	5.00	NIR II (750-1550nm)	#25-421	£114.00 Volume Pricing	5 In Stock
25.40	-	0.50	BBAR (1650-3000nm)	#21-009	£134.00 Volume Pricing	6 In Stock
25.40	-	1.00	BBAR (1650-3000nm)	#21-010	£134.00 Volume Pricing	13 In Stock
25.40	-	2.30	BBAR (1650-3000nm)	#15-996	£134.00 Volume Pricing	Contact Us
25.40	-	5.00	BBAR (1650-3000nm)	#25-431	£134.00 Volume Pricing	Contact Us
25.40	-	0.50	BBAR (2000-5000nm)	#21-061	£134.00 Volume Pricing	9 In Stock
25.40	-	1.00	BBAR (2000-5000nm)	#21-062	£139.00 Volume Pricing	16 In Stock
25.40	-	2.30	BBAR (2000-5000nm)	#16-009	£134.00 Volume Pricing	3 In Stock
25.40	-	5.00	BBAR (2000-5000nm)	#25-441	£134.00 Volume Pricing	Contact Us
-	25.40 x 25.40	1.00	Uncoated	#39-230	£111.00 Volume Pricing	20+ In Stock
28.00	-	1.50	Uncoated	#23-291	£129.00 Volume Pricing	20+ In Stock
30.00	-	0.50	Uncoated	#71-231	£124.00 Volume Pricing	16 In Stock
30.00	-	1.00	Uncoated	#48-919	£126.00 Volume Pricing	20+ In Stock
30.00	-	2.00	Uncoated	#25-382	£126.00 Volume Pricing	20+ In Stock
30.00	-	1.00	MgF ₂ (400-700nm)	#39-234	£146.00 Volume Pricing	Contact Us

30.00	-	2.00	MgF ₂ (400-700nm)	#25-392	£146.00 Volume Pricing	Contact Us
30.00	-	1.00	VIS-EXT (350-700nm)	#28-695	£171.00 Volume Pricing	Contact Us
30.00	-	2.00	VIS-EXT (350-700nm)	#28-696	£171.00 Volume Pricing	11 In Stock
30.00	-	1.00	VIS-NIR (400-1000nm)	#37-702	£171.00 Volume Pricing	9 In Stock
30.00	-	2.00	VIS-NIR (400-1000nm)	#25-402	£171.00 Volume Pricing	Contact Us
30.00	-	1.00	NIR I (600-1050nm)	#39-256	£167.00 Volume Pricing	10 In Stock
30.00	-	2.00	NIR I (600-1050nm)	#25-412	£167.00 Volume Pricing	1 In Stock
30.00	-	1.00	NIR II (750-1550nm)	#39-265	£166.00 Volume Pricing	20+ In Stock
30.00	-	2.00	NIR II (750-1550nm)	#25-422	£167.00 Volume Pricing	2 In Stock
30.00	-	1.00	BBAR (1650-3000nm)	#15-997	£180.00 Volume Pricing	13 In Stock
30.00	-	2.00	BBAR (1650-3000nm)	#25-432	£180.00 Volume Pricing	5 In Stock
30.00	-	1.00	BBAR (2000-5000nm)	#16-010	£180.00 Volume Pricing	20+ In Stock
30.00	-	2.00	BBAR (2000-5000nm)	#25-442	£180.00 Volume Pricing	2 In Stock
31.60	-	1.50	Uncoated	#23-292	£129.00 Volume Pricing	20+ In Stock
31.75	-	1.00	Uncoated	#43-637	£126.00 Volume Pricing	15 In Stock

31.75	-	1.00	MgF ₂ (400-700nm)	#39-236	£146.00 Volume Pricing	20+ In Stock
31.75	-	1.00	VIS-EXT (350-700nm)	#28-697	£171.00 Volume Pricing	8 In Stock
31.75	-	1.00	VIS-NIR (400-1000nm)	#39-249	£167.00 Volume Pricing	4 In Stock
31.75	-	1.00	NIR I (600-1050nm)	#39-257	£167.00 Volume Pricing	20+ In Stock
31.75	-	1.00	NIR II (750-1550nm)	#39-266	£166.00 Volume Pricing	7 In Stock
35.00	-	1.00	Uncoated	#48-920	£199.00 Volume Pricing	20+ In Stock
35.00	-	2.20	Uncoated	#23-293	£199.00 Volume Pricing	12 In Stock
35.00	-	1.00	MgF ₂ (400-700nm)	#39-238	£219.00 Volume Pricing	5 In Stock
35.00	-	1.00	VIS-EXT (350-700nm)	#28-698	£247.00 Volume Pricing	1 In Stock
35.00	-	1.00	VIS-NIR (400-1000nm)	#39-250	£240.00 Volume Pricing	20+ In Stock
35.00	-	1.00	NIR I (600-1050nm)	#39-258	£240.00 Volume Pricing	8 In Stock
35.00	-	1.00	NIR II (750-1550nm)	#39-267	£246.00 Volume Pricing	3 In Stock
38.00	-	1.50	Uncoated	#23-294	£227.00 Volume Pricing	20+ In Stock
38.10	-	1.00	Uncoated	#45-568	£227.00 Volume Pricing	20+ In Stock
38.10	-	1.00	MgF ₂ (400-700nm)	#39-242	£253.00 Volume Pricing	Contact Us

38.10	-	1.00	VIS-EXT (350-700nm)	#28-699	£269.00 Volume Pricing	4 In Stock
38.10	-	1.00	VIS-NIR (400-1000nm)	#39-251	£269.00 Volume Pricing	13 In Stock
38.10	-	1.00	NIR I (600-1050nm)	#39-259	£269.00 Volume Pricing	3 In Stock
38.10	-	1.00	NIR II (750-1550nm)	#39-268	£277.00 Volume Pricing	5 In Stock
40.00	-	1.00	Uncoated	#25-383	£251.00 Volume Pricing	20+ In Stock
40.00	-	2.00	Uncoated	#48-921	£251.00 Volume Pricing	20+ In Stock
40.00	-	1.00	MgF ₂ (400-700nm)	#25-393	£277.00 Volume Pricing	3 In Stock
40.00	-	2.00	MgF ₂ (400-700nm)	#39-243	£277.00 Volume Pricing	4 In Stock
40.00	-	2.00	VIS-EXT (350-700nm)	#28-703	£296.00 Volume Pricing	16 In Stock
40.00	-	1.00	VIS-EXT (350-700nm)	#28-702	£296.00 Volume Pricing	3 In Stock
40.00	-	1.00	VIS-NIR (400-1000nm)	#25-403	£304.00 Volume Pricing	16 In Stock
40.00	-	2.00	VIS-NIR (400-1000nm)	#37-703	£304.00 Volume Pricing	12 In Stock
40.00	-	1.00	NIR I (600-1050nm)	#25-413	£296.00 Volume Pricing	5 In Stock
40.00	-	2.00	NIR I (600-1050nm)	#39-260	£296.00 Volume Pricing	20+ In Stock
40.00	-	1.00	NIR II (750-1550nm)	#25-423	£296.00 Volume Pricing	4 In Stock

40.00	-	2.00	NIR II (750-1550nm)	#39-269	£304.00 Volume Pricing	5 In Stock
40.00	-	1.00	BBAR (1650-3000nm)	#25-433	£310.00 Volume Pricing	4 In Stock
40.00	-	2.00	BBAR (1650-3000nm)	#15-998	£310.00 Volume Pricing	3 In Stock
40.00	-	1.00	BBAR (2000-5000nm)	#25-443	£310.00 Volume Pricing	5 In Stock
40.00	-	2.00	BBAR (2000-5000nm)	#16-011	£310.00 Volume Pricing	9 In Stock
40.20	-	1.50	Uncoated	#23-295	£251.00 Volume Pricing	20+ In Stock
43.20	-	1.50	Uncoated	#23-296	£282.00 Volume Pricing	Contact Us
50.00	-	1.00	Uncoated	#25-384	£374.00 Volume Pricing	14 In Stock
50.00	-	1.00	MgF ₂ (400-700nm)	#25-394	£407.00 Volume Pricing	Contact Us
50.00	-	1.00	VIS-EXT (350-700nm)	#28-704	£419.00 Volume Pricing	5 In Stock
50.00	-	1.00	VIS-NIR (400-1000nm)	#25-404	£429.00 Volume Pricing	1 In Stock
50.00	-	1.00	NIR I (600-1050nm)	#25-414	£419.00 Volume Pricing	3 In Stock
50.00	-	1.00	NIR II (750-1550nm)	#25-424	£419.00 Volume Pricing	2 In Stock
50.00	-	1.00	BBAR (1650-3000nm)	#25-434	£442.00 Volume Pricing	4 In Stock
50.00	-	1.00	BBAR (2000-5000nm)	#25-444	£442.00 Volume Pricing	1 In Stock

50.80	-	0.50	Uncoated	#71-233	£385.00 Volume Pricing	8 In Stock
50.80	-	1.00	Uncoated	#25-385	£374.00 Volume Pricing	20+ In Stock
50.80	-	3.18	Uncoated	#45-817	£374.00 Volume Pricing	20+ In Stock
50.80	-	1.00	MgF ₂ (400-700nm)	#25-395	£407.00 Volume Pricing	Contact Us
50.80	-	3.18	MgF ₂ (400-700nm)	#39-245	£407.00 Volume Pricing	6 In Stock
50.80	-	3.18	VIS-EXT (350-700nm)	#28-706	£419.00 Volume Pricing	9 In Stock
50.80	-	1.00	VIS-EXT (350-700nm)	#28-705	£419.00 Volume Pricing	20+ In Stock
50.80	-	1.00	VIS-NIR (400-1000nm)	#25-405	£429.00 Volume Pricing	8 In Stock
50.80	-	3.18	VIS-NIR (400-1000nm)	#37-704	£429.00 Volume Pricing	8 In Stock
50.80	-	1.00	NIR I (600-1050nm)	#25-415	£419.00 Volume Pricing	4 In Stock
50.80	-	3.18	NIR I (600-1050nm)	#39-261	£419.00 Volume Pricing	11 In Stock
50.80	-	1.00	NIR II (750-1550nm)	#25-425	£419.00 Volume Pricing	4 In Stock
50.80	-	3.18	NIR II (750-1550nm)	#39-270	£429.00 Volume Pricing	8 In Stock
50.80	-	1.00	BBAR (1650-3000nm)	#25-435	£442.00 Volume Pricing	5 In Stock
50.80	-	3.18	BBAR (1650-3000nm)	#15-999	£446.00 Volume Pricing	7 In Stock

50.80	-	1.00	BBAR (2000-5000nm)	#25-445	£442.00 Volume Pricing	1 In Stock
50.80	-	3.18	BBAR (2000-5000nm)	#16-013	£442.00 Volume Pricing	Contact Us
55.00	-	2.00	Uncoated	#23-297	£434.00 Volume Pricing	20+ In Stock
59.20	-	1.50	Uncoated	#23-298	£480.00 Volume Pricing	20+ In Stock
63.50	-	2.00	Uncoated	#48-922	£510.00 Volume Pricing	20+ In Stock
75.00	-	1.00	Uncoated	#71-234	£790.00 Volume Pricing	5 In Stock
75.00	-	2.00	Uncoated	#47-542	£790.00 Volume Pricing	20+ In Stock
75.00	-	2.00	MgF ₂ (400-700nm)	#18-947	£855.00 Volume Pricing	4 In Stock
75.00	-	2.00	VIS-EXT (350-700nm)	#28-707	£875.00 Volume Pricing	2 In Stock
75.00	-	2.00	VIS-NIR (400-1000nm)	#18-948	£875.00 Volume Pricing	20+ In Stock
75.00	-	2.00	NIR I (600-1050nm)	#18-949	£875.00 Volume Pricing	2 In Stock
75.00	-	2.00	NIR II (750-1550nm)	#18-950	£875.00 Volume Pricing	9 In Stock
75.00	-	2.00	BBAR (1650-3000nm)	#18-951	£900.00 Volume Pricing	4 In Stock
75.00	-	2.00	BBAR (2000-5000nm)	#18-952	£900.00 Volume Pricing	1 In Stock
100.00	-	2.00	Uncoated	#17-233	£1,120.00 Volume Pricing	2 In Stock
100.00	-	2.00	VIS-NIR (400-1000nm)	#24-172	£1,345.00 Volume Pricing	3 In Stock

125.00	-	2.00	Uncoated	#19-507	£1,390.00 Volume Pricing	5 In Stock
125.00	-	2.00	VIS-NIR (400-1000nm)	#24-173	£1,705.00 Volume Pricing	8 In Stock
150.00	-	3.00	Uncoated	#19-508	£1,820.00 Volume Pricing	7 In Stock
150.00	-	3.00	VIS-NIR (400-1000nm)	#24-174	£2,210.00 Volume Pricing	1 In Stock

[#75-137 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	5 x 5	1.00	Uncoated		£30.20 Volume Pricing	1 In Stock
---	-------	------	----------	--	--	------------

[#75-141 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

- 10 x 10 1.00 Uncoated

£47.60
[Volume Pricing](#)

11 In Stock

[#75-142 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

- 20 x 20 2.00 Uncoated

£81.60
[Volume Pricing](#)

1 In Stock

[#75-143 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	25 x 25	2.30	Uncoated		£106.40 Volume Pricing	15 In Stock
---	---------	------	----------	--	---	-------------

[#75-144 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	50 x 50	3.18	Uncoated		£420.00 Volume Pricing	Contact Us
---	---------	------	----------	--	---	------------

[#75-146 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

- 75 x 75 2.00 Uncoated

£884.00
[Volume Pricing](#)

14 In Stock

[#75-147 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

- 12.5 x 17.5 1.00 Uncoated

£65.60
[Volume Pricing](#)

15 In Stock

[#75-148 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

- 25 x 35 2.00 Uncoated

£140.80
[Volume Pricing](#)

4 In Stock

[#75-149 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

- 35 x 50 2.00 Uncoated

£281.60
[Volume Pricing](#)

Contact Us

[#75-151 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	5 x 5	1.00	VIS-NIR (400-1000nm)	£57.20 Volume Pricing	9 In Stock
---	-------	------	-------------------------	--	------------

[#75-157 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	10 x 10	1.00	VIS-NIR (400-1000nm)	£64.80 Volume Pricing	7 In Stock
---	---------	------	-------------------------	--	------------

[#75-160 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	20 x 20	2.00	VIS-NIR (400-1000nm)	£98.40 Volume Pricing	8 In Stock
---	---------	------	-------------------------	--	------------

[#75-164 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	25 x 25	2.30	VIS-NIR (400-1000nm)	£106.40 Volume Pricing	6 In Stock
---	---------	------	-------------------------	---	------------

[#75-166 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	50 x 50	3.18	VIS-NIR (400-1000nm)	£472.00 Volume Pricing	9 In Stock
---	---------	------	-------------------------	--	------------

[#75-167 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	75 x 75	2.00	VIS-NIR (400-1000nm)	£984.00 Volume Pricing	5 In Stock
---	---------	------	-------------------------	--	------------

[#75-168 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	12.5 x 17.5	1.00	VIS-NIR (400- 1000nm)	£88.00 Volume Pricing	9 In Stock
---	-------------	------	-----------------------------	--	------------

[#75-169 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	25 x 35	2.00	VIS-NIR (400- 1000nm)	£186.40 Volume Pricing	9 In Stock
---	---------	------	-----------------------------	---	------------

[#75-170 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	35 x 50	2.00	VIS-NIR (400- 1000nm)	£332.80 Volume Pricing	9 In Stock
---	---------	------	-----------------------------	---	------------

[#75-171 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	5 x 5	1.00	NIR I (600- 1050nm)	£57.20 Volume Pricing	9 In Stock
---	-------	------	---------------------------	--	------------

[#75-172 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	10 x 10	1.00	NIR I (600-1050nm)	£64.80 Volume Pricing	9 In Stock
---	---------	------	-----------------------	--	------------

[#75-175 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	20 x 20	2.00	NIR I (600-1050nm)	£98.40 Volume Pricing	9 In Stock
---	---------	------	-----------------------	--	------------

[#75-177 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	25 x 25	2.30	NIR I (600-1050nm)	£106.40 Volume Pricing	8 In Stock
---	---------	------	-----------------------	--	------------

[#75-181 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	50 x 50	3.18	NIR I (600-1050nm)	£472.00 Volume Pricing	9 In Stock
---	---------	------	-----------------------	--	------------

[#75-183 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	75 x 75	2.00	NIR I (600-1050nm)	£984.00 Volume Pricing	5 In Stock
---	---------	------	-----------------------	--	------------

[#75-184 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	12.5 x 17.5	1.00	NIR I (600-1050nm)	£88.00 Volume Pricing	9 In Stock
---	-------------	------	-----------------------	---	------------

[#75-185 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

- 25 x 35 2.00 NIR I
(600-
1050nm)

£186.40
[Volume Pricing](#)

9 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 : [#75-188 New](#)
www.edmundoptics.com



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

- 35 x 50 2.00 NIR I
(600-
1050nm)

£332.80
[Volume Pricing](#)

9 In Stock