


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [Visible Windows](#)

High Efficiency Anti-Reflection (HEAR) Coated Windows

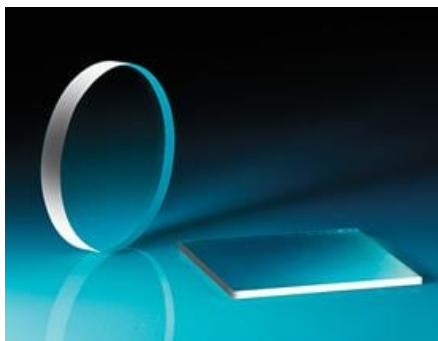

- High Transmission
- Eliminate Back Reflections and Reduce Glare
- Available in a Wide Range of Sizes

Common Specifications


Physical & Mechanical Properties

Bevel:	Protective as needed	Clear Aperture (%):	≥90
---------------	----------------------	----------------------------	-----



Optical Properties

Angle of Incidence (°):	0	Coating:	BBAR (425-700nm)
Coating Specification:	$R_{avg} \leq 0.5\% @ 425 - 700nm$	Substrate:	Float Glass
Surface Quality:	80-50	Wavelength Range (nm):	425 - 700

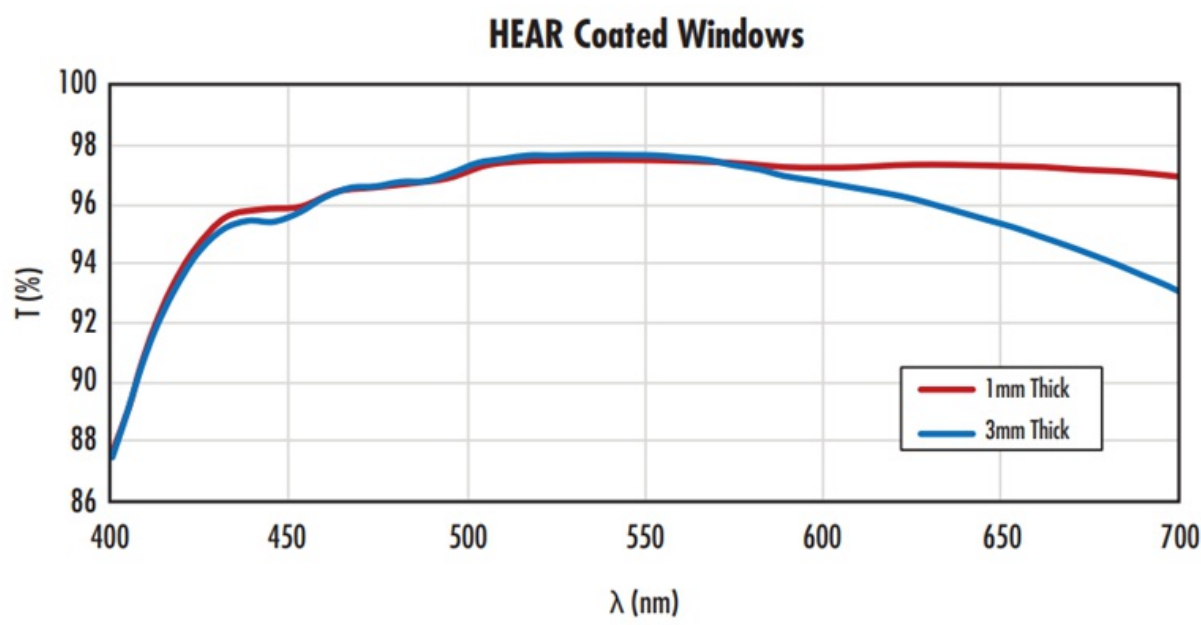Technical Information



Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
#71-564 New						
						
New						
Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!						
5.00	-	1.00	BBAR (425-700nm)		£17.51 Volume Pricing	20+ In Stock
#71-565 New						
						
New						
Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!						
5.00	-	3.00	BBAR (425-700nm)		£17.51 Volume Pricing	20+ In Stock

[#71-566 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

10.00

-

1.00

BBAR
(425-
700nm)

£18.83
[Volume Pricing](#)

20+ In Stock

[#71-567 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

10.00

-

3.00

BBAR
(425-
700nm)

£18.83
[Volume Pricing](#)

20+ In Stock

12.50

-

1.00

BBAR
(425-
700nm)

[#21-324](#)

£19.48
[Volume Pricing](#)

20+ In Stock

12.70

-

1.00

BBAR
(425-
700nm)

[#39-279](#)

£19.48
[Volume Pricing](#)

20+ In Stock

12.70	-	2.00	BBAR (425-700nm)	#71-590	£19.48 Volume Pricing	20+ In Stock
-------	---	------	---------------------	-------------------------	--	--------------

12.70	-	3.00	BBAR (425-700nm)	#39-283	£19.48 Volume Pricing	20+ In Stock
-------	---	------	---------------------	-------------------------	--	--------------

[#71-582 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	12.70 x 12.70	1.00	BBAR (425-700nm)		£19.70 Volume Pricing	20+ In Stock
---	---------------	------	---------------------	--	--	--------------

[#71-583 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	12.70 x 12.70	3.00	BBAR (425-700nm)		£19.70 Volume Pricing	20+ In Stock
---	---------------	------	---------------------	--	--	--------------

[#71-568 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

15.00

-

1.00

BBAR
(425-700nm)

£19.48
[Volume Pricing](#)

20+ In Stock

[#71-569 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

15.00

-

3.00

BBAR
(425-700nm)

£19.48
[Volume Pricing](#)

20+ In Stock

[#71-570 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

20.00

-

1.00

BBAR
(425-
700nm)

£19.48
[Volume Pricing](#)

14 In Stock

[#71-571 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

20.00

-

3.00

BBAR
(425-
700nm)

£19.48
[Volume Pricing](#)

20+ In Stock

25.00

-

1.00

BBAR
(425-
700nm)

[#21-325](#)

£19.48
[Volume Pricing](#)

20+ In Stock

25.40

-

1.00

BBAR
(425-
700nm)

[#48-924](#)

£19.48
[Volume Pricing](#)

20+ In Stock

-

25.40 x 25.40

1.00

BBAR
(425-
700nm)

[#48-923](#)

£19.48
[Volume Pricing](#)

20+ In Stock

25.40	-	2.00	BBAR (425-700nm)	#71-591	£19.48 Volume Pricing	Contact Us
25.40	-	3.00	BBAR (425-700nm)	#46-098	£19.48 Volume Pricing	11 In Stock
-	25.40 x 25.40	3.00	BBAR (425-700nm)	#46-097	£19.48 Volume Pricing	17 In Stock

[#71-584 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	25.40 x 50.80	1.00	BBAR (425-700nm)		£20.58 Volume Pricing	11 In Stock
---	---------------	------	---------------------	--	--	-------------

[#71-585 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	25.40 x 50.80	3.00	BBAR (425-700nm)		£20.58 Volume Pricing	20+ In Stock
---	---------------	------	---------------------	--	--	--------------

[#71-572 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

30.00	-	1.00	BBAR (425-700nm)	£20.58 Volume Pricing	3 In Stock
-------	---	------	------------------	---	------------

[#71-573 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

30.00	-	3.00	BBAR (425-700nm)	£20.58 Volume Pricing	20+ In Stock
-------	---	------	------------------	---	--------------

[#71-574 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

35.00

-

1.00

BBAR
(425-700nm)

£20.58
[Volume Pricing](#)

20+ In Stock

[#71-575 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

35.00

-

3.00

BBAR
(425-700nm)

£20.58
[Volume Pricing](#)

20+ In Stock

38.10

-

1.00

BBAR
(425-700nm)

[#39-280](#)

£20.57
[Volume Pricing](#)

20+ In Stock

38.10

-

2.00

BBAR
(425-700nm)

[#71-592](#)

£20.57
[Volume Pricing](#)

20+ In Stock

-	50.80 x 50.80	1.00	BBAR (425-700nm)	#48-925	£20.57 Volume Pricing	20+ In Stock
50.80	-	2.00	BBAR (425-700nm)	#71-593	£20.57 Volume Pricing	2 In Stock
-	50.80 x 50.80	2.00	BBAR (425-700nm)	#71-594	£20.57 Volume Pricing	20+ In Stock
50.80	-	3.00	BBAR (425-700nm)	#46-100	£20.57 Volume Pricing	20+ In Stock
-	50.80 x 50.80	3.00	BBAR (425-700nm)	#46-099	£20.57 Volume Pricing	20+ In Stock

[#71-586 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	50.80 x 76.20	1.00	BBAR (425-700nm)		£26.48 Volume Pricing	20+ In Stock
---	---------------	------	---------------------	--	--	--------------

[#71-587 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

-	50.80 x 76.20	3.00	BBAR (425- 700nm)		£26.48 Volume Pricing	Contact Us
63.50	-	1.00	BBAR (425- 700nm)	#39-281	£23.20 Volume Pricing	20+ In Stock
63.50	-	3.00	BBAR (425- 700nm)	#39-285	£23.20 Volume Pricing	Contact Us
75.00	-	3.00	BBAR (425- 700nm)	#21-328	£26.48 Volume Pricing	15 In Stock
76.20	-	1.00	BBAR (425- 700nm)	#48-928	£26.48 Volume Pricing	20+ In Stock
-	76.20 x 76.20	1.00	BBAR (425- 700nm)	#48-927	£26.48 Volume Pricing	20+ In Stock
76.20	-	2.00	BBAR (425- 700nm)	#71-595	£26.48 Volume Pricing	3 In Stock
-	76.20 x 76.20	2.00	BBAR (425- 700nm)	#71-596	£26.48 Volume Pricing	20+ In Stock
76.20	-	3.00	BBAR (425- 700nm)	#46-102	£26.48 Volume Pricing	20+ In Stock

-	76.20 x 76.20	3.00	BBAR (425-700nm)	#46-101	£26.48 Volume Pricing	20+ In Stock
88.90	-	1.00	BBAR (425-700nm)	#39-282	£30.43 Volume Pricing	20+ In Stock
88.90	-	3.00	BBAR (425-700nm)	#39-286	£30.43 Volume Pricing	20+ In Stock
101.60	-	1.00	BBAR (425-700nm)	#48-930	£34.58 Volume Pricing	20+ In Stock
-	101.60 x 101.60	1.00	BBAR (425-700nm)	#48-929	£34.58 Volume Pricing	20+ In Stock
101.60	-	2.00	BBAR (425-700nm)	#71-597	£34.58 Volume Pricing	13 In Stock
-	101.60 x 101.60	2.00	BBAR (425-700nm)	#71-598	£34.58 Volume Pricing	14 In Stock
101.60	-	3.00	BBAR (425-700nm)	#46-104	£34.58 Volume Pricing	20+ In Stock
-	101.60 x 101.60	3.00	BBAR (425-700nm)	#46-103	£34.58 Volume Pricing	Contact Us
-	101.60 x 127.00	3.00	BBAR (425-700nm)	#21-329	£37.43 Volume Pricing	20+ In Stock
127.00	-	1.00	BBAR (425-700nm)	#63-216	£44.65 Volume Pricing	20+ In Stock
-	127.00 x 177.80	1.00	BBAR (425-700nm)	#63-217	£44.65 Volume Pricing	20+ In Stock
127.00	-	2.00	BBAR (425-700nm)	#71-599	£44.65 Volume Pricing	20+ In Stock
-	127.00 x 177.80	2.00	BBAR (425-700nm)	#71-600	£44.65 Volume Pricing	Contact Us

127.00	-	3.00	BBAR (425-700nm)	#48-858	£44.65 Volume Pricing	20+ In Stock
-	127.00 x 177.80	3.00	BBAR (425-700nm)	#43-973	£44.65 Volume Pricing	20+ In Stock

[#71-578 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

152.00	-	1.00	BBAR (425-700nm)		£48.15 Volume Pricing	20+ In Stock
--------	---	------	---------------------	--	--	--------------

[#71-579 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

152.00	-	3.00	BBAR (425-700nm)		£48.15 Volume Pricing	9 In Stock
--------	---	------	---------------------	--	--	------------

[#71-580 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

177.00

-

1.00

BBAR
(425-
700nm)

£50.35
[Volume Pricing](#)

20+ In Stock

[#71-581 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

177.00

-

3.00

BBAR
(425-
700nm)

£50.35
[Volume Pricing](#)

20+ In Stock

203.20

-

1.00

BBAR
(425-
700nm)

[#63-218](#)

£54.72
[Volume Pricing](#)

5 In Stock

-

203.20 x
203.20

3.00

BBAR
(425-
700nm)

[#21-330](#)

£54.72
[Volume Pricing](#)

12 In Stock

-	203.20 x 254.00	1.00	BBAR (425- 700nm)	#63-219	£54.72 Volume Pricing	20+ In Stock
203.20	-	3.00	BBAR (425- 700nm)	#48-859	£54.72 Volume Pricing	11 In Stock
-	203.20 x 254.00	3.00	BBAR (425- 700nm)	#43-974	£54.72 Volume Pricing	20+ In Stock
254.00	-	1.00	BBAR (425- 700nm)	#63-220	£79.67 Volume Pricing	11 In Stock
-	254.00 x 254.00	3.00	BBAR (425- 700nm)	#21-331	£79.67 Volume Pricing	6 In Stock
-	254.00 x 304.80	1.00	BBAR (425- 700nm)	#63-221	£79.67 Volume Pricing	1 In Stock
254.00	-	3.00	BBAR (425- 700nm)	#48-860	£79.67 Volume Pricing	20+ In Stock
-	254.00 x 304.80	3.00	BBAR (425- 700nm)	#43-975	£79.67 Volume Pricing	20+ In Stock
-	304.80 x 304.80	3.00	BBAR (425- 700nm)	#21-332	£95.43 Volume Pricing	14 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 :
www.edmundoptics.com