

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Double-Convex \(DCX\) Lenses](#)

TECHSPEC® UV Fused Silica Double-Convex (DCX) Lenses



- Ideal for Imaging Applications
- Minimize Aberrations Including Spherical and Coma
- Precision Fused Silica Substrate

Common Specifications

Physical & Mechanical Properties


Bevel: Protective as needed

Optical Properties


Substrate: [Fused Silica](#) (Corning 7980)

Surface Quality:	40-20	Power (P-V) @ 632.8nm:	1.5λ
Irregularity (P-V) @ 632.8nm:	λ/4	Focal Length Specification Wavelength (nm):	587.6
Focal Length Tolerance (%):	±1		


Technical Information

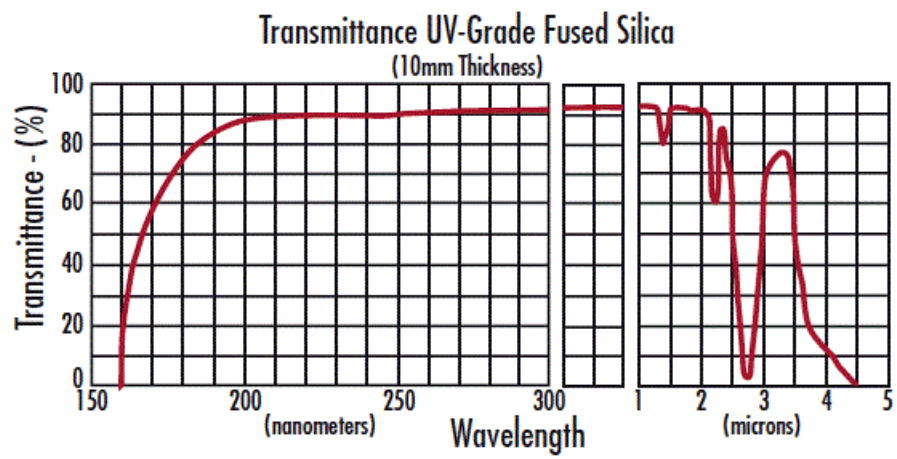


UV FS Transmission Curve

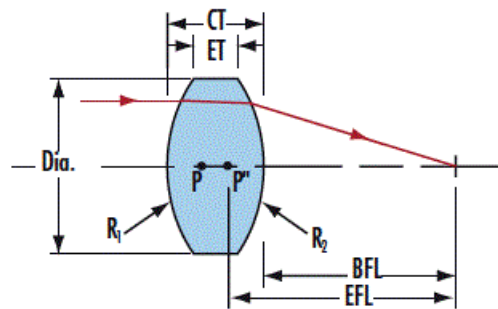

Standard Visible Anti-Reflection Coatings

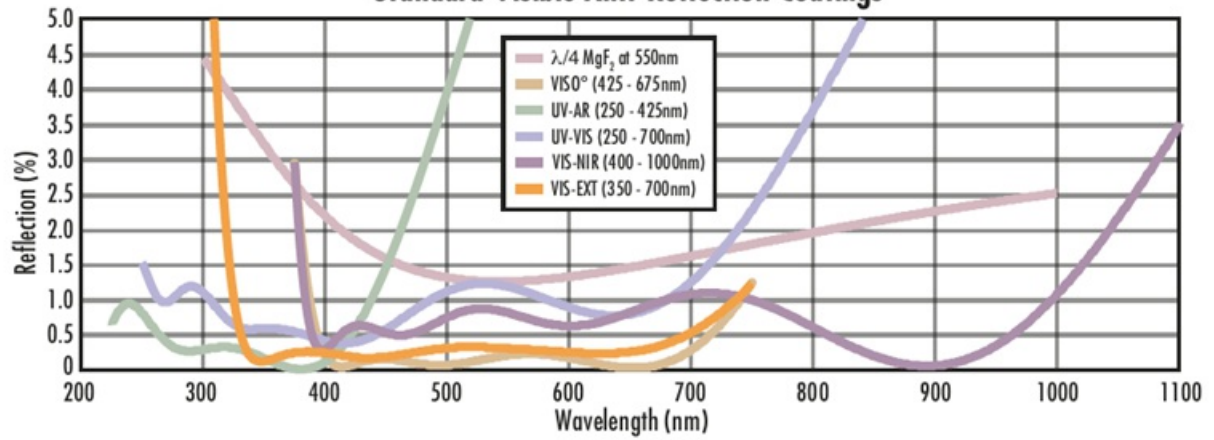

Standard Near Infrared Anti-Reflection Coatings

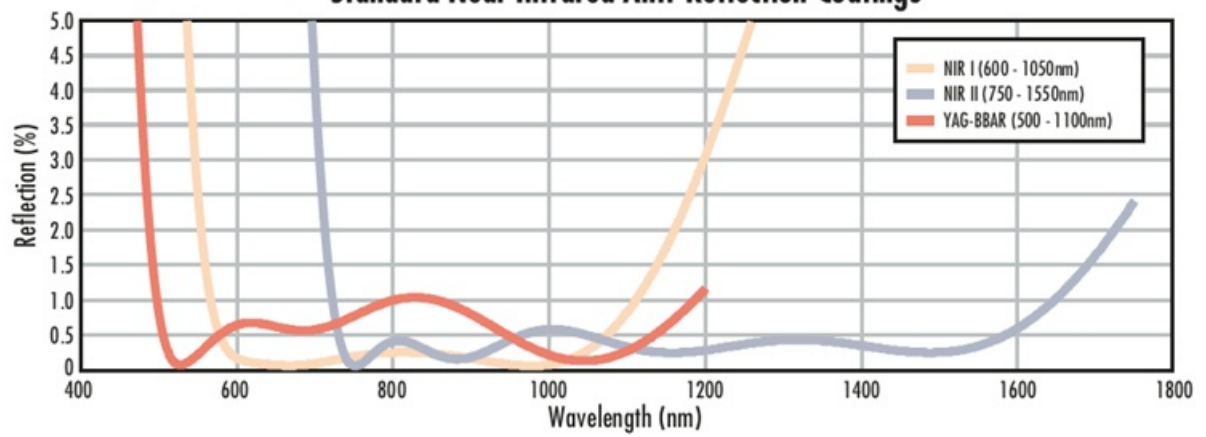

Products

Dia. (mm)	BFL (mm)	EFL (mm)	Coating	Substrate	Stock Number	Price	Buy
6.00	4.38	6.00	Uncoated	Fused Silica	#49-238	£102.43 Volume Pricing	20+ In Stock
6.00	4.38	6.00	UV-AR (250-425nm)	Fused Silica	#49-246	£120.82 Volume Pricing	20+ In Stock
6.00	4.38	6.00	UV-VIS (250-700nm)	Fused Silica	#49-254	£120.82 Volume Pricing	16 In Stock
6.00	4.38	6.00	VIS-EXT (350-700nm)	Fused Silica	#22-196	£120.82 Volume Pricing	8 In Stock
6.00	4.38	6.00	VIS 0° (425-675nm)	Fused Silica	#49-262	£119.07 Volume Pricing	Contact Us
6.00	4.38	6.00	VIS-NIR (400-1000nm)	Fused Silica	#63-817	£120.82 Volume Pricing	13 In Stock
6.00	4.38	6.00	NIR I (600-1050nm)	Fused Silica	#22-156	£119.07 Volume Pricing	7 In Stock
6.00	4.38	6.00	NIR II (750-1550nm)	Fused Silica	#22-176	£119.07 Volume Pricing	2 In Stock
6.00	8.02	9.00	Uncoated	Fused Silica	#49-239	£102.43 Volume Pricing	6 In Stock
6.00	8.02	9.00	UV-AR (250-425nm)	Fused Silica	#49-247	£120.82 Volume Pricing	7 In Stock
6.00	8.02	9.00	UV-VIS (250-700nm)	Fused Silica	#49-255	£120.82 Volume Pricing	20+ In Stock
6.00	8.02	9.00	VIS 0° (425-675nm)	Fused Silica	#49-263	£119.07 Volume Pricing	20+ In Stock
6.00	8.02	9.00	VIS-NIR (400-1000nm)	Fused Silica	#63-818	£120.82 Volume Pricing	12 In Stock
6.00	11.23	12.00	Uncoated	Fused Silica	#49-240	£102.43 Volume Pricing	20+ In Stock

6.00	11.23	12.00	UV-AR (250-425nm)	Fused Silica	#49-248	£120.82 Volume Pricing	1 In Stock
6.00	11.23	12.00	UV-VIS (250-700nm)	Fused Silica	#49-256	£120.82 Volume Pricing	5 In Stock
6.00	11.23	12.00	VIS-EXT (350-700nm)	Fused Silica	#22-195	£120.82 Volume Pricing	3 In Stock
6.00	11.23	12.00	VIS 0° (425-675nm)	Fused Silica	#49-264	£119.07 Volume Pricing	12 In Stock
6.00	11.23	12.00	VIS-NIR (400-1000nm)	Fused Silica	#63-819	£120.82 Volume Pricing	20+ In Stock
6.00	11.23	12.00	NIR I (600-1050nm)	Fused Silica	#22-155	£119.07 Volume Pricing	5 In Stock
6.00	11.23	12.00	NIR II (750-1550nm)	Fused Silica	#22-175	£119.07 Volume Pricing	2 In Stock
6.00	17.30	18.00	Uncoated	Fused Silica	#49-983	£98.06 Volume Pricing	20+ In Stock
6.00	17.30	18.00	UV-AR (250-425nm)	Fused Silica	#49-987	£116.44 Volume Pricing	5 In Stock
6.00	17.30	18.00	UV-VIS (250-700nm)	Fused Silica	#49-991	£116.44 Volume Pricing	8 In Stock
6.00	17.30	18.00	VIS 0° (425-675nm)	Fused Silica	#49-995	£114.69 Volume Pricing	5 In Stock
6.00	17.30	18.00	VIS-NIR (400-1000nm)	Fused Silica	#63-820	£116.44 Volume Pricing	16 In Stock
6.00	23.31	24.00	Uncoated	Fused Silica	#49-984	£98.06 Volume Pricing	20+ In Stock
6.00	23.31	24.00	UV-AR (250-425nm)	Fused Silica	#49-988	£116.44 Volume Pricing	5 In Stock
6.00	23.31	24.00	UV-VIS (250-700nm)	Fused Silica	#49-992	£116.44 Volume Pricing	Contact Us
6.00	23.31	24.00	VIS 0° (425-675nm)	Fused Silica	#49-996	£114.69 Volume Pricing	13 In Stock

6.00	23.31	24.00	VIS-NIR (400-1000nm)	Fused Silica	#63-821	£116.44 Volume Pricing	20+ In Stock
9.00	7.12	9.00	Uncoated	Fused Silica	#49-241	£105.06 Volume Pricing	20+ In Stock
9.00	7.12	9.00	UV-AR (250-425nm)	Fused Silica	#49-249	£123.45 Volume Pricing	20+ In Stock
9.00	7.12	9.00	UV-VIS (250-700nm)	Fused Silica	#49-257	£123.45 Volume Pricing	13 In Stock
9.00	7.12	9.00	VIS-EXT (350-700nm)	Fused Silica	#22-200	£123.45 Volume Pricing	4 In Stock
9.00	7.12	9.00	VIS 0° (425-675nm)	Fused Silica	#49-265	£121.69 Volume Pricing	5 In Stock
9.00	7.12	9.00	VIS-NIR (400-1000nm)	Fused Silica	#63-822	£123.45 Volume Pricing	7 In Stock
9.00	7.12	9.00	NIR I (600-1050nm)	Fused Silica	#22-160	£121.69 Volume Pricing	2 In Stock
9.00	7.12	9.00	NIR II (750-1550nm)	Fused Silica	#22-180	£121.69 Volume Pricing	4 In Stock
9.00	12.32	13.50	Uncoated	Fused Silica	#49-242	£105.06 Volume Pricing	20+ In Stock
9.00	12.32	13.50	UV-AR (250-425nm)	Fused Silica	#49-250	£123.45 Volume Pricing	4 In Stock
9.00	12.32	13.50	UV-VIS (250-700nm)	Fused Silica	#49-258	£123.45 Volume Pricing	1 In Stock
9.00	12.32	13.50	VIS-EXT (350-700nm)	Fused Silica	#22-197	£123.45 Volume Pricing	1 In Stock
9.00	12.32	13.50	VIS 0° (425-675nm)	Fused Silica	#49-266	£121.69 Volume Pricing	5 In Stock
9.00	12.32	13.50	VIS-NIR (400-1000nm)	Fused Silica	#63-823	£123.45 Volume Pricing	20+ In Stock
9.00	12.32	13.50	NIR I (600-1050nm)	Fused Silica	#22-157	£121.69 Volume Pricing	4 In Stock

9.00	12.32	13.50	NIR II (750-1550nm)	Fused Silica	#22-177	£121.69 Volume Pricing	5 In Stock
9.00	17.09	18.00	Uncoated	Fused Silica	#49-243	£105.06 Volume Pricing	20+ In Stock
9.00	17.09	18.00	UV-AR (250-425nm)	Fused Silica	#49-251	£123.45 Volume Pricing	20+ In Stock
9.00	17.09	18.00	UV-VIS (250-700nm)	Fused Silica	#49-259	£123.45 Volume Pricing	Contact Us
9.00	17.09	18.00	VIS-EXT (350-700nm)	Fused Silica	#22-198	£123.45 Volume Pricing	4 In Stock
9.00	17.09	18.00	VIS 0° (425-675nm)	Fused Silica	#49-267	£121.69 Volume Pricing	Contact Us
9.00	17.09	18.00	VIS-NIR (400-1000nm)	Fused Silica	#63-824	£123.45 Volume Pricing	14 In Stock
9.00	17.09	18.00	NIR I (600-1050nm)	Fused Silica	#22-158	£121.69 Volume Pricing	5 In Stock
9.00	17.09	18.00	NIR II (750-1550nm)	Fused Silica	#22-178	£121.69 Volume Pricing	4 In Stock
9.00	26.13	27.00	Uncoated	Fused Silica	#49-985	£100.68 Volume Pricing	20+ In Stock
9.00	26.13	27.00	UV-AR (250-425nm)	Fused Silica	#49-989	£119.07 Volume Pricing	3 In Stock
9.00	26.13	27.00	UV-VIS (250-700nm)	Fused Silica	#49-993	£119.07 Volume Pricing	14 In Stock
9.00	26.13	27.00	VIS-EXT (350-700nm)	Fused Silica	#22-199	£119.07 Volume Pricing	5 In Stock
9.00	26.13	27.00	VIS 0° (425-675nm)	Fused Silica	#49-997	£116.44 Volume Pricing	8 In Stock
9.00	26.13	27.00	VIS-NIR (400-1000nm)	Fused Silica	#63-825	£119.07 Volume Pricing	20+ In Stock
9.00	26.13	27.00	NIR I (600-1050nm)	Fused Silica	#22-159	£116.44 Volume Pricing	5 In Stock

9.00	26.13	27.00	NIR II (750-1550nm)	Fused Silica	#22-179	£116.44 Volume Pricing	5 In Stock
9.00	35.31	36.00	Uncoated	Fused Silica	#49-986	£100.68 Volume Pricing	20+ In Stock
9.00	35.31	36.00	UV-AR (250-425nm)	Fused Silica	#49-990	£119.07 Volume Pricing	1 In Stock
9.00	35.31	36.00	UV-VIS (250-700nm)	Fused Silica	#49-994	£119.07 Volume Pricing	20+ In Stock
9.00	35.31	36.00	VIS 0° (425-675nm)	Fused Silica	#49-998	£116.44 Volume Pricing	8 In Stock
9.00	35.31	36.00	VIS-NIR (400-1000nm)	Fused Silica	#63-826	£119.07 Volume Pricing	20+ In Stock
12.00	9.25	12.00	Uncoated	Fused Silica	#48-034	£105.06 Volume Pricing	20+ In Stock
12.00	9.25	12.00	UV-AR (250-425nm)	Fused Silica	#48-040	£126.07 Volume Pricing	14 In Stock
12.00	9.25	12.00	UV-VIS (250-700nm)	Fused Silica	#48-834	£126.07 Volume Pricing	7 In Stock
12.00	9.25	12.00	VIS-EXT (350-700nm)	Fused Silica	#22-203	£126.07 Volume Pricing	2 In Stock
12.00	9.25	12.00	VIS 0° (425-675nm)	Fused Silica	#48-974	£123.45 Volume Pricing	9 In Stock
12.00	9.25	12.00	VIS-NIR (400-1000nm)	Fused Silica	#63-827	£126.07 Volume Pricing	20+ In Stock
12.00	9.25	12.00	NIR I (600-1050nm)	Fused Silica	#22-163	£123.45 Volume Pricing	3 In Stock
12.00	9.25	12.00	NIR II (750-1550nm)	Fused Silica	#22-183	£123.45 Volume Pricing	7 In Stock
12.00	13.37	15.00	Uncoated	Fused Silica	#49-244	£105.06 Volume Pricing	20+ In Stock
12.00	13.37	15.00	UV-AR (250-425nm)	Fused Silica	#49-252	£126.07 Volume Pricing	5 In Stock

12.00	13.37	15.00	UV-VIS (250-700nm)	Fused Silica	#49-260	£126.07 Volume Pricing	13 In Stock
12.00	13.37	15.00	VIS-EXT (350-700nm)	Fused Silica	#22-204	£126.07 Volume Pricing	14 In Stock
12.00	13.37	15.00	VIS 0° (425-675nm)	Fused Silica	#49-268	£123.45 Volume Pricing	2 In Stock
12.00	13.37	15.00	VIS-NIR (400-1000nm)	Fused Silica	#63-828	£126.07 Volume Pricing	20+ In Stock
12.00	13.37	15.00	NIR I (600-1050nm)	Fused Silica	#22-164	£123.45 Volume Pricing	3 In Stock
12.00	13.37	15.00	NIR II (750-1550nm)	Fused Silica	#22-184	£123.45 Volume Pricing	3 In Stock
12.00	18.44	20.00	Uncoated	Fused Silica	#48-035	£105.06 Volume Pricing	17 In Stock
12.00	18.44	20.00	UV-AR (250-425nm)	Fused Silica	#48-041	£126.07 Volume Pricing	Contact Us
12.00	18.44	20.00	UV-VIS (250-700nm)	Fused Silica	#48-835	£126.07 Volume Pricing	Contact Us
12.00	18.44	20.00	VIS-EXT (350-700nm)	Fused Silica	#22-205	£126.07 Volume Pricing	5 In Stock
12.00	18.44	20.00	VIS 0° (425-675nm)	Fused Silica	#48-975	£123.45 Volume Pricing	15 In Stock
12.00	18.44	20.00	VIS-NIR (400-1000nm)	Fused Silica	#63-829	£126.07 Volume Pricing	20+ In Stock
12.00	18.44	20.00	NIR I (600-1050nm)	Fused Silica	#22-165	£123.45 Volume Pricing	5 In Stock
12.00	18.44	20.00	NIR II (750-1550nm)	Fused Silica	#22-185	£123.45 Volume Pricing	5 In Stock
12.00	22.92	24.00	Uncoated	Fused Silica	#49-245	£105.06 Volume Pricing	20+ In Stock
12.00	22.92	24.00	UV-AR (250-425nm)	Fused Silica	#49-253	£126.07 Volume Pricing	2 In Stock

12.00	22.92	24.00	UV-VIS (250-700nm)	Fused Silica	#49-261	£126.07 Volume Pricing	Contact Us
12.00	22.92	24.00	VIS-EXT (350-700nm)	Fused Silica	#22-206	£126.07 Volume Pricing	5 In Stock
12.00	22.92	24.00	VIS 0° (425-675nm)	Fused Silica	#49-269	£123.45 Volume Pricing	5 In Stock
12.00	22.92	24.00	VIS-NIR (400-1000nm)	Fused Silica	#63-830	£126.07 Volume Pricing	20+ In Stock
12.00	22.92	24.00	NIR I (600-1050nm)	Fused Silica	#22-166	£123.45 Volume Pricing	4 In Stock
12.00	22.92	24.00	NIR II (750-1550nm)	Fused Silica	#22-186	£123.45 Volume Pricing	5 In Stock
12.00	28.77	30.00	Uncoated	Fused Silica	#48-036	£99.81 Volume Pricing	20+ In Stock
12.00	28.77	30.00	UV-AR (250-425nm)	Fused Silica	#48-042	£120.82 Volume Pricing	4 In Stock
12.00	28.77	30.00	UV-VIS (250-700nm)	Fused Silica	#48-836	£120.82 Volume Pricing	6 In Stock
12.00	28.77	30.00	VIS-EXT (350-700nm)	Fused Silica	#22-201	£120.82 Volume Pricing	4 In Stock
12.00	28.77	30.00	VIS 0° (425-675nm)	Fused Silica	#48-976	£118.19 Volume Pricing	8 In Stock
12.00	28.77	30.00	VIS-NIR (400-1000nm)	Fused Silica	#63-831	£120.82 Volume Pricing	12 In Stock
12.00	28.77	30.00	NIR I (600-1050nm)	Fused Silica	#22-161	£118.19 Volume Pricing	4 In Stock
12.00	28.77	30.00	NIR II (750-1550nm)	Fused Silica	#22-181	£118.19 Volume Pricing	5 In Stock
12.00	33.85	35.00	Uncoated	Fused Silica	#48-037	£99.81 Volume Pricing	20+ In Stock
12.00	33.85	35.00	UV-AR (250-425nm)	Fused Silica	#48-043	£120.82 Volume Pricing	Contact Us

12.00	33.85	35.00	UV-VIS (250-700nm)	Fused Silica	#48-837	£120.82 Volume Pricing	Contact Us
12.00	33.85	35.00	VIS-EXT (350-700nm)	Fused Silica	#22-202	£120.82 Volume Pricing	1 In Stock
12.00	33.85	35.00	VIS 0° (425-675nm)	Fused Silica	#48-977	£118.19 Volume Pricing	9 In Stock
12.00	33.85	35.00	VIS-NIR (400-1000nm)	Fused Silica	#63-832	£120.82 Volume Pricing	14 In Stock
12.00	33.85	35.00	NIR I (600-1050nm)	Fused Silica	#22-162	£118.19 Volume Pricing	3 In Stock
12.00	33.85	35.00	NIR II (750-1550nm)	Fused Silica	#22-182	£118.19 Volume Pricing	4 In Stock
12.00	43.96	45.00	Uncoated	Fused Silica	#48-038	£99.81 Volume Pricing	20+ In Stock
12.00	43.96	45.00	UV-AR (250-425nm)	Fused Silica	#48-044	£120.82 Volume Pricing	1 In Stock
12.00	43.96	45.00	UV-VIS (250-700nm)	Fused Silica	#48-838	£120.82 Volume Pricing	Contact Us
12.00	43.96	45.00	VIS 0° (425-675nm)	Fused Silica	#48-978	£118.19 Volume Pricing	1 In Stock
12.00	43.96	45.00	VIS-NIR (400-1000nm)	Fused Silica	#63-833	£120.82 Volume Pricing	20+ In Stock
12.00	74.11	75.00	Uncoated	Fused Silica	#48-039	£99.81 Volume Pricing	7 In Stock
12.00	74.11	75.00	UV-VIS (250-700nm)	Fused Silica	#48-839	£120.82 Volume Pricing	12 In Stock
12.00	74.11	75.00	UV-AR (250-425nm)	Fused Silica	#48-045	£120.82 Volume Pricing	4 In Stock
12.00	74.11	75.00	VIS-EXT (350-700nm)	Fused Silica	#22-207	£120.82 Volume Pricing	2 In Stock
12.00	74.11	75.00	VIS 0° (425-675nm)	Fused Silica	#48-979	£118.19 Volume Pricing	15 In Stock

12.00	74.11	75.00	VIS-NIR (400-1000nm)	Fused Silica	#63-834	£120.82 Volume Pricing	16 In Stock
12.00	74.11	75.00	NIR I (600-1050nm)	Fused Silica	#22-167	£118.19 Volume Pricing	5 In Stock
12.00	74.11	75.00	NIR II (750-1550nm)	Fused Silica	#22-187	£118.19 Volume Pricing	4 In Stock
18.00	17.18	20.00	Uncoated	Fused Silica	#08-083	£112.06 Volume Pricing	20+ In Stock
18.00	17.18	20.00	UV-AR (250-425nm)	Fused Silica	#46-290	£132.20 Volume Pricing	20+ In Stock
18.00	17.18	20.00	UV-VIS (250-700nm)	Fused Silica	#48-840	£132.20 Volume Pricing	1 In Stock
18.00	17.18	20.00	VIS-EXT (350-700nm)	Fused Silica	#22-208	£132.20 Volume Pricing	4 In Stock
18.00	17.18	20.00	VIS 0° (425-675nm)	Fused Silica	#48-980	£130.45 Volume Pricing	14 In Stock
18.00	17.18	20.00	VIS-NIR (400-1000nm)	Fused Silica	#63-835	£132.20 Volume Pricing	7 In Stock
18.00	17.18	20.00	NIR I (600-1050nm)	Fused Silica	#22-168	£130.45 Volume Pricing	3 In Stock
18.00	17.18	20.00	NIR II (750-1550nm)	Fused Silica	#22-188	£130.45 Volume Pricing	5 In Stock
18.00	38.50	40.00	Uncoated	Fused Silica	#08-084	£112.06 Volume Pricing	11 In Stock
18.00	38.50	40.00	UV-AR (250-425nm)	Fused Silica	#46-291	£132.20 Volume Pricing	3 In Stock
18.00	38.50	40.00	UV-VIS (250-700nm)	Fused Silica	#48-841	£132.20 Volume Pricing	Contact Us
18.00	38.50	40.00	VIS-EXT (350-700nm)	Fused Silica	#22-209	£132.20 Volume Pricing	5 In Stock
18.00	38.50	40.00	VIS 0° (425-675nm)	Fused Silica	#48-981	£130.45 Volume Pricing	8 In Stock

18.00	38.50	40.00	VIS-NIR (400-1000nm)	Fused Silica	#63-836	£132.20 Volume Pricing	1 In Stock
18.00	38.50	40.00	NIR I (600-1050nm)	Fused Silica	#22-169	£130.45 Volume Pricing	5 In Stock
18.00	38.50	40.00	NIR II (750-1550nm)	Fused Silica	#22-189	£130.45 Volume Pricing	5 In Stock
25.00	20.93	25.00	Uncoated	Fused Silica	#48-293	£118.19 Volume Pricing	20+ In Stock
25.00	20.93	25.00	UV-AR (250-425nm)	Fused Silica	#48-304	£138.33 Volume Pricing	20+ In Stock
25.00	20.93	25.00	UV-VIS (250-700nm)	Fused Silica	#48-842	£138.33 Volume Pricing	20+ In Stock
25.00	20.93	25.00	VIS-EXT (350-700nm)	Fused Silica	#22-212	£138.33 Volume Pricing	3 In Stock
25.00	20.93	25.00	VIS 0° (425-675nm)	Fused Silica	#48-982	£136.58 Volume Pricing	14 In Stock
25.00	20.93	25.00	VIS-NIR (400-1000nm)	Fused Silica	#63-837	£138.33 Volume Pricing	8 In Stock
25.00	20.93	25.00	NIR I (600-1050nm)	Fused Silica	#22-172	£136.58 Volume Pricing	9 In Stock
25.00	20.93	25.00	NIR II (750-1550nm)	Fused Silica	#22-192	£136.58 Volume Pricing	14 In Stock
25.00	48.02	50.00	Uncoated	Fused Silica	#48-294	£118.19 Volume Pricing	20+ In Stock
25.00	48.02	50.00	UV-AR (250-425nm)	Fused Silica	#48-305	£138.33 Volume Pricing	20+ In Stock
25.00	48.02	50.00	UV-VIS (250-700nm)	Fused Silica	#48-843	£138.33 Volume Pricing	8 In Stock
25.00	48.02	50.00	VIS-EXT (350-700nm)	Fused Silica	#22-213	£138.33 Volume Pricing	5 In Stock
25.00	48.02	50.00	VIS 0° (425-675nm)	Fused Silica	#48-983	£136.58 Volume Pricing	16 In Stock

25.00	48.02	50.00	VIS-NIR (400-1000nm)	Fused Silica	#63-838	£138.33 Volume Pricing	7 In Stock
25.00	48.02	50.00	NIR I (600-1050nm)	Fused Silica	#22-173	£136.58 Volume Pricing	5 In Stock
25.00	48.02	50.00	NIR II (750-1550nm)	Fused Silica	#22-193	£136.58 Volume Pricing	Contact Us
25.00	58.08	60.00	Uncoated	Fused Silica	#48-295	£113.82 Volume Pricing	13 In Stock
25.00	58.08	60.00	UV-AR (250-425nm)	Fused Silica	#48-306	£133.95 Volume Pricing	14 In Stock
25.00	58.08	60.00	UV-VIS (250-700nm)	Fused Silica	#48-844	£133.95 Volume Pricing	4 In Stock
25.00	58.08	60.00	VIS-EXT (350-700nm)	Fused Silica	#22-214	£133.95 Volume Pricing	4 In Stock
25.00	58.08	60.00	VIS 0° (425-675nm)	Fused Silica	#48-984	£132.20 Volume Pricing	4 In Stock
25.00	58.08	60.00	VIS-NIR (400-1000nm)	Fused Silica	#63-839	£133.95 Volume Pricing	12 In Stock
25.00	58.08	60.00	NIR I (600-1050nm)	Fused Silica	#22-174	£132.20 Volume Pricing	4 In Stock
25.00	58.08	60.00	NIR II (750-1550nm)	Fused Silica	#22-194	£132.20 Volume Pricing	4 In Stock
25.00	73.91	75.60	Uncoated	Fused Silica	#48-296	£113.82 Volume Pricing	11 In Stock
25.00	73.91	75.60	UV-AR (250-425nm)	Fused Silica	#48-307	£133.95 Volume Pricing	Contact Us
25.00	73.91	75.60	UV-VIS (250-700nm)	Fused Silica	#48-845	£133.95 Volume Pricing	3 In Stock
25.00	73.91	75.60	VIS-EXT (350-700nm)	Fused Silica	#22-210	£133.95 Volume Pricing	3 In Stock
25.00	73.91	75.60	VIS 0° (425-675nm)	Fused Silica	#48-985	£132.20 Volume Pricing	11 In Stock

25.00	73.91	75.60	VIS-NIR (400-1000nm)	Fused Silica	#63-840	£133.95 Volume Pricing	8 In Stock
25.00	73.91	75.60	NIR I (600-1050nm)	Fused Silica	#22-170	£132.20 Volume Pricing	5 In Stock
25.00	73.91	75.60	NIR II (750-1550nm)	Fused Silica	#22-190	£132.20 Volume Pricing	1 In Stock
25.00	98.70	100.00	Uncoated	Fused Silica	#48-297	£113.82 Volume Pricing	15 In Stock
25.00	98.70	100.00	UV-AR (250-425nm)	Fused Silica	#48-308	£133.95 Volume Pricing	13 In Stock
25.00	98.70	100.00	UV-VIS (250-700nm)	Fused Silica	#48-846	£133.95 Volume Pricing	11 In Stock
25.00	98.70	100.00	VIS-EXT (350-700nm)	Fused Silica	#22-211	£133.95 Volume Pricing	8 In Stock
25.00	98.70	100.00	VIS 0° (425-675nm)	Fused Silica	#48-986	£132.20 Volume Pricing	7 In Stock
25.00	98.70	100.00	VIS-NIR (400-1000nm)	Fused Silica	#63-841	£133.95 Volume Pricing	2 In Stock
25.00	98.70	100.00	NIR I (600-1050nm)	Fused Silica	#22-171	£132.20 Volume Pricing	4 In Stock
25.00	98.70	100.00	NIR II (750-1550nm)	Fused Silica	#22-191	£132.20 Volume Pricing	3 In Stock
25.00	123.82	125.00	Uncoated	Fused Silica	#48-298	£108.56 Volume Pricing	20+ In Stock
25.00	123.82	125.00	UV-AR (250-425nm)	Fused Silica	#48-309	£129.57 Volume Pricing	4 In Stock
25.00	123.82	125.00	UV-VIS (250-700nm)	Fused Silica	#48-847	£129.57 Volume Pricing	10 In Stock
25.00	123.82	125.00	VIS 0° (425-675nm)	Fused Silica	#48-987	£126.95 Volume Pricing	14 In Stock
25.00	123.82	125.00	VIS-NIR (400-1000nm)	Fused Silica	#63-842	£129.57 Volume Pricing	5 In Stock

25.00	148.37	150.00	Uncoated	Fused Silica	#48-299	£108.56 Volume Pricing	20+ In Stock
25.00	148.37	150.00	UV-AR (250-425nm)	Fused Silica	#48-310	£129.57 Volume Pricing	16 In Stock
25.00	148.37	150.00	UV-VIS (250-700nm)	Fused Silica	#48-848	£129.57 Volume Pricing	2 In Stock
25.00	148.37	150.00	VIS 0° (425-675nm)	Fused Silica	#48-988	£126.95 Volume Pricing	7 In Stock
25.00	148.37	150.00	VIS-NIR (400-1000nm)	Fused Silica	#63-843	£129.57 Volume Pricing	4 In Stock
25.00	198.84	200.00	Uncoated	Fused Silica	#48-300	£108.56 Volume Pricing	5 In Stock
25.00	198.84	200.00	UV-AR (250-425nm)	Fused Silica	#48-311	£129.57 Volume Pricing	20+ In Stock
25.00	198.84	200.00	UV-VIS (250-700nm)	Fused Silica	#48-849	£129.57 Volume Pricing	Contact Us
25.00	198.84	200.00	VIS 0° (425-675nm)	Fused Silica	#48-989	£126.95 Volume Pricing	20+ In Stock
25.00	198.84	200.00	VIS-NIR (400-1000nm)	Fused Silica	#63-844	£129.57 Volume Pricing	1 In Stock
25.00	248.90	250.00	Uncoated	Fused Silica	#48-301	£108.56 Volume Pricing	20+ In Stock
25.00	248.90	250.00	UV-AR (250-425nm)	Fused Silica	#48-312	£129.57 Volume Pricing	6 In Stock
25.00	248.90	250.00	UV-VIS (250-700nm)	Fused Silica	#48-850	£129.57 Volume Pricing	Contact Us
25.00	248.90	250.00	VIS 0° (425-675nm)	Fused Silica	#48-990	£126.95 Volume Pricing	5 In Stock
25.00	248.90	250.00	VIS-NIR (400-1000nm)	Fused Silica	#63-845	£129.57 Volume Pricing	5 In Stock
25.00	298.94	300.00	Uncoated	Fused Silica	#48-302	£108.56 Volume Pricing	20+ In Stock

25.00	298.94	300.00	UV-AR (250-425nm)	Fused Silica	#48-313	£129.57 Volume Pricing	14 In Stock
25.00	298.94	300.00	UV-VIS (250-700nm)	Fused Silica	#48-851	£129.57 Volume Pricing	6 In Stock
25.00	298.94	300.00	VIS 0° (425-675nm)	Fused Silica	#48-991	£126.95 Volume Pricing	20+ In Stock
25.00	298.94	300.00	VIS-NIR (400-1000nm)	Fused Silica	#63-846	£129.57 Volume Pricing	4 In Stock
25.00	498.85	500.00	Uncoated	Fused Silica	#48-303	£108.56 Volume Pricing	12 In Stock
25.00	498.85	500.00	UV-AR (250-425nm)	Fused Silica	#48-314	£129.57 Volume Pricing	20+ In Stock
25.00	498.85	500.00	UV-VIS (250-700nm)	Fused Silica	#48-852	£129.57 Volume Pricing	7 In Stock
25.00	498.85	500.00	VIS 0° (425-675nm)	Fused Silica	#48-992	£126.95 Volume Pricing	6 In Stock
25.00	498.85	500.00	VIS-NIR (400-1000nm)	Fused Silica	#63-847	£129.57 Volume Pricing	3 In Stock
30.00	25.12	30.00	Uncoated	Fused Silica	#22-413	£135.70 Volume Pricing	5 In Stock
30.00	25.12	30.00	UV-AR (250-425nm)	Fused Silica	#26-600	£161.97 Volume Pricing	4 In Stock
30.00	25.12	30.00	UV-VIS (250-700nm)	Fused Silica	#26-606	£157.59 Volume Pricing	1 In Stock
30.00	25.12	30.00	VIS 0° (425-675nm)	Fused Silica	#26-612	£161.97 Volume Pricing	2 In Stock
30.00	25.12	30.00	VIS-NIR (400-1000nm)	Fused Silica	#26-618	£161.97 Volume Pricing	1 In Stock
40.00	33.49	40.00	Uncoated	Fused Silica	#22-420	£151.46 Volume Pricing	Contact Us

40.00	33.49	40.00	UV-AR (250-425nm)	Fused Silica	#26-601	£180.35 Volume Pricing	1 In Stock
40.00	33.49	40.00	UV-VIS (250-700nm)	Fused Silica	#26-607	£175.98 Volume Pricing	2 In Stock
40.00	33.49	40.00	VIS 0° (425-675nm)	Fused Silica	#26-613	£180.35 Volume Pricing	5 In Stock
40.00	33.49	40.00	VIS-NIR (400-1000nm)	Fused Silica	#26-619	£180.35 Volume Pricing	4 In Stock
50.00	41.87	50.00	Uncoated	Fused Silica	#22-426	£254.77 Volume Pricing	20+ In Stock
50.00	41.87	50.00	UV-AR (250-425nm)	Fused Silica	#26-602	£281.04 Volume Pricing	Contact Us
50.00	41.87	50.00	UV-VIS (250-700nm)	Fused Silica	#26-608	£276.66 Volume Pricing	Contact Us
50.00	41.87	50.00	VIS 0° (425-675nm)	Fused Silica	#26-614	£281.04 Volume Pricing	5 In Stock
50.00	41.87	50.00	VIS-NIR (400-1000nm)	Fused Silica	#26-620	£281.04 Volume Pricing	1 In Stock
50.00	97.13	100.00	Uncoated	Fused Silica	#22-427	£254.77 Volume Pricing	Contact Us
50.00	97.13	100.00	UV-AR (250-425nm)	Fused Silica	#26-603	£281.04 Volume Pricing	Contact Us
50.00	97.13	100.00	UV-VIS (250-700nm)	Fused Silica	#26-609	£276.66 Volume Pricing	3 In Stock
50.00	97.13	100.00	VIS 0° (425-675nm)	Fused Silica	#26-615	£281.04 Volume Pricing	3 In Stock
50.00	97.13	100.00	VIS-NIR (400-1000nm)	Fused Silica	#26-621	£281.04 Volume Pricing	Contact Us
50.00	148.00	150.00	Uncoated	Fused Silica	#22-428	£254.77 Volume Pricing	10 In Stock

50.00	148.00	150.00	UV-AR (250-425nm)	Fused Silica	#26-604	£281.04 Volume Pricing	3 In Stock
50.00	148.00	150.00	UV-VIS (250-700nm)	Fused Silica	#26-610	£276.66 Volume Pricing	4 In Stock
50.00	148.00	150.00	VIS 0° (425-675nm)	Fused Silica	#26-616	£281.04 Volume Pricing	5 In Stock
50.00	148.00	150.00	VIS-NIR (400-1000nm)	Fused Silica	#26-622	£281.04 Volume Pricing	4 In Stock
50.00	198.39	200.00	Uncoated	Fused Silica	#22-429	£254.77 Volume Pricing	3 In Stock
50.00	198.39	200.00	UV-AR (250-425nm)	Fused Silica	#26-605	£281.04 Volume Pricing	2 In Stock
50.00	198.39	200.00	UV-VIS (250-700nm)	Fused Silica	#26-611	£276.66 Volume Pricing	2 In Stock
50.00	198.39	200.00	VIS 0° (425-675nm)	Fused Silica	#26-617	£281.04 Volume Pricing	5 In Stock
50.00	198.39	200.00	VIS-NIR (400-1000nm)	Fused Silica	#26-623	£281.04 Volume Pricing	1 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 :
www.edmundoptics.com