

[All Products](#) / [Optics](#) / [Prisms](#) / [Image Rotation Prisms](#)**TECHSPEC® Amici Roof Prisms**

- Ray Deviation of 90°
- Right Handed Image
- 6 Arcsecond Resolution
- Roof Surfaces Available Uncoated or Silver Coated


**Common Specifications****Physical & Mechanical Properties**

<b>Dimensional Tolerance (mm):</b>	+0/-0.1	<b>Resolution (arcsec):</b>	6.00
<b>Bevel:</b>	Protective as needed		

**Optical Properties**

<b>Surface Quality:</b>	60-40	<b>Ray Deviation (°):</b>	90
<b>Image Orientation:</b>	Right-Handed	<b>Power (fringes) @ 632.8nm:</b>	3.00
<b>Wavelength Range (nm):</b>	350 - 2200	<b>Irregularity (fringes) @ 632.8nm:</b>	1.00

## Technical Information

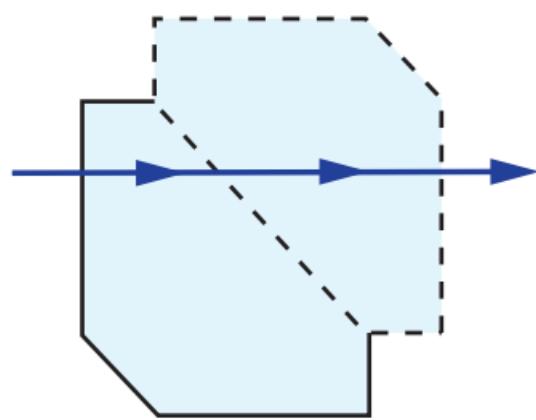

Amici Roof Prism Tunnel Diagram

## Products

Coating	CA (mm)	Wavelength Range (nm)	Stock Number	Price	Buy
Uncoated	8.00	350 - 2200	<a href="#">#45-662</a>	£79.20 <a href="#">Volume Pricing</a>	15 In Stock
Silver with protective overcoat	8.00	350 - 2200	<a href="#">#12-638</a>	£104.80 <a href="#">Volume Pricing</a>	20+ In Stock
Uncoated	13.00	350 - 2200	<a href="#">#45-261</a>	£88.00 <a href="#">Volume Pricing</a>	20+ In Stock
Silver with protective overcoat	13.00	350 - 2200	<a href="#">#12-639</a>	£113.60 <a href="#">Volume Pricing</a>	4 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

[www.edmundoptics.com](http://www.edmundoptics.com)