


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Fresnel Lenses](#)

Conical Groove Plano-Concave (PCV) Fresnel Lenses

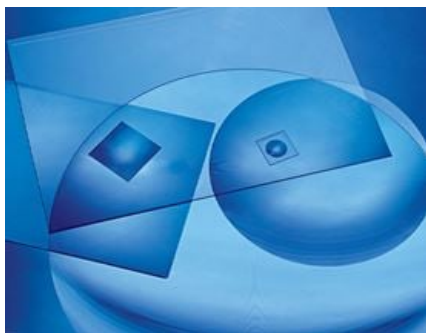

- Negative Focal Length
- Acrylic Substrate
- Square and Rectangular Options

Common Specifications

Physical & Mechanical Properties

Dimensional Tolerance (inches):	±0.05	Thickness Tolerance (%):	±40
---------------------------------	-------	--------------------------	-----


Optical Properties

Substrate:	Acrylic	Coating:	Uncoated
Wavelength Range (nm):	400 - 1100	Index of Refraction (n _d):	1.49
Transmission (%):	85 (Typical)		

Environmental & Durability Factors

Operating Temperature (°C):	≤80
-----------------------------	-----

Technical Information

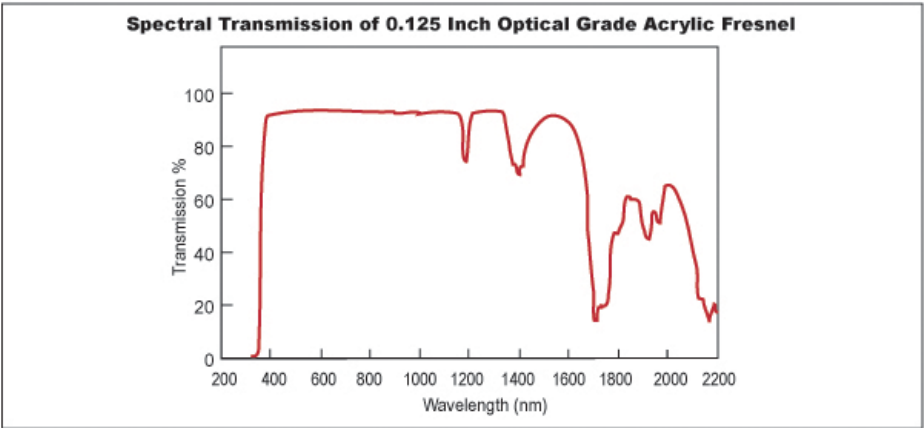

Products

Dimensions (inches)	Dia. (mm)	EFL (inches)	CT (inches)	Groove Density (grooves/inch)	Stock Number	Price	Buy
-	463.55	-18.00	0.11	143.00	#46-397	£347.57 Volume Pricing	3 In Stock
6.7 x 6.7	-	-3.00	0.06	100.00	#46-395	£112.06 Volume Pricing	5 In Stock
2.0 x 2.0	-	-0.85	0.06	200.00	#46-394	£30.20 Volume Pricing	5 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

www.edmundoptics.com