


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Cylinder Lenses](#) / [Illumination Grade Cylinder Lenses](#)

TECHSPEC®

Illumination Grade PCX Cylinder Lenses

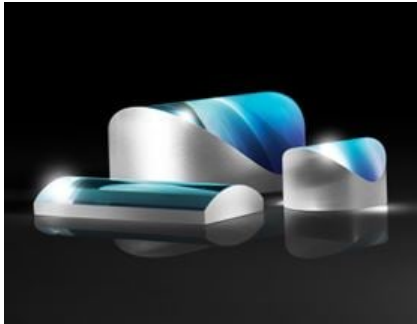

- N-BK7 Substrate for Broadband Performance
- Cost-Effective for OEM Integration
- Multiple Coating Options Available

Common Specifications


Physical & Mechanical Properties

Dimensional Tolerance (mm):	+0.0/-0.2
-----------------------------	-----------

Optical Properties



Focal Length Tolerance (%):	±3
Surface Quality:	60-40

Technical Information

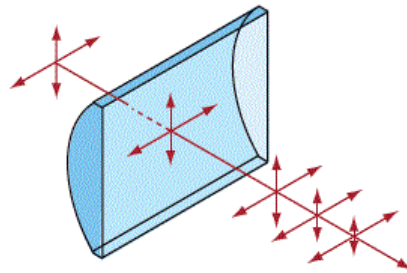

PCX Rectangular

Circular And Rectangular Cylinder Lenses

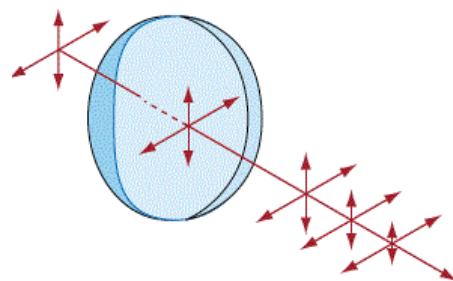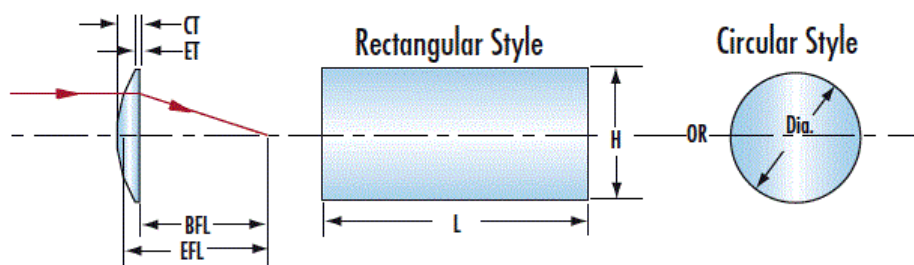

PCX Circular

Products

Dia. (mm)	Dimensions (mm)	EFL (mm)	Substrate	Coating	Stock Number	Price	Buy
5.00	-	8.00	N-BK7	Uncoated	#45-981	£98.06 Volume Pricing	20+ In Stock
5.00	-	8.00	N-BK7	MgF ₂ (400-700nm)	#47-760	£106.81 Volume Pricing	20+ In Stock
#45-982 Clearance							
Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
5.00	-	30.00	N-BK7	Uncoated		£48.11	14 In Stock

[#47-955 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

5.00	-	30.00	N-BK7	VIS-NIR (400-1000nm)		£60.37	14 In Stock
------	---	-------	-----------------------	----------------------	--	--------	-------------

-	5.0 x 10.0	8.00	N-BK7	Uncoated	#43-856	£98.06 Volume Pricing	20+ In Stock
-	5.0 x 10.0	8.00	N-BK7	MgF ₂ (400-700nm)	#47-763	£106.81 Volume Pricing	4 In Stock
-	5.0 x 10.0	20.00	N-BK7	Uncoated	#43-857	£98.06 Volume Pricing	15 In Stock
-	5.0 x 10.0	20.00	N-BK7	MgF ₂ (400-700nm)	#47-764	£106.81 Volume Pricing	4 In Stock
-	5.0 x 10.0	20.00	N-BK7	VIS 0° (425-675nm)	#69-693	£112.94 Volume Pricing	4 In Stock
-	5.0 x 10.0	20.00	N-BK7	VIS-NIR (400-1000nm)	#47-958	£112.94 Volume Pricing	1 In Stock
-	5.0 x 10.0	20.00	N-BK7	NIR I (600-1050nm)	#69-704	£112.94 Volume Pricing	2 In Stock
-	5.0 x 10.0	50.00	N-BK7	Uncoated	#43-859	£98.06 Volume Pricing	10 In Stock
-	5.0 x 10.0	50.00	N-BK7	MgF ₂ (400-700nm)	#47-766	£106.81 Volume Pricing	14 In Stock

-	5.0 x 10.0	50.00	N-BK7	VIS 0° (425-675nm)	#69-695	£112.94 Volume Pricing	20+ In Stock
-	5.0 x 10.0	50.00	N-BK7	VIS-NIR (400-1000nm)	#47-960	£112.94 Volume Pricing	11 In Stock
-	5.0 x 10.0	50.00	N-BK7	NIR I (600-1050nm)	#69-706	£112.94 Volume Pricing	Contact Us
6.00	-	6.00	N-SF11	Uncoated	#68-024	£53.84 Volume Pricing	20+ In Stock
6.00	-	6.00	N-SF11	MgF ₂ (400-700nm)	#68-038	£63.48 Volume Pricing	20+ In Stock
6.00	-	9.00	N-SF11	Uncoated	#68-025	£53.84 Volume Pricing	20+ In Stock
6.00	-	9.00	N-SF11	MgF ₂ (400-700nm)	#68-039	£63.48 Volume Pricing	12 In Stock
6.00	-	12.00	N-BK7	Uncoated	#68-026	£53.84 Volume Pricing	20+ In Stock
6.00	-	12.00	N-BK7	MgF ₂ (400-700nm)	#68-040	£63.48 Volume Pricing	Contact Us
6.00	-	12.00	N-BK7	VIS 0° (425-675nm)	#69-714	£71.79 Volume Pricing	14 In Stock
6.00	-	12.00	N-BK7	VIS-NIR (400-1000nm)	#69-766	£71.79 Volume Pricing	5 In Stock
6.00	-	12.00	N-BK7	NIR I (600-1050nm)	#69-740	£71.79 Volume Pricing	5 In Stock
6.00	-	18.00	N-BK7	Uncoated	#68-027	£53.84 Volume Pricing	13 In Stock
6.00	-	18.00	N-BK7	MgF ₂ (400-700nm)	#68-041	£63.48 Volume Pricing	20+ In Stock
6.00	-	18.00	N-BK7	VIS 0° (425-675nm)	#69-715	£71.79 Volume Pricing	20+ In Stock
6.00	-	18.00	N-BK7	VIS-NIR (400-1000nm)	#69-767	£71.79 Volume Pricing	Contact Us

6.00	-	18.00	N-BK7	NIR I (600-1050nm)	#69-741	£71.79 Volume Pricing	4 In Stock
6.00	-	24.00	N-BK7	Uncoated	#68-028	£53.84 Volume Pricing	20+ In Stock
6.00	-	24.00	N-BK7	MgF ₂ (400-700nm)	#68-042	£63.48 Volume Pricing	4 In Stock
6.00	-	24.00	N-BK7	VIS 0° (425-675nm)	#69-716	£71.79 Volume Pricing	2 In Stock
6.00	-	24.00	N-BK7	VIS-NIR (400-1000nm)	#69-768	£71.79 Volume Pricing	Contact Us
6.00	-	24.00	N-BK7	NIR I (600-1050nm)	#69-742	£71.79 Volume Pricing	20+ In Stock
-	10.0 x 10.0	25.00	N-BK7	VIS 0° (425-675nm)	#25-484	£73.98 Volume Pricing	2 In Stock
-	10.0 x 10.0	25.00	N-BK7	NIR I (600-1050nm)	#25-485	£73.98 Volume Pricing	Contact Us
10.00	-	15.00	N-BK7	Uncoated	#47-754	£107.69 Volume Pricing	4 In Stock
10.00	-	15.00	N-BK7	MgF ₂ (400-700nm)	#47-767	£117.32 Volume Pricing	13 In Stock

[#69-696 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

10.00	-	20.00	N-BK7	VIS 0° (425-675nm)		£60.37	8 In Stock
-------	---	-------	-----------------------	-----------------------	--	--------	------------

10.00	-	30.00	N-BK7	Uncoated	#47-756	£107.69 Volume Pricing	20+ In Stock
-------	---	-------	-----------------------	----------	-------------------------	---	--------------

10.00	-	30.00	N-BK7	MgF ₂ (400-700nm)	#47-769	£117.32 Volume Pricing	5 In Stock
-------	---	-------	-----------------------	---------------------------------	-------------------------	---	------------

10.00	-	30.00	N-BK7	VIS 0° (425-675nm)	#69-697	£123.45 Volume Pricing	1 In Stock
-------	---	-------	-----------------------	-----------------------	-------------------------	---	------------

10.00	-	30.00	N-BK7	VIS-NIR (400-1000nm)	#47-963	£123.45 Volume Pricing	2 In Stock
-------	---	-------	-----------------------	-------------------------	-------------------------	---	------------

10.00	-	30.00	N-BK7	NIR I (600-1050nm)	#69-708	£123.45 Volume Pricing	7 In Stock
-------	---	-------	-----------------------	-----------------------	-------------------------	---	------------

10.00	-	50.00	N-BK7	Uncoated	#47-757	£107.69 Volume Pricing	20+ In Stock
-------	---	-------	-----------------------	----------	-------------------------	---	--------------

10.00	-	50.00	N-BK7	MgF ₂ (400-700nm)	#47-770	£117.32 Volume Pricing	3 In Stock
-------	---	-------	-----------------------	---------------------------------	-------------------------	---	------------

10.00	-	50.00	N-BK7	VIS 0° (425-675nm)	#69-698	£123.45 Volume Pricing	1 In Stock
-------	---	-------	-----------------------	-----------------------	-------------------------	---	------------

10.00	-	50.00	N-BK7	VIS-NIR (400-1000nm)	#47-964	£123.45 Volume Pricing	5 In Stock
-------	---	-------	-----------------------	-------------------------	-------------------------	---	------------

10.00	-	50.00	N-BK7	NIR I (600-1050nm)	#69-709	£123.45 Volume Pricing	Contact Us
-	10.0 x 10.0	25.00	N-BK7	Uncoated	#25-483	£56.03 Volume Pricing	20+ In Stock
-	10.0 x 20.0	25.00	N-BK7	Uncoated	#25-486	£68.72 Volume Pricing	20+ In Stock
-	10.0 x 20.0	25.00	N-BK7	VIS 0° (425-675nm)	#25-487	£86.67 Volume Pricing	2 In Stock
-	10.0 x 20.0	25.00	N-BK7	NIR I (600-1050nm)	#25-488	£86.67 Volume Pricing	5 In Stock

[#47-775 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

12.50	-	12.50	N-BK7	Uncoated	#46-193	£56.03 Volume Pricing	20+ In Stock
12.50	-	12.50	N-BK7	MgF ₂ (400-700nm)	#48-352	£64.35 Volume Pricing	20+ In Stock
12.50	-	25.00	N-BK7	Uncoated	#46-194	£56.03 Volume Pricing	20+ In Stock
12.50	-	25.00	N-BK7	MgF ₂ (400-700nm)	#48-353	£64.35 Volume Pricing	20+ In Stock
12.50	-	25.00	N-BK7	VIS 0° (425-675nm)	#69-717	£73.98 Volume Pricing	20+ In Stock

12.50	-	25.00	N-BK7	VIS-NIR (400-1000nm)	#69-769	£73.98 Volume Pricing	3 In Stock
12.50	-	25.00	N-BK7	NIR I (600-1050nm)	#69-743	£73.98 Volume Pricing	1 In Stock
12.50	-	50.00	N-BK7	Uncoated	#46-195	£56.03 Volume Pricing	20+ In Stock
12.50	-	50.00	N-BK7	MgF ₂ (400-700nm)	#48-354	£64.35 Volume Pricing	20+ In Stock
12.50	-	50.00	N-BK7	VIS 0° (425-675nm)	#69-718	£73.98 Volume Pricing	1 In Stock
12.50	-	50.00	N-BK7	VIS-NIR (400-1000nm)	#69-770	£73.98 Volume Pricing	20+ In Stock
12.50	-	50.00	N-BK7	NIR I (600-1050nm)	#69-744	£73.98 Volume Pricing	Contact Us
12.50	-	75.00	N-BK7	Uncoated	#47-742	£56.03 Volume Pricing	20+ In Stock
12.50	-	75.00	N-BK7	MgF ₂ (400-700nm)	#48-355	£64.35 Volume Pricing	20+ In Stock
12.50	-	75.00	N-BK7	VIS 0° (425-675nm)	#69-719	£73.98 Volume Pricing	15 In Stock
12.50	-	75.00	N-BK7	VIS-NIR (400-1000nm)	#69-771	£73.98 Volume Pricing	Contact Us
12.50	-	75.00	N-BK7	NIR I (600-1050nm)	#69-745	£73.98 Volume Pricing	Contact Us
12.50	-	100.00	N-BK7	Uncoated	#47-743	£56.03 Volume Pricing	20+ In Stock
12.50	-	100.00	N-BK7	MgF ₂ (400-700nm)	#48-356	£64.35 Volume Pricing	20+ In Stock
12.50	-	100.00	N-BK7	VIS 0° (425-675nm)	#69-720	£73.98 Volume Pricing	9 In Stock
-	12.5 x 25.0	12.50	N-SF11	Uncoated	#68-029	£56.03 Volume Pricing	20+ In Stock

-	12.5 x 25.0	12.50	N-SF11	MgF ₂ (400-700nm)	#68-043	£64.35 Volume Pricing	5 In Stock
-	12.5 x 25.0	15.00	N-SF11	Uncoated	#68-030	£56.03 Volume Pricing	14 In Stock
-	12.5 x 25.0	15.00	N-SF11	MgF ₂ (400-700nm)	#68-044	£64.35 Volume Pricing	6 In Stock
-	12.5 x 25.0	20.00	N-BK7	Uncoated	#68-031	£56.03 Volume Pricing	4 In Stock
-	12.5 x 25.0	20.00	N-BK7	MgF ₂ (400-700nm)	#68-045	£64.35 Volume Pricing	1 In Stock
-	12.5 x 25.0	20.00	N-BK7	VIS 0° (425-675nm)	#69-721	£73.98 Volume Pricing	Contact Us
-	12.5 x 25.0	20.00	N-BK7	VIS-NIR (400-1000nm)	#69-773	£73.98 Volume Pricing	4 In Stock
-	12.5 x 25.0	20.00	N-BK7	NIR I (600-1050nm)	#69-747	£73.98 Volume Pricing	4 In Stock
-	12.5 x 25.0	25.00	N-BK7	Uncoated	#68-032	£56.03 Volume Pricing	20+ In Stock
-	12.5 x 25.0	25.00	N-BK7	MgF ₂ (400-700nm)	#68-046	£64.35 Volume Pricing	20+ In Stock
-	12.5 x 25.0	25.00	N-BK7	VIS 0° (425-675nm)	#69-722	£73.98 Volume Pricing	10 In Stock
-	12.5 x 25.0	25.00	N-BK7	VIS-NIR (400-1000nm)	#69-774	£73.98 Volume Pricing	6 In Stock
-	12.5 x 25.0	25.00	N-BK7	NIR I (600-1050nm)	#69-748	£73.98 Volume Pricing	8 In Stock
-	12.5 x 25.0	50.00	N-BK7	Uncoated	#68-033	£56.03 Volume Pricing	20+ In Stock
-	12.5 x 25.0	50.00	N-BK7	MgF ₂ (400-700nm)	#68-047	£64.35 Volume Pricing	5 In Stock
-	12.5 x 25.0	50.00	N-BK7	VIS 0° (425-675nm)	#69-723	£73.98 Volume Pricing	20+ In Stock

-	12.5 x 25.0	50.00	N-BK7	VIS-NIR (400-1000nm)	#69-775	£73.98 Volume Pricing	5 In Stock
-	12.5 x 25.0	50.00	N-BK7	NIR I (600-1050nm)	#69-749	£73.98 Volume Pricing	4 In Stock
-	12.5 x 25.0	75.00	N-BK7	Uncoated	#68-034	£56.03 Volume Pricing	10 In Stock
-	12.5 x 25.0	75.00	N-BK7	MgF ₂ (400-700nm)	#68-048	£64.35 Volume Pricing	8 In Stock
-	12.5 x 25.0	75.00	N-BK7	VIS 0° (425-675nm)	#69-724	£73.98 Volume Pricing	20+ In Stock
-	12.5 x 25.0	75.00	N-BK7	VIS-NIR (400-1000nm)	#69-776	£73.98 Volume Pricing	13 In Stock
-	12.5 x 25.0	75.00	N-BK7	NIR I (600-1050nm)	#69-750	£73.98 Volume Pricing	3 In Stock
-	12.5 x 25.0	100.00	N-BK7	Uncoated	#68-035	£56.03 Volume Pricing	20+ In Stock
-	12.5 x 25.0	100.00	N-BK7	MgF ₂ (400-700nm)	#68-049	£64.35 Volume Pricing	5 In Stock
-	12.5 x 25.0	100.00	N-BK7	VIS 0° (425-675nm)	#69-725	£73.98 Volume Pricing	5 In Stock
-	12.5 x 25.0	100.00	N-BK7	VIS-NIR (400-1000nm)	#69-777	£73.98 Volume Pricing	20+ In Stock
-	12.5 x 25.0	100.00	N-BK7	NIR I (600-1050nm)	#69-751	£73.98 Volume Pricing	3 In Stock
-	12.5 x 25.0	150.00	N-BK7	Uncoated	#68-037	£56.03 Volume Pricing	20+ In Stock
-	12.5 x 25.0	150.00	N-BK7	MgF ₂ (400-700nm)	#68-051	£64.35 Volume Pricing	5 In Stock
-	12.5 x 25.0	150.00	N-BK7	VIS 0° (425-675nm)	#69-726	£73.98 Volume Pricing	Contact Us
-	12.5 x 25.0	150.00	N-BK7	VIS-NIR (400-1000nm)	#69-778	£73.98 Volume Pricing	9 In Stock

-	12.5 x 25.0	150.00	N-BK7	NIR I (600-1050nm)	#69-752	£73.98 Volume Pricing	3 In Stock
-	12.7 x 12.7	12.50	N-BK7	Uncoated	#35-020	£56.03 Volume Pricing	20+ In Stock
-	12.7 x 12.7	12.50	N-BK7	VIS 0° (425-675nm)	#36-208	£73.98 Volume Pricing	Contact Us
-	12.7 x 12.7	12.50	N-BK7	VIS-NIR (400-1000nm)	#36-217	£73.98 Volume Pricing	1 In Stock
-	12.7 x 12.7	12.50	N-BK7	NIR I (600-1050nm)	#36-227	£73.98 Volume Pricing	1 In Stock
-	12.7 x 12.7	25.00	N-BK7	Uncoated	#35-021	£56.03 Volume Pricing	20+ In Stock
-	12.7 x 12.7	25.00	N-BK7	VIS 0° (425-675nm)	#36-209	£73.98 Volume Pricing	2 In Stock
-	12.7 x 12.7	25.00	N-BK7	VIS-NIR (400-1000nm)	#36-218	£73.98 Volume Pricing	Contact Us
-	12.7 x 12.7	25.00	N-BK7	NIR I (600-1050nm)	#36-228	£73.98 Volume Pricing	2 In Stock
-	12.7 x 12.7	100.00	N-BK7	Uncoated	#35-022	£56.03 Volume Pricing	20+ In Stock
-	12.7 x 12.7	100.00	N-BK7	VIS 0° (425-675nm)	#36-210	£73.98 Volume Pricing	2 In Stock
-	12.7 x 12.7	100.00	N-BK7	VIS-NIR (400-1000nm)	#36-219	£73.98 Volume Pricing	20+ In Stock
-	12.7 x 12.7	100.00	N-BK7	NIR I (600-1050nm)	#36-229	£73.98 Volume Pricing	5 In Stock
-	12.7 x 12.7	150.00	N-BK7	Uncoated	#35-023	£56.03 Volume Pricing	20+ In Stock
-	12.7 x 12.7	150.00	N-BK7	VIS 0° (425-675nm)	#36-211	£73.98 Volume Pricing	5 In Stock
-	12.7 x 12.7	150.00	N-BK7	VIS-NIR (400-1000nm)	#36-220	£73.98 Volume Pricing	3 In Stock

-	12.7 x 12.7	150.00	N-BK7	NIR I (600-1050nm)	#36-230	£73.98 Volume Pricing	4 In Stock
-	20.0 x 20.0	25.00	N-BK7	Uncoated	#25-489	£84.05 Volume Pricing	20+ In Stock
-	20.0 x 20.0	25.00	N-BK7	VIS 0° (425-675nm)	#25-490	£101.56 Volume Pricing	5 In Stock
-	20.0 x 20.0	25.00	N-BK7	NIR I (600-1050nm)	#25-491	£101.56 Volume Pricing	5 In Stock
-	20.0 x 20.0	50.00	N-BK7	Uncoated	#25-495	£84.05 Volume Pricing	5 In Stock
-	20.0 x 20.0	50.00	N-BK7	VIS 0° (425-675nm)	#25-496	£101.56 Volume Pricing	5 In Stock
-	20.0 x 20.0	50.00	N-BK7	NIR I (600-1050nm)	#25-497	£101.56 Volume Pricing	5 In Stock
-	20.0 x 40.0	25.00	N-BK7	Uncoated	#25-492	£103.31 Volume Pricing	14 In Stock
-	20.0 x 40.0	25.00	N-BK7	VIS 0° (425-675nm)	#25-493	£121.69 Volume Pricing	5 In Stock
-	20.0 x 40.0	25.00	N-BK7	NIR I (600-1050nm)	#25-494	£121.69 Volume Pricing	4 In Stock
-	20.0 x 40.0	50.00	N-BK7	Uncoated	#25-498	£103.31 Volume Pricing	20+ In Stock
-	20.0 x 40.0	50.00	N-BK7	VIS 0° (425-675nm)	#25-499	£121.69 Volume Pricing	4 In Stock
-	20.0 x 40.0	50.00	N-BK7	NIR I (600-1050nm)	#25-500	£121.69 Volume Pricing	2 In Stock
25.00	-	25.00	N-BK7	Uncoated	#46-015	£63.04 Volume Pricing	20+ In Stock
25.00	-	25.00	N-BK7	MgF ₂ (400-700nm)	#48-357	£71.35 Volume Pricing	16 In Stock
25.00	-	50.00	N-BK7	Uncoated	#46-016	£63.04 Volume Pricing	20+ In Stock
25.00	-	50.00	N-BK7	MgF ₂ (400-700nm)	#48-358	£71.35 Volume Pricing	20+ In Stock

25.00	-	50.00	N-BK7	VIS 0° (425-675nm)	#69-727	£79.23 Volume Pricing	20+ In Stock
25.00	-	50.00	N-BK7	VIS-NIR (400-1000nm)	#69-779	£79.23 Volume Pricing	3 In Stock
25.00	-	50.00	N-BK7	NIR I (600-1050nm)	#69-753	£79.23 Volume Pricing	20+ In Stock
25.00	-	75.00	N-BK7	Uncoated	#46-017	£63.04 Volume Pricing	20+ In Stock
25.00	-	75.00	N-BK7	MgF ₂ (400-700nm)	#48-359	£71.35 Volume Pricing	7 In Stock
25.00	-	75.00	N-BK7	VIS 0° (425-675nm)	#69-728	£79.23 Volume Pricing	5 In Stock
25.00	-	75.00	N-BK7	VIS-NIR (400-1000nm)	#69-780	£71.35 Volume Pricing	1 In Stock
25.00	-	75.00	N-BK7	NIR I (600-1050nm)	#69-754	£79.23 Volume Pricing	2 In Stock
25.00	-	100.00	N-BK7	Uncoated	#46-018	£63.04 Volume Pricing	20+ In Stock
25.00	-	100.00	N-BK7	MgF ₂ (400-700nm)	#48-360	£71.35 Volume Pricing	11 In Stock
25.00	-	100.00	N-BK7	VIS 0° (425-675nm)	#69-729	£79.23 Volume Pricing	6 In Stock
25.00	-	100.00	N-BK7	VIS-NIR (400-1000nm)	#69-781	£79.23 Volume Pricing	Contact Us
25.00	-	100.00	N-BK7	NIR I (600-1050nm)	#69-755	£79.23 Volume Pricing	Contact Us
25.00	-	125.00	N-BK7	Uncoated	#47-744	£63.04 Volume Pricing	20+ In Stock
25.00	-	125.00	N-BK7	MgF ₂ (400-700nm)	#48-361	£71.35 Volume Pricing	8 In Stock
25.00	-	125.00	N-BK7	VIS 0° (425-675nm)	#69-730	£79.23 Volume Pricing	6 In Stock

25.00	-	125.00	N-BK7	VIS-NIR (400-1000nm)	#69-782	£79.23 Volume Pricing	5 In Stock
25.00	-	125.00	N-BK7	NIR I (600-1050nm)	#69-756	£79.23 Volume Pricing	7 In Stock
25.00	-	150.00	N-BK7	Uncoated	#46-019	£63.04 Volume Pricing	20+ In Stock
25.00	-	150.00	N-BK7	MgF ₂ (400-700nm)	#48-362	£71.35 Volume Pricing	20+ In Stock
25.00	-	150.00	N-BK7	VIS 0° (425-675nm)	#69-731	£79.23 Volume Pricing	5 In Stock
25.00	-	150.00	N-BK7	VIS-NIR (400-1000nm)	#69-783	£79.23 Volume Pricing	3 In Stock
25.00	-	150.00	N-BK7	NIR I (600-1050nm)	#69-757	£79.23 Volume Pricing	7 In Stock
-	25.0 x 50.0	25.00	N-BK7	Uncoated	#46-020	£98.93 Volume Pricing	20+ In Stock
-	25.0 x 50.0	25.00	N-BK7	MgF ₂ (400-700nm)	#48-363	£108.56 Volume Pricing	11 In Stock
-	25.0 x 50.0	50.00	N-BK7	Uncoated	#46-021	£98.93 Volume Pricing	20+ In Stock
-	25.0 x 50.0	50.00	N-BK7	MgF ₂ (400-700nm)	#48-364	£108.56 Volume Pricing	20+ In Stock
-	25.0 x 50.0	50.00	N-BK7	VIS 0° (425-675nm)	#69-732	£116.44 Volume Pricing	2 In Stock
-	25.0 x 50.0	50.00	N-BK7	VIS-NIR (400-1000nm)	#69-784	£116.44 Volume Pricing	2 In Stock
-	25.0 x 50.0	50.00	N-BK7	NIR I (600-1050nm)	#69-758	£116.44 Volume Pricing	2 In Stock
-	25.0 x 50.0	75.00	N-BK7	Uncoated	#46-022	£98.93 Volume Pricing	2 In Stock
-	25.0 x 50.0	75.00	N-BK7	MgF ₂ (400-700nm)	#48-365	£108.56 Volume Pricing	1 In Stock

-	25.0 x 50.0	75.00	N-BK7	VIS 0° (425-675nm)	#69-733	£116.44 Volume Pricing	6 In Stock
-	25.0 x 50.0	75.00	N-BK7	VIS-NIR (400-1000nm)	#69-785	£116.44 Volume Pricing	1 In Stock
-	25.0 x 50.0	75.00	N-BK7	NIR I (600-1050nm)	#69-759	£116.44 Volume Pricing	20+ In Stock
-	25.0 x 50.0	100.00	N-BK7	Uncoated	#46-023	£98.93 Volume Pricing	2 In Stock
-	25.0 x 50.0	100.00	N-BK7	MgF ₂ (400-700nm)	#48-366	£108.56 Volume Pricing	3 In Stock
-	25.0 x 50.0	100.00	N-BK7	VIS 0° (425-675nm)	#69-734	£116.44 Volume Pricing	4 In Stock
-	25.0 x 50.0	100.00	N-BK7	VIS-NIR (400-1000nm)	#69-786	£116.44 Volume Pricing	3 In Stock
-	25.0 x 50.0	100.00	N-BK7	NIR I (600-1050nm)	#69-760	£116.44 Volume Pricing	8 In Stock
-	25.0 x 50.0	150.00	N-BK7	Uncoated	#46-024	£98.93 Volume Pricing	2 In Stock
-	25.0 x 50.0	150.00	N-BK7	MgF ₂ (400-700nm)	#48-367	£108.56 Volume Pricing	5 In Stock
-	25.0 x 50.0	150.00	N-BK7	VIS 0° (425-675nm)	#69-735	£116.44 Volume Pricing	5 In Stock
-	25.0 x 50.0	150.00	N-BK7	VIS-NIR (400-1000nm)	#69-787	£116.44 Volume Pricing	1 In Stock
-	25.0 x 50.0	150.00	N-BK7	NIR I (600-1050nm)	#69-761	£116.44 Volume Pricing	1 In Stock
-	25.4 x 25.4	50.00	N-BK7	Uncoated	#35-024	£63.04 Volume Pricing	20+ In Stock
-	25.4 x 25.4	50.00	N-BK7	VIS 0° (425-675nm)	#36-212	£79.23 Volume Pricing	2 In Stock
-	25.4 x 25.4	50.00	N-BK7	VIS-NIR (400-1000nm)	#36-222	£79.23 Volume Pricing	3 In Stock

-	25.4 x 25.4	50.00	N-BK7	NIR I (600-1050nm)	#36-231	£79.23 Volume Pricing	1 In Stock
-	25.4 x 25.4	100.00	N-BK7	Uncoated	#35-025	£63.04 Volume Pricing	20+ In Stock
-	25.4 x 25.4	100.00	N-BK7	VIS 0° (425-675nm)	#36-213	£79.23 Volume Pricing	6 In Stock
-	25.4 x 25.4	100.00	N-BK7	VIS-NIR (400-1000nm)	#36-223	£79.23 Volume Pricing	3 In Stock
-	25.4 x 25.4	100.00	N-BK7	NIR I (600-1050nm)	#36-232	£79.23 Volume Pricing	3 In Stock
-	25.4 x 25.4	150.00	N-BK7	Uncoated	#35-026	£63.04 Volume Pricing	20+ In Stock
-	25.4 x 25.4	150.00	N-BK7	VIS 0° (425-675nm)	#36-214	£79.23 Volume Pricing	1 In Stock
-	25.4 x 25.4	150.00	N-BK7	VIS-NIR (400-1000nm)	#36-224	£79.23 Volume Pricing	2 In Stock
-	25.4 x 25.4	150.00	N-BK7	NIR I (600-1050nm)	#36-233	£79.23 Volume Pricing	5 In Stock
-	25.4 x 25.4	200.00	N-BK7	Uncoated	#35-027	£63.04 Volume Pricing	20+ In Stock
-	25.4 x 25.4	200.00	N-BK7	VIS 0° (425-675nm)	#36-215	£79.23 Volume Pricing	Contact Us
-	25.4 x 25.4	200.00	N-BK7	VIS-NIR (400-1000nm)	#36-225	£79.23 Volume Pricing	3 In Stock
-	25.4 x 25.4	200.00	N-BK7	NIR I (600-1050nm)	#36-234	£79.23 Volume Pricing	5 In Stock
-	25.4 x 25.4	250.00	N-BK7	Uncoated	#35-028	£63.04 Volume Pricing	20+ In Stock
-	25.4 x 25.4	250.00	N-BK7	VIS 0° (425-675nm)	#36-216	£79.23 Volume Pricing	2 In Stock
-	25.4 x 25.4	250.00	N-BK7	VIS-NIR (400-1000nm)	#36-226	£79.23 Volume Pricing	11 In Stock

-	25.4 x 25.4	250.00	N-BK7	NIR I (600-1050nm)	#36-235	£79.23 Volume Pricing	2 In Stock
-	30.0 x 30.0	50.00	N-BK7	Uncoated	#25-501	£117.32 Volume Pricing	20+ In Stock
-	30.0 x 30.0	50.00	N-BK7	VIS 0° (425-675nm)	#25-502	£135.70 Volume Pricing	4 In Stock
-	30.0 x 30.0	50.00	N-BK7	NIR I (600-1050nm)	#25-503	£135.70 Volume Pricing	11 In Stock
-	30.0 x 30.0	100.00	N-BK7	Uncoated	#25-504	£117.32 Volume Pricing	6 In Stock
-	30.0 x 30.0	100.00	N-BK7	NIR I (600-1050nm)	#25-506	£135.70 Volume Pricing	5 In Stock
-	30.0 x 30.0	100.00	N-BK7	VIS 0° (425-675nm)	#25-505	£135.70 Volume Pricing	5 In Stock
-	50.0 x 25.0	75.00	N-BK7	Uncoated	#46-198	£98.93 Volume Pricing	20+ In Stock
-	50.0 x 25.0	75.00	N-BK7	MgF ₂ (400-700nm)	#48-368	£108.56 Volume Pricing	8 In Stock
-	50.0 x 25.0	75.00	N-BK7	VIS 0° (425-675nm)	#69-736	£116.44 Volume Pricing	1 In Stock
-	50.0 x 25.0	75.00	N-BK7	VIS-NIR (400-1000nm)	#69-788	£116.44 Volume Pricing	2 In Stock
-	50.0 x 25.0	75.00	N-BK7	NIR I (600-1050nm)	#69-762	£116.44 Volume Pricing	5 In Stock
-	50.0 x 25.0	100.00	N-BK7	Uncoated	#46-199	£98.93 Volume Pricing	20+ In Stock
-	50.0 x 25.0	100.00	N-BK7	MgF ₂ (400-700nm)	#48-369	£108.56 Volume Pricing	2 In Stock
-	50.0 x 25.0	100.00	N-BK7	VIS 0° (425-675nm)	#69-737	£116.44 Volume Pricing	5 In Stock
-	50.0 x 25.0	100.00	N-BK7	VIS-NIR (400-1000nm)	#69-789	£116.44 Volume Pricing	3 In Stock

-	50.0 x 25.0	100.00	N-BK7	NIR I (600-1050nm)	#69-763	£116.44 Volume Pricing	3 In Stock
-	50.0 x 25.0	150.00	N-BK7	Uncoated	#46-200	£98.93 Volume Pricing	20+ In Stock
-	50.0 x 25.0	150.00	N-BK7	MgF ₂ (400-700nm)	#48-370	£108.56 Volume Pricing	Contact Us
-	50.0 x 25.0	150.00	N-BK7	VIS 0° (425-675nm)	#69-738	£116.44 Volume Pricing	3 In Stock
 Edmund optics worldwide				VIS-NIR (400-1000nm)	#69-790	£116.44 Volume Pricing	5 In Stock
Copyright 2023 Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK Phone: 1-800-363-1992 : www.edmundoptics.com							
-	50.0 x 25.0	150.00	N-BK7	NIR I (600-1050nm)	#69-764	£116.44 Volume Pricing	3 In Stock