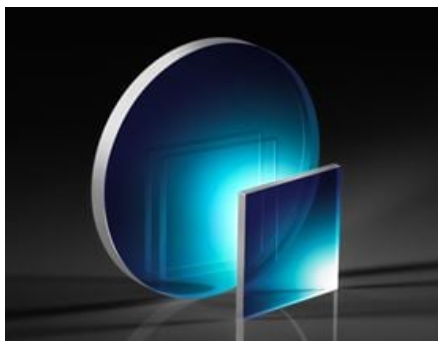


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [UV and IR Windows](#)
TECHSPEC® $\lambda/10$ UV Fused Silica Windows


- UV, Visible, and NIR Anti-Reflection Coated Versions Available
- $\lambda/10$ Transmitted Wavefront Distortion
- Circular and Square Sizes from 2mm to 150mm
- [1 \$\lambda\$](#) or [\$\lambda/4\$](#) UV Fused Silica Windows Also Available

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed	Edges:	Fine Ground
Knoop Hardness (kg/mm²):	522.00	Poisson's Ratio:	0.16
Young's Modulus (GPa):	73		



Optical Properties

Abbe Number (v_d):	67.8
Index of Refraction (n_d):	1.458

Material Properties

Density (g/cm³):	2.20
------------------------------------	------

Technical Information

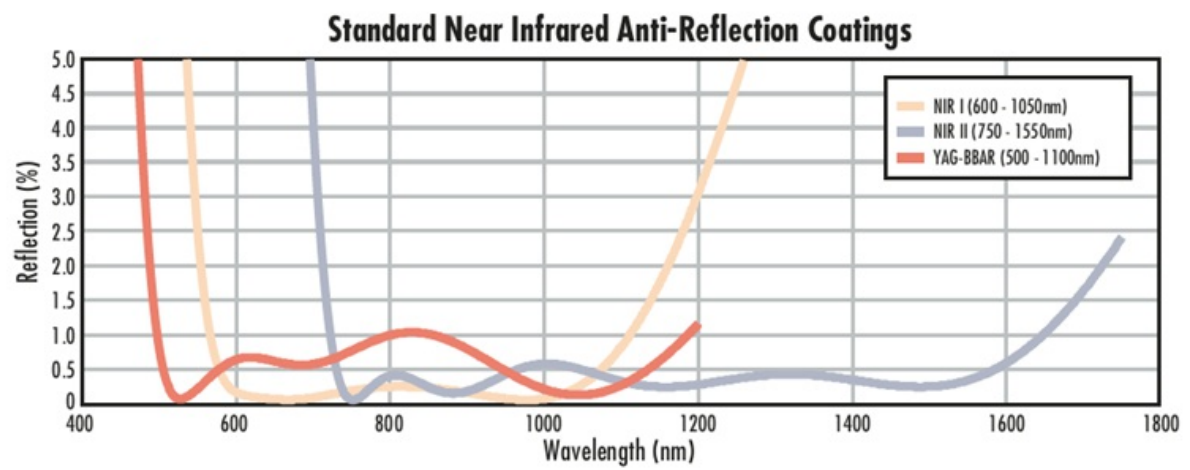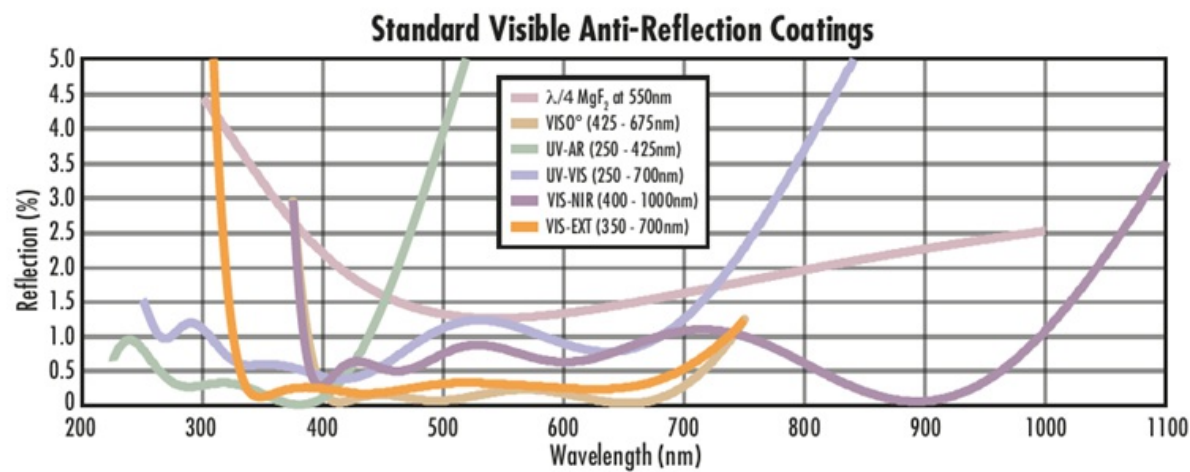

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
2.00	-	1.00	Uncoated	#27-669	£83.17 Volume Pricing	5 In Stock
2.50	-	1.00	Uncoated	#27-670	£83.17 Volume Pricing	20+ In Stock
3.00	-	1.00	Uncoated	#27-671	£87.55 Volume Pricing	20+ In Stock
4.00	-	1.00	Uncoated	#27-672	£92.80 Volume Pricing	20+ In Stock
5.00	-	1.00	Uncoated	#47-833	£104.18 Volume Pricing	Contact Us
10.00	-	1.25	Uncoated	#47-192	£98.93 Volume Pricing	20+ In Stock
12.50	-	1.50	Uncoated	#47-193	£101.56 Volume Pricing	20+ In Stock
-	12.50 x 12.50	1.50	Uncoated	#23-136	£101.56 Volume Pricing	6 In Stock
12.50	-	2.00	Uncoated	#63-107	£101.56 Volume Pricing	20+ In Stock
12.70	-	1.50	Uncoated	#15-402	£101.56 Volume Pricing	Contact Us
15.00	-	2.00	Uncoated	#47-194	£105.94 Volume Pricing	20+ In Stock
20.00	-	2.00	Uncoated	#63-204	£112.94 Volume Pricing	20+ In Stock
25.00	-	1.00	Uncoated	#11-876	£119.94 Volume Pricing	12 In Stock
25.00	-	2.00	Uncoated	#11-877	£119.94 Volume Pricing	20+ In Stock
25.00	-	3.00	Uncoated	#47-195	£119.94 Volume Pricing	20+ In Stock
-	25.00 x 25.00	3.00	Uncoated	#23-137	£119.94 Volume Pricing	20+ In Stock
25.00	-	5.00	Uncoated	#11-878	£119.94 Volume Pricing	20+ In Stock

25.40	-	3.00	Uncoated	#15-403	£119.94 Volume Pricing	1 In Stock
30.00	-	4.00	Uncoated	#47-834	£152.34 Volume Pricing	20+ In Stock
40.00	-	4.00	Uncoated	#47-835	£173.35 Volume Pricing	20+ In Stock
50.00	-	1.00	Uncoated	#34-599	£210.12 Volume Pricing	20+ In Stock
50.00	-	2.00	Uncoated	#34-600	£210.12 Volume Pricing	Contact Us
50.00	-	3.00	Uncoated	#34-601	£210.12 Volume Pricing	20+ In Stock
50.00	-	5.00	Uncoated	#47-836	£210.12 Volume Pricing	20+ In Stock
-	50.00 x 50.00	5.00	Uncoated	#23-138	£210.12 Volume Pricing	2 In Stock
50.00	-	6.00	Uncoated	#34-602	£210.12 Volume Pricing	5 In Stock
50.80	-	5.00	Uncoated	#15-404	£210.12 Volume Pricing	16 In Stock
75.00	-	3.00	Uncoated	#36-935	£351.08 Volume Pricing	20+ In Stock
75.00	-	5.00	Uncoated	#36-936	£351.08 Volume Pricing	Contact Us
100.00	-	5.00	Uncoated	#17-561	£446.51 Volume Pricing	16 In Stock
125.00	-	6.00	Uncoated	#17-562	£564.70 Volume Pricing	20+ In Stock
150.00	-	8.00	Uncoated	#17-563	£783.57 Volume Pricing	20+ In Stock
5.00	-	1.00	UV-AR (250-425nm)	#65-870	£129.57 Volume Pricing	11 In Stock
10.00	-	1.25	UV-AR (250-425nm)	#65-871	£124.32 Volume Pricing	6 In Stock
12.50	-	1.50	UV-AR (250-425nm)	#65-872	£126.95 Volume Pricing	20+ In Stock

-	12.50 x 12.50	1.50	UV-AR (250-425nm)	#24-296	£126.95 Volume Pricing	2 In Stock
12.50	-	2.00	UV-AR (250-425nm)	#68-487	£126.95 Volume Pricing	17 In Stock
12.70	-	1.50	UV-AR (250-425nm)	#15-405	£126.95 Volume Pricing	Contact Us
15.00	-	2.00	UV-AR (250-425nm)	#65-873	£131.33 Volume Pricing	20+ In Stock
20.00	-	2.00	UV-AR (250-425nm)	#65-874	£138.33 Volume Pricing	20+ In Stock
25.00	-	1.00	UV-AR (250-425nm)	#11-879	£145.33 Volume Pricing	1 In Stock
25.00	-	2.00	UV-AR (250-425nm)	#11-880	£145.33 Volume Pricing	5 In Stock
25.00	-	3.00	UV-AR (250-425nm)	#65-875	£145.33 Volume Pricing	20+ In Stock
-	25.00 x 25.00	3.00	UV-AR (250-425nm)	#24-304	£145.33 Volume Pricing	8 In Stock
25.00	-	5.00	UV-AR (250-425nm)	#11-881	£145.33 Volume Pricing	6 In Stock
25.40	-	3.00	UV-AR (250-425nm)	#15-406	£145.33 Volume Pricing	8 In Stock
30.00	-	4.00	UV-AR (250-425nm)	#65-876	£182.10 Volume Pricing	8 In Stock
40.00	-	4.00	UV-AR (250-425nm)	#65-877	£203.12 Volume Pricing	Contact Us
50.00	-	1.00	UV-AR (250-425nm)	#36-938	£239.89 Volume Pricing	3 In Stock

50.00	-	2.00	UV-AR (250-425nm)	#36-943	£239.89 Volume Pricing	Contact Us
50.00	-	3.00	UV-AR (250-425nm)	#36-948	£239.89 Volume Pricing	6 In Stock
50.00	-	5.00	UV-AR (250-425nm)	#65-878	£239.89 Volume Pricing	9 In Stock
-	50.00 x 50.00	5.00	UV-AR (250-425nm)	#24-312	£239.89 Volume Pricing	1 In Stock
50.00	-	6.00	UV-AR (250-425nm)	#36-953	£239.89 Volume Pricing	5 In Stock
50.80	-	5.00	UV-AR (250-425nm)	#15-407	£239.89 Volume Pricing	1 In Stock
75.00	-	3.00	UV-AR (250-425nm)	#36-958	£410.61 Volume Pricing	3 In Stock
75.00	-	5.00	UV-AR (250-425nm)	#36-963	£410.61 Volume Pricing	4 In Stock
5.00	-	1.00	UV-VIS (250-700nm)	#48-062	£129.57 Volume Pricing	15 In Stock
10.00	-	1.25	UV-VIS (250-700nm)	#48-063	£124.32 Volume Pricing	20+ In Stock
12.50	-	1.50	UV-VIS (250-700nm)	#48-064	£126.95 Volume Pricing	14 In Stock
-	12.50 x 12.50	1.50	UV-VIS (250-700nm)	#24-297	£126.95 Volume Pricing	1 In Stock
12.50	-	2.00	UV-VIS (250-700nm)	#68-488	£126.95 Volume Pricing	1 In Stock
12.70	-	1.50	UV-VIS (250-700nm)	#15-408	£126.95 Volume Pricing	1 In Stock

15.00	-	2.00	UV-VIS (250-700nm)	#48-065	£131.33 Volume Pricing	Contact Us
20.00	-	2.00	UV-VIS (250-700nm)	#63-206	£138.33 Volume Pricing	13 In Stock
25.00	-	1.00	UV-VIS (250-700nm)	#11-882	£145.33 Volume Pricing	7 In Stock
25.00	-	2.00	UV-VIS (250-700nm)	#11-883	£145.33 Volume Pricing	20+ In Stock
25.00	-	3.00	UV-VIS (250-700nm)	#48-066	£145.33 Volume Pricing	7 In Stock
-	25.00 x 25.00	3.00	UV-VIS (250-700nm)	#24-305	£145.33 Volume Pricing	4 In Stock
25.00	-	5.00	UV-VIS (250-700nm)	#11-884	£145.33 Volume Pricing	14 In Stock
25.40	-	3.00	UV-VIS (250-700nm)	#15-409	£145.33 Volume Pricing	5 In Stock
30.00	-	4.00	UV-VIS (250-700nm)	#48-067	£182.10 Volume Pricing	10 In Stock
40.00	-	4.00	UV-VIS (250-700nm)	#48-068	£203.12 Volume Pricing	2 In Stock
50.00	-	1.00	UV-VIS (250-700nm)	#36-939	£239.89 Volume Pricing	1 In Stock
50.00	-	2.00	UV-VIS (250-700nm)	#36-944	£239.89 Volume Pricing	Contact Us
50.00	-	3.00	UV-VIS (250-700nm)	#36-949	£239.89 Volume Pricing	7 In Stock
50.00	-	5.00	UV-VIS (250-700nm)	#48-069	£239.89 Volume Pricing	5 In Stock

-	50.00 x 50.00	5.00	UV-VIS (250-700nm)	#24-313	£239.89 Volume Pricing	6 In Stock
50.00	-	6.00	UV-VIS (250-700nm)	#36-954	£239.89 Volume Pricing	1 In Stock
50.80	-	5.00	UV-VIS (250-700nm)	#15-410	£239.89 Volume Pricing	3 In Stock
75.00	-	3.00	UV-VIS (250-700nm)	#36-959	£410.61 Volume Pricing	20+ In Stock
75.00	-	5.00	UV-VIS (250-700nm)	#36-964	£410.61 Volume Pricing	Contact Us
100.00	-	5.00	UV-VIS (250-700nm)	#22-064	£691.65 Volume Pricing	8 In Stock
125.00	-	6.00	UV-VIS (250-700nm)	#22-065	£888.63 Volume Pricing	5 In Stock
150.00	-	8.00	UV-VIS (250-700nm)	#22-066	£1,177.55 Volume Pricing	2 In Stock
5.00	-	1.00	VIS-EXT (350-700nm)	#13-330	£131.33 Volume Pricing	5 In Stock
10.00	-	1.25	VIS-EXT (350-700nm)	#13-331	£126.95 Volume Pricing	5 In Stock
-	12.50 x 12.50	1.50	VIS-EXT (350-700nm)	#24-301	£129.57 Volume Pricing	4 In Stock
12.50	-	1.50	VIS-EXT (350-700nm)	#13-332	£129.57 Volume Pricing	7 In Stock
12.50	-	2.00	VIS-EXT (350-700nm)	#13-333	£129.57 Volume Pricing	5 In Stock
12.70	-	1.50	VIS-EXT (350-700nm)	#15-781	£129.57 Volume Pricing	11 In Stock

15.00	-	2.00	VIS-EXT (350-700nm)	#13-334	£133.95 Volume Pricing	20+ In Stock
20.00	-	2.00	VIS-EXT (350-700nm)	#13-335	£140.96 Volume Pricing	9 In Stock
25.00	-	1.00	VIS-EXT (350-700nm)	#13-336	£147.96 Volume Pricing	Contact Us
25.00	-	2.00	VIS-EXT (350-700nm)	#13-337	£147.96 Volume Pricing	Contact Us
-	25.00 x 25.00	3.00	VIS-EXT (350-700nm)	#24-309	£147.96 Volume Pricing	1 In Stock
25.00	-	3.00	VIS-EXT (350-700nm)	#13-338	£147.96 Volume Pricing	5 In Stock
25.00	-	5.00	VIS-EXT (350-700nm)	#13-339	£147.96 Volume Pricing	2 In Stock
25.40	-	3.00	VIS-EXT (350-700nm)	#15-782	£147.96 Volume Pricing	4 In Stock
30.00	-	4.00	VIS-EXT (350-700nm)	#16-461	£184.73 Volume Pricing	2 In Stock
40.00	-	4.00	VIS-EXT (350-700nm)	#13-341	£205.74 Volume Pricing	Contact Us
50.00	-	1.00	VIS-EXT (350-700nm)	#13-342	£242.51 Volume Pricing	3 In Stock
50.00	-	2.00	VIS-EXT (350-700nm)	#13-343	£242.51 Volume Pricing	Contact Us
50.00	-	3.00	VIS-EXT (350-700nm)	#13-344	£242.51 Volume Pricing	2 In Stock
50.00	-	5.00	VIS-EXT (350-700nm)	#13-345	£242.51 Volume Pricing	Contact Us

-	50.00 x 50.00	5.00	VIS-EXT (350-700nm)	#24-317	£242.51 Volume Pricing	7 In Stock
50.00	-	6.00	VIS-EXT (350-700nm)	#13-346	£242.51 Volume Pricing	Contact Us
50.80	-	5.00	VIS-EXT (350-700nm)	#15-783	£242.51 Volume Pricing	Contact Us
75.00	-	3.00	VIS-EXT (350-700nm)	#15-799	£415.86 Volume Pricing	2 In Stock
75.00	-	5.00	VIS-EXT (350-700nm)	#15-800	£415.86 Volume Pricing	Contact Us
5.00	-	1.00	VIS-NIR (400-1000nm)	#84-449	£131.33 Volume Pricing	4 In Stock
10.00	-	1.25	VIS-NIR (400-1000nm)	#84-450	£126.95 Volume Pricing	9 In Stock
12.50	-	1.50	VIS-NIR (400-1000nm)	#84-451	£129.57 Volume Pricing	11 In Stock
-	12.50 x 12.50	1.50	VIS-NIR (400-1000nm)	#24-302	£129.57 Volume Pricing	1 In Stock
12.50	-	2.00	VIS-NIR (400-1000nm)	#84-452	£129.57 Volume Pricing	2 In Stock
12.70	-	1.50	VIS-NIR (400-1000nm)	#15-414	£129.57 Volume Pricing	1 In Stock
15.00	-	2.00	VIS-NIR (400-1000nm)	#84-453	£133.95 Volume Pricing	Contact Us
20.00	-	2.00	VIS-NIR (400-1000nm)	#84-454	£140.96 Volume Pricing	20+ In Stock
25.00	-	1.00	VIS-NIR (400-1000nm)	#11-888	£147.96 Volume Pricing	20+ In Stock

25.00	-	2.00	VIS-NIR (400-1000nm)	#11-889	£147.96 Volume Pricing	9 In Stock
-	25.00 x 25.00	3.00	VIS-NIR (400-1000nm)	#24-310	£147.96 Volume Pricing	5 In Stock
25.00	-	3.00	VIS-NIR (400-1000nm)	#84-455	£147.96 Volume Pricing	20+ In Stock
25.00	-	5.00	VIS-NIR (400-1000nm)	#11-890	£147.96 Volume Pricing	2 In Stock
25.40	-	3.00	VIS-NIR (400-1000nm)	#15-415	£147.96 Volume Pricing	6 In Stock
30.00	-	4.00	VIS-NIR (400-1000nm)	#84-456	£184.73 Volume Pricing	10 In Stock
40.00	-	4.00	VIS-NIR (400-1000nm)	#84-457	£205.74 Volume Pricing	13 In Stock
50.00	-	1.00	VIS-NIR (400-1000nm)	#36-941	£242.51 Volume Pricing	6 In Stock
50.00	-	2.00	VIS-NIR (400-1000nm)	#36-946	£242.51 Volume Pricing	7 In Stock
50.00	-	3.00	VIS-NIR (400-1000nm)	#36-951	£242.51 Volume Pricing	1 In Stock
50.00	-	5.00	VIS-NIR (400-1000nm)	#84-458	£242.51 Volume Pricing	20+ In Stock
-	50.00 x 50.00	5.00	VIS-NIR (400-1000nm)	#24-318	£242.51 Volume Pricing	1 In Stock
50.00	-	6.00	VIS-NIR (400-1000nm)	#36-956	£242.51 Volume Pricing	13 In Stock
50.80	-	5.00	VIS-NIR (400-1000nm)	#15-416	£242.51 Volume Pricing	4 In Stock

75.00	-	3.00	VIS-NIR (400-1000nm)	#36-961	£415.86 Volume Pricing	5 In Stock
75.00	-	5.00	VIS-NIR (400-1000nm)	#36-966	£415.86 Volume Pricing	13 In Stock
100.00	-	5.00	VIS-NIR (400-1000nm)	#22-070	£691.65 Volume Pricing	4 In Stock
125.00	-	6.00	VIS-NIR (400-1000nm)	#22-071	£888.63 Volume Pricing	15 In Stock
150.00	-	8.00	VIS-NIR (400-1000nm)	#22-072	£1,177.55 Volume Pricing	5 In Stock
5.00	-	1.00	VIS 0° (425-675nm)	#47-837	£126.95 Volume Pricing	Contact Us
10.00	-	1.25	VIS 0° (425-675nm)	#47-196	£122.57 Volume Pricing	20+ In Stock
-	12.50 x 12.50	1.50	VIS 0° (425-675nm)	#24-298	£124.32 Volume Pricing	1 In Stock
12.50	-	1.50	VIS 0° (425-675nm)	#47-197	£124.32 Volume Pricing	20+ In Stock
12.50	-	2.00	VIS 0° (425-675nm)	#68-489	£124.32 Volume Pricing	10 In Stock
12.70	-	1.50	VIS 0° (425-675nm)	#15-411	£124.32 Volume Pricing	4 In Stock
15.00	-	2.00	VIS 0° (425-675nm)	#47-198	£129.57 Volume Pricing	20+ In Stock
20.00	-	2.00	VIS 0° (425-675nm)	#63-205	£136.58 Volume Pricing	7 In Stock
25.00	-	1.00	VIS 0° (425-675nm)	#11-885	£143.58 Volume Pricing	9 In Stock

25.00	-	2.00	VIS 0° (425-675nm)	#11-886	£143.58 Volume Pricing	17 In Stock
25.00	-	3.00	VIS 0° (425-675nm)	#47-199	£143.58 Volume Pricing	20+ In Stock
-	25.00 x 25.00	3.00	VIS 0° (425-675nm)	#24-306	£143.58 Volume Pricing	4 In Stock
25.00	-	5.00	VIS 0° (425-675nm)	#11-887	£143.58 Volume Pricing	6 In Stock
25.40	-	3.00	VIS 0° (425-675nm)	#15-412	£143.58 Volume Pricing	20+ In Stock
30.00	-	4.00	VIS 0° (425-675nm)	#47-838	£180.35 Volume Pricing	9 In Stock
40.00	-	4.00	VIS 0° (425-675nm)	#47-839	£200.49 Volume Pricing	13 In Stock
50.00	-	1.00	VIS 0° (425-675nm)	#36-940	£238.14 Volume Pricing	10 In Stock
50.00	-	2.00	VIS 0° (425-675nm)	#36-945	£238.14 Volume Pricing	14 In Stock
50.00	-	3.00	VIS 0° (425-675nm)	#36-950	£238.14 Volume Pricing	11 In Stock
50.00	-	5.00	VIS 0° (425-675nm)	#47-840	£238.14 Volume Pricing	20+ In Stock
-	50.00 x 50.00	5.00	VIS 0° (425-675nm)	#24-314	£238.14 Volume Pricing	2 In Stock
50.00	-	6.00	VIS 0° (425-675nm)	#36-955	£238.14 Volume Pricing	4 In Stock
50.80	-	5.00	VIS 0° (425-675nm)	#15-413	£238.14 Volume Pricing	4 In Stock

75.00	-	3.00	VIS 0° (425-675nm)	#36-960	£406.23 Volume Pricing	2 In Stock
75.00	-	5.00	VIS 0° (425-675nm)	#36-965	£406.23 Volume Pricing	2 In Stock
100.00	-	5.00	VIS 0° (425-675nm)	#22-067	£678.51 Volume Pricing	Contact Us
125.00	-	6.00	VIS 0° (425-675nm)	#22-068	£862.37 Volume Pricing	4 In Stock
150.00	-	8.00	VIS 0° (425-675nm)	#22-069	£1,155.66 Volume Pricing	3 In Stock
5.00	-	1.00	YAG-BBAR (500-1100nm)	#13-347	£131.33 Volume Pricing	15 In Stock
10.00	-	1.25	YAG-BBAR (500-1100nm)	#13-348	£126.95 Volume Pricing	13 In Stock
-	12.50 x 12.50	1.50	YAG-BBAR (500-1100nm)	#24-303	£129.57 Volume Pricing	8 In Stock
12.50	-	1.50	YAG-BBAR (500-1100nm)	#13-349	£129.57 Volume Pricing	1 In Stock
12.50	-	2.00	YAG-BBAR (500-1100nm)	#13-350	£129.57 Volume Pricing	9 In Stock
12.70	-	1.50	YAG-BBAR (500-1100nm)	#15-784	£129.57 Volume Pricing	4 In Stock
15.00	-	2.00	YAG-BBAR (500-1100nm)	#13-351	£133.95 Volume Pricing	1 In Stock

20.00	-	2.00	YAG-BBAR (500-1100nm)	#13-352	£140.96 Volume Pricing	9 In Stock
25.00	-	1.00	YAG-BBAR (500-1100nm)	#13-353	£147.96 Volume Pricing	Contact Us
25.00	-	2.00	YAG-BBAR (500-1100nm)	#13-354	£147.96 Volume Pricing	6 In Stock
-	25.00 x 25.00	3.00	YAG-BBAR (500-1100nm)	#24-311	£147.96 Volume Pricing	3 In Stock
25.00	-	3.00	YAG-BBAR (500-1100nm)	#13-355	£147.96 Volume Pricing	3 In Stock
25.00	-	5.00	YAG-BBAR (500-1100nm)	#13-356	£147.96 Volume Pricing	3 In Stock
25.40	-	3.00	YAG-BBAR (500-1100nm)	#15-785	£147.96 Volume Pricing	9 In Stock
30.00	-	4.00	YAG-BBAR (500-1100nm)	#13-357	£184.73 Volume Pricing	17 In Stock
40.00	-	4.00	YAG-BBAR (500-1100nm)	#13-358	£205.74 Volume Pricing	20+ In Stock
50.00	-	1.00	YAG-BBAR (500-1100nm)	#13-359	£242.51 Volume Pricing	Contact Us
50.00	-	2.00	YAG-BBAR (500-1100nm)	#13-360	£242.51 Volume Pricing	Contact Us

50.00	-	3.00	YAG-BBAR (500-1100nm)	#13-361	£242.51 Volume Pricing	13 In Stock
50.00	-	5.00	YAG-BBAR (500-1100nm)	#13-362	£242.51 Volume Pricing	14 In Stock
-	50.00 x 50.00	5.00	YAG-BBAR (500-1100nm)	#24-319	£242.51 Volume Pricing	5 In Stock
50.00	-	6.00	YAG-BBAR (500-1100nm)	#13-363	£242.51 Volume Pricing	12 In Stock
50.80	-	5.00	YAG-BBAR (500-1100nm)	#15-786	£242.51 Volume Pricing	4 In Stock
75.00	-	3.00	YAG-BBAR (500-1100nm)	#15-801	£415.86 Volume Pricing	Contact Us
75.00	-	5.00	YAG-BBAR (500-1100nm)	#15-802	£415.86 Volume Pricing	20+ In Stock
5.00	-	1.00	NIR I (600-1050nm)	#84-459	£126.95 Volume Pricing	Contact Us
10.00	-	1.25	NIR I (600-1050nm)	#84-460	£122.57 Volume Pricing	20+ In Stock
12.50	-	1.50	NIR I (600-1050nm)	#84-461	£124.32 Volume Pricing	7 In Stock
-	12.50 x 12.50	1.50	NIR I (600-1050nm)	#24-299	£124.32 Volume Pricing	5 In Stock
12.50	-	2.00	NIR I (600-1050nm)	#84-462	£124.32 Volume Pricing	20+ In Stock

12.70	-	1.50	NIR I (600- 1050nm)	#15-417	£124.32 Volume Pricing	2 In Stock
15.00	-	2.00	NIR I (600- 1050nm)	#84-463	£129.57 Volume Pricing	20+ In Stock
20.00	-	2.00	NIR I (600- 1050nm)	#84-464	£136.58 Volume Pricing	20+ In Stock
25.00	-	1.00	NIR I (600- 1050nm)	#11-891	£143.58 Volume Pricing	15 In Stock
25.00	-	2.00	NIR I (600- 1050nm)	#11-892	£143.58 Volume Pricing	2 In Stock
25.00	-	3.00	NIR I (600- 1050nm)	#84-465	£143.58 Volume Pricing	5 In Stock
25.00	-	5.00	NIR I (600- 1050nm)	#11-893	£143.58 Volume Pricing	1 In Stock
25.40	-	3.00	NIR I (600- 1050nm)	#15-418	£143.58 Volume Pricing	5 In Stock
-	25.00 x 25.00	3.00	NIR I (600- 1050nm)	#24-307	£143.58 Volume Pricing	Contact Us
30.00	-	4.00	NIR I (600- 1050nm)	#84-466	£180.35 Volume Pricing	10 In Stock
40.00	-	4.00	NIR I (600- 1050nm)	#84-467	£200.49 Volume Pricing	5 In Stock
50.00	-	1.00	NIR I (600- 1050nm)	#36-937	£238.14 Volume Pricing	5 In Stock
50.00	-	2.00	NIR I (600- 1050nm)	#36-942	£238.14 Volume Pricing	14 In Stock
50.00	-	3.00	NIR I (600- 1050nm)	#36-947	£238.14 Volume Pricing	5 In Stock

50.00	-	5.00	NIR I (600-1050nm)	#84-468	£238.14 Volume Pricing	Contact Us
-	50.00 x 50.00	5.00	NIR I (600-1050nm)	#24-315	£238.14 Volume Pricing	2 In Stock
50.00	-	6.00	NIR I (600-1050nm)	#36-952	£238.14 Volume Pricing	20+ In Stock
50.80	-	5.00	NIR I (600-1050nm)	#15-419	£238.14 Volume Pricing	2 In Stock
75.00	-	3.00	NIR I (600-1050nm)	#36-957	£406.23 Volume Pricing	Contact Us
75.00	-	5.00	NIR I (600-1050nm)	#36-962	£406.23 Volume Pricing	Contact Us
5.00	-	1.00	NIR II (750-1550nm)	#11-894	£126.95 Volume Pricing	Contact Us
10.00	-	1.25	NIR II (750-1550nm)	#11-895	£122.57 Volume Pricing	5 In Stock
12.50	-	1.50	NIR II (750-1550nm)	#11-896	£124.32 Volume Pricing	Contact Us
-	12.50 x 12.50	1.50	NIR II (750-1550nm)	#24-300	£124.32 Volume Pricing	2 In Stock
12.50	-	2.00	NIR II (750-1550nm)	#11-897	£124.32 Volume Pricing	1 In Stock
12.70	-	1.50	NIR II (750-1550nm)	#15-420	£124.32 Volume Pricing	Contact Us
15.00	-	2.00	NIR II (750-1550nm)	#11-898	£129.57 Volume Pricing	11 In Stock
20.00	-	2.00	NIR II (750-1550nm)	#11-899	£136.58 Volume Pricing	17 In Stock

25.00	-	1.00	NIR II (750-1550nm)	#11-900	£143.58 Volume Pricing	8 In Stock
25.00	-	2.00	NIR II (750-1550nm)	#11-901	£143.58 Volume Pricing	Contact Us
-	25.00 x 25.00	3.00	NIR II (750-1550nm)	#24-308	£143.58 Volume Pricing	4 In Stock
25.00	-	3.00	NIR II (750-1550nm)	#11-902	£143.58 Volume Pricing	8 In Stock
25.00	-	5.00	NIR II (750-1550nm)	#11-903	£143.58 Volume Pricing	8 In Stock
25.40	-	3.00	NIR II (750-1550nm)	#15-421	£143.58 Volume Pricing	5 In Stock
30.00	-	4.00	NIR II (750-1550nm)	#11-904	£180.35 Volume Pricing	5 In Stock
40.00	-	4.00	NIR II (750-1550nm)	#11-905	£200.49 Volume Pricing	1 In Stock
50.00	-	1.00	NIR II (750-1550nm)	#11-906	£238.14 Volume Pricing	7 In Stock
50.00	-	2.00	NIR II (750-1550nm)	#11-907	£238.14 Volume Pricing	16 In Stock
50.00	-	3.00	NIR II (750-1550nm)	#11-908	£238.14 Volume Pricing	20+ In Stock
50.00	-	5.00	NIR II (750-1550nm)	#11-909	£238.14 Volume Pricing	4 In Stock
-	50.00 x 50.00	5.00	NIR II (750-1550nm)	#24-316	£238.14 Volume Pricing	6 In Stock
50.00	-	6.00	NIR II (750-1550nm)	#11-910	£238.14 Volume Pricing	9 In Stock

50.80	-	5.00	NIR II (750-1550nm)	#15-422	£238.14 Volume Pricing	5 In Stock
75.00	-	3.00	NIR II (750-1550nm)	#11-911	£406.23 Volume Pricing	20+ In Stock
75.00	-	5.00	NIR II (750-1550nm)	#11-912	£406.23 Volume Pricing	6 In Stock
100.00	-	5.00	UV-AR (250-425nm)	#29-604	£691.65 Volume Pricing	Contact Us
100.00	-	5.00	VIS-EXT (350-700nm)	#29-607	£691.65 Volume Pricing	Contact Us
100.00	-	5.00	NIR I (600-1050nm)	#29-605	£678.51 Volume Pricing	Contact Us
100.00	-	5.00	NIR II (750-1550nm)	#29-606	£678.51 Volume Pricing	11 In Stock
#29-608 New						
 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!						
100.00	-	5.00	YAG-BBAR (500-1100nm)		£691.65 Volume Pricing	Contact Us
100.00	-	10.00	Uncoated	#29-508	£538.43 Volume Pricing	20+ In Stock
125.00	-	6.00	UV-AR (250-425nm)	#29-609	£888.63 Volume Pricing	2 In Stock

125.00	-	6.00	VIS-EXT (350-700nm)	#29-612	£888.63 Volume Pricing	Contact Us
125.00	-	6.00	NIR I (600-1050nm)	#29-610	£862.37 Volume Pricing	1 In Stock
125.00	-	6.00	NIR II (750-1550nm)	#29-611	£862.37 Volume Pricing	5 In Stock
125.00	-	6.00	YAG-BBAR (500-1100nm)	#29-613	£888.63 Volume Pricing	2 In Stock
125.00	-	12.50	Uncoated	#29-509	£691.65 Volume Pricing	1 In Stock
150.00	-	8.00	UV-AR (250-425nm)	#29-614	£1,177.55 Volume Pricing	1 In Stock
150.00	-	8.00	VIS-EXT (350-700nm)	#29-617	£1,177.55 Volume Pricing	1 In Stock
150.00	-	8.00	NIR I (600-1050nm)	#29-615	£1,155.66 Volume Pricing	Contact Us
150.00	-	8.00	NIR II (750-1550nm)	#29-616	£1,155.66 Volume Pricing	3 In Stock

[#29-618 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.

Be the
first to buy
before
anyone
else!

150.00 - 8.00 YAG-BBAR
(500-1100nm)

£1,177.55
[Volume Pricing](#)

1 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Newer Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 :
www.edmundoptics.com

150.00 - 15.00 Uncoated [#29-510](#)

£1,094.38
[Volume Pricing](#)

5 In Stock
