

[All Products](#) / [Imaging Lenses](#) / [Zoom & Variable Magnification Lenses](#) / [High Magnification Long Working Distance Zoom Lenses](#)

Infiniprobe™ UV Microscopes See More by [Infinity Photo-Optical Company](#)



- Available in Standard and Right Angle Versions
- Magnification Range from 0X to 8.0X
- Max. 2/3" Sensor Format
- Direct Video C-Mount Coupling
- No Adapters Required

Common Specifications

Sensor

Maximum Sensor Format:

2/3"


Threading & Mounting

Mount:


C-Mount

Technical Information


Infiniprobe™ UV Video Microscopes Right Angle Configuration

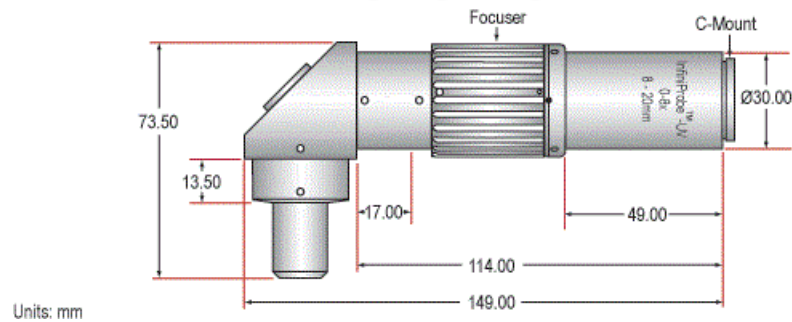

Infiniprobe™ UV Video Microscopes Standard Configuration

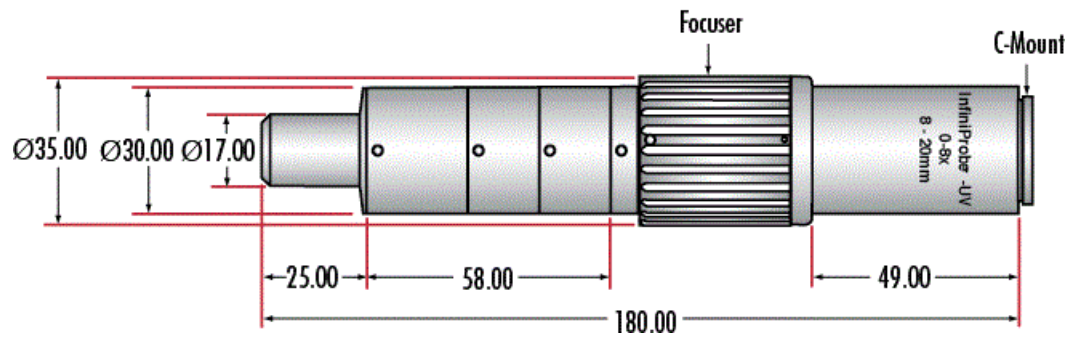

Standard S-32 Configuration

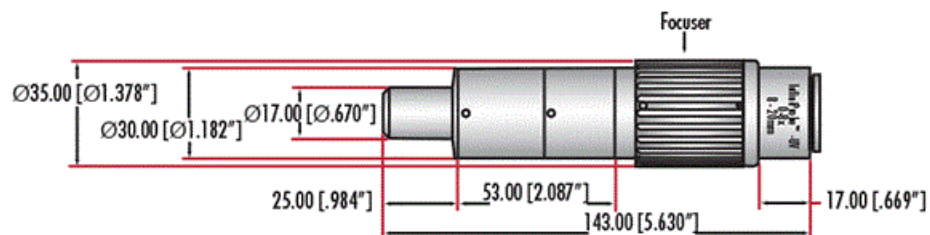

Products

Title	Stock Number	Price	Buy
Infiniprobe S-80 UV Video Microscope	#58-946	£3,565.75	Contact Us
Infiniprobe N-80 UV Right Angle Video Microscope	#59-121	£3,905.75	Contact Us
Infiniprobe S-32 UV Video Microscope	#62-853	£2,932.50	Contact Us
Infiniprobe N-32 UV Right Angle Video Microscope	#62-854	£3,251.25	Contact Us



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

www.edmundoptics.com