

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Bandpass Filters](#)

TECHSPEC® Hard Coated OD 4.0 50nm Bandpass Filters



- High Transmission, Deep Blocking
- Broad Bandwidths Ideal for Imaging Applications
- Available in VIS and IR Center Wavelengths
- [Hard Coated OD 4.0 10nm](#) and [25nm](#) Bandpass Filters Also Available

Common Specifications

Physical & Mechanical Properties

Construction: Mounted in Black Anodized Ring	Physical Durability: Adhesion per MIL-PRF-13830B, Section C.4.5.12 Moderate abrasion per MIL-PRF-13830B, Section C.4.5.11 Cleaning per MIL-C-48497A Section 4.5.4.2
---	--

Optical Properties

Angle of Incidence (°): 0	Bandwidth (nm): 45
Optical Density OD (Average): ≥ 4.0	Substrate: Optical Glass
Coating: Hard Coated	Surface Quality: 80-50


Threading & Mounting

Mount Thickness (mm): 5.0 $\pm$ 0.1
--

Environmental & Durability Factors

Environmental Durability: Humidity per MIL-STD-810H, Section 507.6 Temperature per MIL-STD-810H, Section 501.7 and 502.7
--

Technical Information

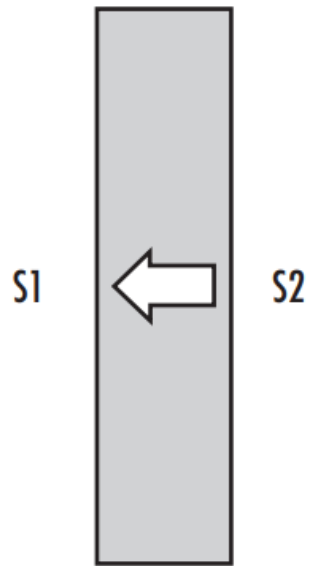

All mounted TECHSPEC® Optical Filters have an arrow on the side of the mount that points to the filter-coated surface for quick reference. Filter oriented such that arrow points to filter coated surface S1. Anti-reflective (AR) coating is applied to S2.

Products

Dia. (mm)	CWL (nm)	FWHM (nm)	Minimum Transmission (%)	Blocking Wavelength Range (nm)	Stock Number	Price	Buy
12.50	300.00	50.00	≥60	200 - 1200	#12-088	£167.22 Volume Pricing	Contact Us
25.00	300.00	50.00	≥60	200 - 1200	#12-093	£241.64 Volume Pricing	2 In Stock
50.00	300.00	50.00	≥60	200 - 1200	#12-097	£563.82 Volume Pricing	1 In Stock
12.50	325.00	50.00	>80	200 - 1200	#12-089	£167.22 Volume Pricing	20+ In Stock
25.00	325.00	50.00	>80	200 - 1200	#12-094	£241.64 Volume Pricing	5 In Stock
50.00	325.00	50.00	>80	200 - 1200	#12-098	£563.82 Volume Pricing	11 In Stock
12.50	350.00	50.00	>90	200 - 1200	#12-090	£167.22 Volume Pricing	20+ In Stock
25.00	350.00	50.00	>90	200 - 1200	#12-095	£241.64 Volume Pricing	6 In Stock
50.00	350.00	50.00	>90	200 - 1200	#12-099	£563.82 Volume Pricing	1 In Stock
12.50	375.00	50.00	>90	200 - 1200	#12-091	£167.22 Volume Pricing	16 In Stock
25.00	375.00	50.00	>90	200 - 1200	#12-096	£241.64 Volume Pricing	4 In Stock
50.00	375.00	50.00	>90	200 - 1200	#12-100	£563.82 Volume Pricing	Contact Us
12.50	400.00	50.00	≥90	200 - 1200	#84-769	£151.46 Volume Pricing	15 In Stock
25.00	400.00	50.00	≥90	200 - 1200	#84-781	£226.75 Volume Pricing	8 In Stock
50.00	400.00	50.00	≥90	200 - 1200	#84-793	£539.31 Volume Pricing	4 In Stock
12.50	425.00	50.00	≥90	200 - 1200	#86-937	£151.46 Volume Pricing	20+ In Stock
25.00	425.00	50.00	≥90	200 - 1200	#86-949	£226.75 Volume Pricing	3 In Stock

50.00	425.00	50.00	≥90	200 - 1200	#86-961	£539.31 Volume Pricing	5 In Stock
12.50	450.00	50.00	≥90	200 - 1200	#84-770	£151.46 Volume Pricing	20+ In Stock
25.00	450.00	50.00	≥90	200 - 1200	#84-782	£226.75 Volume Pricing	20+ In Stock
50.00	450.00	50.00	≥90	200 - 1200	#84-794	£539.31 Volume Pricing	7 In Stock
12.50	475.00	50.00	≥90	200 - 1200	#86-938	£151.46 Volume Pricing	20+ In Stock
25.00	475.00	50.00	≥90	200 - 1200	#86-950	£226.75 Volume Pricing	20+ In Stock
50.00	475.00	50.00	≥90	200 - 1200	#86-962	£539.31 Volume Pricing	4 In Stock
12.50	500.00	50.00	≥90	200 - 1200	#84-771	£151.46 Volume Pricing	20+ In Stock
25.00	500.00	50.00	≥90	200 - 1200	#84-783	£226.75 Volume Pricing	20+ In Stock
50.00	500.00	50.00	≥90	200 - 1200	#84-795	£539.31 Volume Pricing	1 In Stock
12.50	525.00	50.00	≥90	200 - 1200	#86-939	£151.46 Volume Pricing	20+ In Stock
25.00	525.00	50.00	≥90	200 - 1200	#86-951	£226.75 Volume Pricing	2 In Stock
50.00	525.00	50.00	≥90	200 - 1200	#86-963	£539.31 Volume Pricing	Contact Us
12.50	550.00	50.00	≥90	200 - 1200	#84-772	£151.46 Volume Pricing	20+ In Stock
25.00	550.00	50.00	≥90	200 - 1200	#84-784	£226.75 Volume Pricing	7 In Stock
50.00	550.00	50.00	≥90	200 - 1200	#84-796	£539.31 Volume Pricing	5 In Stock
12.50	575.00	50.00	≥90	200 - 1200	#86-940	£151.46 Volume Pricing	20+ In Stock
25.00	575.00	50.00	≥90	200 - 1200	#86-952	£226.75 Volume Pricing	12 In Stock
50.00	575.00	50.00	≥90	200 - 1200	#86-964	£539.31 Volume Pricing	2 In Stock
12.50	600.00	50.00	≥90	200 - 1200	#84-773	£151.46 Volume Pricing	16 In Stock

25.00	600.00	50.00	≥90	200 - 1200	#84-785	£226.75 Volume Pricing	20+ In Stock
50.00	600.00	50.00	≥90	200 - 1200	#84-797	£539.31 Volume Pricing	4 In Stock
12.50	625.00	50.00	≥90	200 - 1200	#86-941	£151.46 Volume Pricing	2 In Stock
25.00	625.00	50.00	≥90	200 - 1200	#86-953	£226.75 Volume Pricing	5 In Stock
50.00	625.00	50.00	≥90	200 - 1200	#86-965	£539.31 Volume Pricing	2 In Stock
12.50	650.00	50.00	≥90	200 - 1200	#84-774	£151.46 Volume Pricing	20+ In Stock
25.00	650.00	50.00	≥90	200 - 1200	#84-786	£226.75 Volume Pricing	12 In Stock
50.00	650.00	50.00	≥90	200 - 1200	#84-798	£539.31 Volume Pricing	1 In Stock
12.50	675.00	50.00	≥90	200 - 1200	#86-942	£151.46 Volume Pricing	4 In Stock
25.00	675.00	50.00	≥90	200 - 1200	#86-954	£226.75 Volume Pricing	5 In Stock
50.00	675.00	50.00	≥90	200 - 1200	#86-966	£539.31 Volume Pricing	8 In Stock
12.50	700.00	50.00	≥90	200 - 1200	#84-775	£151.46 Volume Pricing	Contact Us
25.00	700.00	50.00	≥90	200 - 1200	#84-787	£226.75 Volume Pricing	20+ In Stock
50.00	700.00	50.00	≥90	200 - 1200	#84-799	£539.31 Volume Pricing	11 In Stock
12.50	725.00	50.00	≥90	200 - 1200	#86-943	£167.22 Volume Pricing	20+ In Stock
25.00	725.00	50.00	≥90	200 - 1200	#86-955	£241.64 Volume Pricing	4 In Stock
50.00	725.00	50.00	≥90	200 - 1200	#86-967	£563.82 Volume Pricing	12 In Stock
12.50	750.00	50.00	≥90	200 - 1200	#84-776	£167.22 Volume Pricing	20+ In Stock
25.00	750.00	50.00	≥90	200 - 1200	#84-788	£241.64 Volume Pricing	2 In Stock
50.00	750.00	50.00	≥90	200 - 1200	#84-800	£563.82 Volume Pricing	6 In Stock

12.50	775.00	50.00	≥90	200 - 1200	#86-944	£167.22 Volume Pricing	20+ In Stock
25.00	775.00	50.00	≥90	200 - 1200	#86-956	£241.64 Volume Pricing	5 In Stock
50.00	775.00	50.00	≥90	200 - 1200	#86-968	£563.82 Volume Pricing	5 In Stock
12.50	800.00	50.00	≥90	200 - 1200	#84-777	£167.22 Volume Pricing	20+ In Stock
25.00	800.00	50.00	≥90	200 - 1200	#84-789	£241.64 Volume Pricing	Contact Us
50.00	800.00	50.00	≥90	200 - 1200	#84-801	£563.82 Volume Pricing	5 In Stock
12.50	825.00	50.00	≥90	200 - 1200	#86-945	£167.22 Volume Pricing	6 In Stock
25.00	825.00	50.00	≥90	200 - 1200	#86-957	£241.64 Volume Pricing	20+ In Stock
50.00	825.00	50.00	≥90	200 - 1200	#86-969	£563.82 Volume Pricing	3 In Stock
12.50	850.00	50.00	≥90	200 - 1200	#84-778	£167.22 Volume Pricing	5 In Stock
25.00	850.00	50.00	≥90	200 - 1200	#84-790	£241.64 Volume Pricing	5 In Stock
50.00	850.00	50.00	≥90	200 - 1200	#84-802	£563.82 Volume Pricing	2 In Stock
12.50	875.00	50.00	≥90	200 - 1200	#86-946	£167.22 Volume Pricing	20+ In Stock
25.00	875.00	50.00	≥90	200 - 1200	#86-958	£241.64 Volume Pricing	14 In Stock
50.00	875.00	50.00	≥90	200 - 1200	#86-970	£563.82 Volume Pricing	10 In Stock
12.50	900.00	50.00	≥90	200 - 1200	#84-779	£167.22 Volume Pricing	20+ In Stock
25.00	900.00	50.00	≥90	200 - 1200	#84-791	£241.64 Volume Pricing	6 In Stock
50.00	900.00	50.00	≥90	200 - 1200	#84-803	£563.82 Volume Pricing	11 In Stock
12.50	925.00	50.00	≥90	200 - 1200	#86-947	£167.22 Volume Pricing	9 In Stock
25.00	925.00	50.00	≥90	200 - 1200	#86-959	£241.64 Volume Pricing	11 In Stock

50.00	925.00	50.00	≥90	200 - 1200	#86-971	£563.82 Volume Pricing	1 In Stock
12.50	950.00	50.00	≥90	200 - 1200	#84-780	£167.22 Volume Pricing	20+ In Stock
25.00	950.00	50.00	≥90	200 - 1200	#84-792	£241.64 Volume Pricing	20+ In Stock
50.00	950.00	50.00	≥90	200 - 1200	#84-804	£563.82 Volume Pricing	6 In Stock
12.50	975.00	50.00	≥90	200 - 1200	#86-948	£167.22 Volume Pricing	20+ In Stock
25.00	975.00	50.00	≥90	200 - 1200	#86-960	£241.64 Volume Pricing	Contact Us
50.00	975.00	50.00	≥90	200 - 1200	#86-972	£563.82 Volume Pricing	5 In Stock
12.50	1,000.00	50.00	≥90	200 - 1500	#85-880	£196.99 Volume Pricing	5 In Stock
25.00	1,000.00	50.00	≥90	200 - 1500	#85-892	£292.42 Volume Pricing	9 In Stock
50.00	1,000.00	50.00	≥90	200 - 1500	#85-904	£700.40 Volume Pricing	2 In Stock
12.50	1,025.00	50.00	>90	200 - 1500	#87-847	£196.99 Volume Pricing	10 In Stock
25.00	1,025.00	50.00	>90	200 - 1500	#87-860	£295.04 Volume Pricing	2 In Stock
50.00	1,025.00	50.00	>90	200 - 1500	#87-873	£700.40 Volume Pricing	1 In Stock
12.50	1,050.00	50.00	≥90	200 - 1500	#85-881	£196.99 Volume Pricing	20+ In Stock
25.00	1,050.00	50.00	≥90	200 - 1500	#85-893	£295.04 Volume Pricing	8 In Stock
50.00	1,050.00	50.00	≥90	200 - 1500	#85-905	£700.40 Volume Pricing	8 In Stock
12.50	1,075.00	50.00	>90	200 - 1500	#87-848	£196.99 Volume Pricing	20+ In Stock
25.00	1,075.00	50.00	>90	200 - 1500	#87-861	£295.04 Volume Pricing	20+ In Stock
50.00	1,075.00	50.00	>90	200 - 1500	#87-874	£700.40 Volume Pricing	3 In Stock
12.50	1,100.00	50.00	≥90	200 - 1500	#85-882	£196.99 Volume Pricing	3 In Stock

25.00	1,100.00	50.00	≥90	200 - 1500	#85-894	£295.04 Volume Pricing	9 In Stock
50.00	1,100.00	50.00	≥90	200 - 1500	#85-906	£700.40 Volume Pricing	1 In Stock
12.50	1,125.00	50.00	>90	200 - 1500	#87-849	£196.99 Volume Pricing	Contact Us
25.00	1,125.00	50.00	>90	200 - 1500	#87-862	£295.04 Volume Pricing	20+ In Stock
50.00	1,125.00	50.00	>90	200 - 1500	#87-875	£700.40 Volume Pricing	5 In Stock
12.50	1,150.00	50.00	≥90	200 - 1500	#85-883	£196.99 Volume Pricing	Contact Us
25.00	1,150.00	50.00	≥90	200 - 1500	#85-895	£295.04 Volume Pricing	5 In Stock
50.00	1,150.00	50.00	≥90	200 - 1500	#85-907	£700.40 Volume Pricing	2 In Stock
12.50	1,175.00	50.00	>90	200 - 1500	#87-850	£196.99 Volume Pricing	5 In Stock
25.00	1,175.00	50.00	>90	200 - 1500	#87-863	£295.04 Volume Pricing	3 In Stock
50.00	1,175.00	50.00	>90	200 - 1500	#87-876	£700.40 Volume Pricing	1 In Stock
12.50	1,200.00	50.00	≥90	200 - 1500	#85-884	£196.99 Volume Pricing	5 In Stock
25.00	1,200.00	50.00	≥90	200 - 1500	#85-896	£295.04 Volume Pricing	7 In Stock
50.00	1,200.00	50.00	≥90	200 - 1500	#85-908	£700.40 Volume Pricing	1 In Stock
12.50	1,225.00	50.00	>90	200 - 1800	#87-851	£196.99 Volume Pricing	1 In Stock
25.00	1,225.00	50.00	>90	200 - 1800	#87-864	£295.04 Volume Pricing	1 In Stock
50.00	1,225.00	50.00	>90	200 - 1800	#87-877	£700.40 Volume Pricing	1 In Stock
12.50	1,250.00	50.00	≥90	200 - 1800	#85-885	£196.99 Volume Pricing	4 In Stock
25.00	1,250.00	50.00	≥90	200 - 1800	#85-897	£295.04 Volume Pricing	3 In Stock
50.00	1,250.00	50.00	≥90	200 - 1800	#85-909	£700.40 Volume Pricing	3 In Stock

12.50	1,275.00	50.00	>90	200 - 1800	#87-852	£196.99 Volume Pricing	2 In Stock
25.00	1,275.00	50.00	>90	200 - 1800	#87-865	£295.04 Volume Pricing	4 In Stock
50.00	1,275.00	50.00	>90	200 - 1800	#87-878	£700.40 Volume Pricing	1 In Stock
12.50	1,300.00	50.00	≥90	200 - 1800	#85-886	£196.99 Volume Pricing	14 In Stock
25.00	1,300.00	50.00	≥90	200 - 1800	#85-898	£295.04 Volume Pricing	17 In Stock
50.00	1,300.00	50.00	≥90	200 - 1800	#85-910	£700.40 Volume Pricing	3 In Stock
12.50	1,325.00	50.00	>90	200 - 1800	#87-853	£196.99 Volume Pricing	1 In Stock
25.00	1,325.00	50.00	>90	200 - 1800	#87-866	£295.04 Volume Pricing	3 In Stock
50.00	1,325.00	50.00	>90	200 - 1800	#87-879	£700.40 Volume Pricing	12 In Stock
12.50	1,350.00	50.00	≥90	200 - 1800	#85-887	£196.99 Volume Pricing	5 In Stock
25.00	1,350.00	50.00	≥90	200 - 1800	#85-899	£295.04 Volume Pricing	20+ In Stock
50.00	1,350.00	50.00	≥90	200 - 1800	#85-911	£700.40 Volume Pricing	4 In Stock
12.50	1,375.00	50.00	>90	200 - 1800	#87-854	£196.99 Volume Pricing	20+ In Stock
25.00	1,375.00	50.00	>90	200 - 1800	#87-867	£295.04 Volume Pricing	12 In Stock
50.00	1,375.00	50.00	>90	200 - 1800	#87-880	£700.40 Volume Pricing	2 In Stock
12.50	1,400.00	50.00	≥90	200 - 1800	#85-888	£196.99 Volume Pricing	1 In Stock
25.00	1,400.00	50.00	≥90	200 - 1800	#85-900	£295.04 Volume Pricing	6 In Stock
50.00	1,400.00	50.00	≥90	200 - 1800	#85-912	£700.40 Volume Pricing	5 In Stock
12.50	1,425.00	50.00	>90	200 - 1800	#87-855	£196.99 Volume Pricing	3 In Stock
25.00	1,425.00	50.00	>90	200 - 1800	#87-868	£295.04 Volume Pricing	1 In Stock

50.00	1,425.00	50.00	>90	200 - 1800	#87-881	£700.40 Volume Pricing	4 In Stock
12.50	1,450.00	50.00	≥90	200 - 1800	#85-889	£196.99 Volume Pricing	2 In Stock
25.00	1,450.00	50.00	≥90	200 - 1800	#85-901	£295.04 Volume Pricing	3 In Stock
50.00	1,450.00	50.00	≥90	200 - 1800	#85-913	£700.40 Volume Pricing	7 In Stock
12.50	1,475.00	50.00	>90	200 - 1800	#87-856	£196.99 Volume Pricing	1 In Stock
25.00	1,475.00	50.00	>90	200 - 1800	#87-869	£295.04 Volume Pricing	3 In Stock
50.00	1,475.00	50.00	>90	200 - 1800	#87-882	£700.40 Volume Pricing	8 In Stock
12.50	1,500.00	50.00	≥90	200 - 1800	#85-890	£196.99 Volume Pricing	1 In Stock
25.00	1,500.00	50.00	≥90	200 - 1800	#85-902	£295.04 Volume Pricing	17 In Stock
50.00	1,500.00	50.00	≥90	200 - 1800	#85-914	£700.40 Volume Pricing	1 In Stock
12.50	1,525.00	50.00	>90	200 - 1800	#87-857	£196.99 Volume Pricing	16 In Stock
25.00	1,525.00	50.00	>90	200 - 1800	#87-870	£295.04 Volume Pricing	4 In Stock
50.00	1,525.00	50.00	>90	200 - 1800	#87-883	£700.40 Volume Pricing	Contact Us
12.50	1,550.00	50.00	≥90	200 - 1800	#85-891	£196.99 Volume Pricing	4 In Stock
25.00	1,550.00	50.00	≥90	200 - 1800	#85-903	£295.04 Volume Pricing	20+ In Stock
50.00	1,550.00	50.00	≥90	200 - 1800	#85-915	£700.40 Volume Pricing	5 In Stock
12.50	1,575.00	50.00	>90	200 - 1800	#87-858	£196.99 Volume Pricing	20+ In Stock
25.00	1,575.00	50.00	>90	200 - 1800	#87-871	£295.04 Volume Pricing	20+ In Stock
50.00	1,575.00	50.00	>90	200 - 1800	#87-884	£700.40 Volume Pricing	3 In Stock
12.50	1,600.00	50.00	>90	200 - 1800	#87-859	£196.99 Volume Pricing	2 In Stock

25.00	1,600.00	50.00	>90	200 - 1800	#87-872	£295.04 Volume Pricing	12 In Stock
50.00	1,600.00	50.00	>90	200 - 1800	#87-885	£700.40 Volume Pricing	2 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
 Phone: 1-800-363-1992 :
www.edmundoptics.com