


[All Products](#) / [Optics](#) / [Polarization Optics](#) / [Linear Polarizers](#) / [Absorptive \(Dichroic\) Polarizers](#) / [Polymer Film Polarizers](#)

TECHSPEC® High-Temperature Linear Polarizing Film (XP40HT)

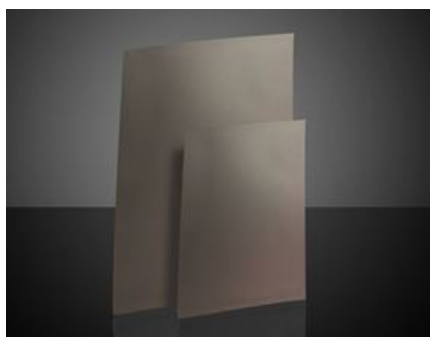

- High-Temperature Resistance Compared with Common Polarizing Films
- Extinction Ratio of 5000:1
- High Transmission of Unpolarized Light from 400 - 700nm
- Custom Sizes Available

Common Specifications

Physical & Mechanical Properties

Construction:	Polarizing Film
---------------	-----------------

Optical Properties

Extinction Ratio:	5000:1
-------------------	--------

Wavelength Range (nm):	400 - 700
------------------------	-----------

Environmental & Durability Factors

Heat Resistance (°C x Hours):	100 x 1,000
-------------------------------	-------------

Cold Resistance (°C x Hours):	-40 x 1,000
-------------------------------	-------------

Humidity Resistance (°C x Hours):	80 x 90% RH x 1,000
-----------------------------------	---------------------

Technical Information

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Substrate	Stock Number	Price	Buy
10.00	-	0.19	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 18	#73-133	£15.76 Volume Pricing	20+ In Stock
10.00	-	0.40	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 40	#73-141	£15.76 Volume Pricing	20+ In Stock
12.50	-	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-465	£16.63 Volume Pricing	20+ In Stock
12.50	-	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-476	£16.63 Volume Pricing	20+ In Stock
15.00	-	0.19	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 18	#73-136	£17.51 Volume Pricing	20+ In Stock
15.00	-	0.40	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 40	#73-142	£17.51 Volume Pricing	20+ In Stock
20.00	-	0.19	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 18	#73-137	£18.39 Volume Pricing	20+ In Stock
20.00	-	0.40	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 40	#73-148	£18.39 Volume Pricing	20+ In Stock
25.00	-	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-466	£19.26 Volume Pricing	20+ In Stock

25.00	-	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-477	£19.26 Volume Pricing	20+ In Stock
-	25.0 x 25.0	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-456	£19.26 Volume Pricing	10 In Stock
-	25.0 x 25.0	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-468	£19.26 Volume Pricing	16 In Stock
30.00	-	0.19	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 18	#73-138	£21.01 Volume Pricing	20+ In Stock
30.00	-	0.40	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 40	#73-149	£21.01 Volume Pricing	20+ In Stock
40.00	-	0.19	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 18	#73-140	£24.51 Volume Pricing	20+ In Stock
40.00	-	0.40	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 40	#73-150	£24.51 Volume Pricing	20+ In Stock
50.00	-	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-467	£26.27 Volume Pricing	20+ In Stock
50.00	-	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-478	£26.27 Volume Pricing	20+ In Stock
-	50.0 x 50.0	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-457	£26.27 Volume Pricing	15 In Stock

-	50.0 x 50.0	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-469	£26.27 Volume Pricing	8 In Stock
-	100.0 x 100.0	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-458	£45.53 Volume Pricing	6 In Stock
-	100.0 x 100.0	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-470	£45.53 Volume Pricing	20+ In Stock
-	150.0 x 150.0	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-459	£61.29 Volume Pricing	20+ In Stock
-	150.0 x 150.0	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-471	£61.29 Volume Pricing	6 In Stock
-	200.0 x 200.0	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-460	£105.06 Volume Pricing	20+ In Stock
-	200.0 x 200.0	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-472	£105.06 Volume Pricing	13 In Stock
-	300.0 x 300.0	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-461	£173.35 Volume Pricing	9 In Stock
-	300.0 x 300.0	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-473	£173.35 Volume Pricing	9 In Stock
-	500.0 x 600.0	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-462	£255.65 Volume Pricing	13 In Stock

-	600.0 x 500.0	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-475	£255.65 Volume Pricing	3 In Stock
-	600.0 x 1000.0	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-464	£367.71 Volume Pricing	6 In Stock
-	600.0 x 1000.0	0.22	Pressure Sensitive Adhesive (PSA) one- sided, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-463	£367.71 Volume Pricing	1 In Stock
-	600.0 x 1000.0	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-474	£367.71 Volume Pricing	9 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 :
www.edmundoptics.com