


[All Products](#) / [Optics](#) / [SCHOTT Optical Components](#)

SCHOTT NG Gray Glass Neutral Density (ND) Filters See More by [SCHOTT Optical Components](#)

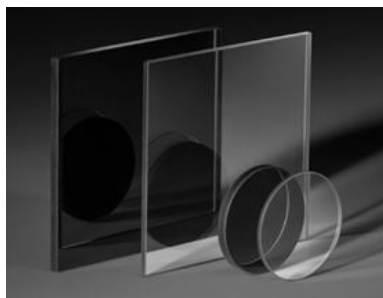

- Tightly Controlled Thickness Specifications
- Standard Thicknesses of 1, 2, and 3mm
- Even Light Attenuation in the Visible Spectrum
- NG1, NG3, NG4, NG5, NG9 and NG11 Glass Types Available
- [Precision SCHOTT NG Glass Filters](#) Also Available


Common Specifications

Physical & Mechanical Properties


Parallelism (arcmin):	≤3	Dimensional Tolerance (mm):	±0.2
Optical Properties			
Coating:	Uncoated	Surface Quality:	60-40
Transmission Tolerance (%):	(nominal)	Optical Density Tolerance (%):	(nominal)

Technical Information

Schott NG Absorptive ND Filters
(1mm Thickness) Visible Spectrum

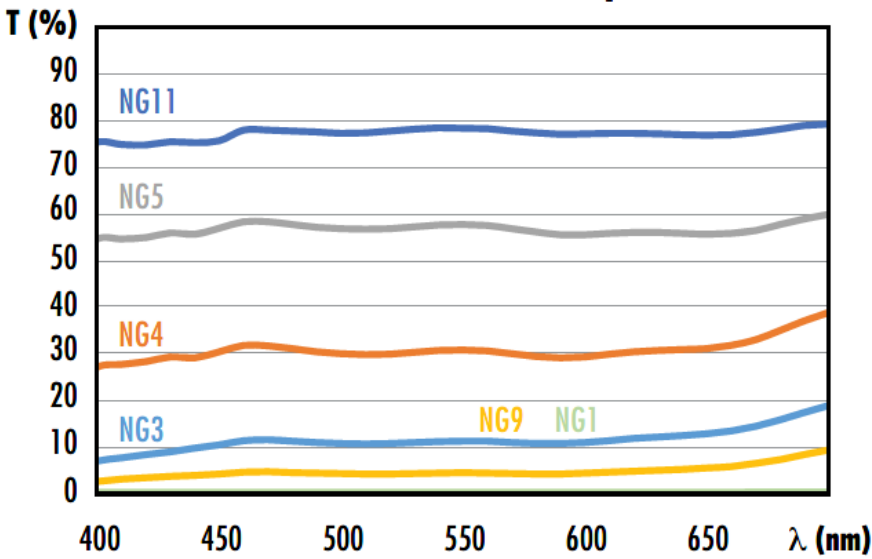

Schott NG Absorptive ND Filters (1mm Thickness) Extended Spectrum

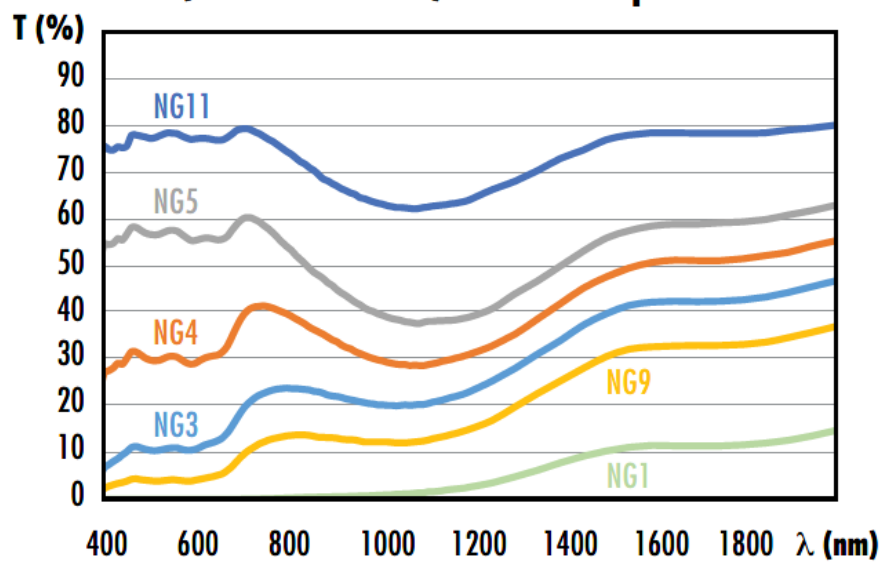

Products

Dia. (mm)	Dimensions (mm)	Optical Density OD (Average)	Glass/Filter Number	Thickness (mm)	Transmission (%)	Stock Number	Price	Buy
25.00	-	4.84	SCHOTT NG1	1.00	0.001	#14-075	£38.52 Volume Pricing	5 In Stock
25.00	-	>5	SCHOTT NG1	2.00	<0.001	#14-077	£38.52 Volume Pricing	13 In Stock
25.00	-	>5	SCHOTT NG1	3.00	<0.001	#14-079	£38.52 Volume Pricing	9 In Stock
-	50.0 x 50.0	4.84	SCHOTT NG1	1.00	0.001	#14-074	£84.92 Volume Pricing	16 In Stock
-	50.0 x 50.0	>5	SCHOTT NG1	2.00	<0.001	#14-076	£84.92 Volume Pricing	12 In Stock
-	50.0 x 50.0	>5	SCHOTT NG1	3.00	<0.001	#14-078	£84.92 Volume Pricing	7 In Stock
25.00	-	0.99	SCHOTT NG3	1.00	10	#14-081	£38.52 Volume Pricing	10 In Stock
25.00	-	1.95	SCHOTT NG3	2.00	1.1	#14-083	£38.52 Volume Pricing	12 In Stock
25.00	-	2.91	SCHOTT NG3	3.00	0.12	#14-085	£38.52 Volume Pricing	16 In Stock
-	50.0 x 50.0	0.99	SCHOTT NG3	1.00	10	#14-080	£84.92 Volume Pricing	14 In Stock
-	50.0 x 50.0	1.95	SCHOTT NG3	2.00	1.1	#14-082	£84.92 Volume Pricing	17 In Stock
-	50.0 x 50.0	2.91	SCHOTT NG3	3.00	0.12	#14-084	£84.92 Volume Pricing	14 In Stock
25.00	-	0.55	SCHOTT NG4	1.00	28	#14-087	£38.52 Volume Pricing	12 In Stock
25.00	-	1.06	SCHOTT NG4	2.00	8.6	#14-089	£38.52 Volume Pricing	17 In Stock
25.00	-	1.58	SCHOTT NG4	3.00	2.6	#14-091	£38.52 Volume Pricing	12 In Stock
-	50.0 x 50.0	0.55	SCHOTT NG4	1.00	28	#14-086	£84.92 Volume Pricing	20+ In Stock
-	50.0 x 50.0	1.06	SCHOTT NG4	2.00	8.6	#14-088	£84.92 Volume Pricing	16 In Stock
-	50.0 x 50.0	1.58	SCHOTT NG4	3.00	2.6	#14-090	£84.92 Volume Pricing	11 In Stock
25.00	-	0.28	SCHOTT NG5	1.00	53	#14-093	£38.52 Volume Pricing	12 In Stock

25.00	-	0.51	SCHOTT NG5	2.00	31	#14-095	£38.52 Volume Pricing	20+ In Stock
25.00	-	0.75	SCHOTT NG5	3.00	18	#14-097	£38.52 Volume Pricing	15 In Stock
-	50.0 x 50.0	0.28	SCHOTT NG5	1.00	53	#14-092	£84.92 Volume Pricing	11 In Stock
-	50.0 x 50.0	0.51	SCHOTT NG5	2.00	31	#14-094	£84.92 Volume Pricing	8 In Stock
-	50.0 x 50.0	0.75	SCHOTT NG5	3.00	18	#14-096	£84.92 Volume Pricing	14 In Stock
25.00	-	1.42	SCHOTT NG9	1.00	3.8	#14-099	£38.52 Volume Pricing	14 In Stock
25.00	-	2.8	SCHOTT NG9	2.00	0.15	#14-101	£38.52 Volume Pricing	11 In Stock
25.00	-	4.18	SCHOTT NG9	3.00	0.007	#14-103	£38.52 Volume Pricing	13 In Stock
-	50.0 x 50.0	1.42	SCHOTT NG9	1.00	3.8	#14-098	£84.92 Volume Pricing	7 In Stock
-	50.0 x 50.0	2.8	SCHOTT NG9	2.00	0.15	#14-100	£84.92 Volume Pricing	14 In Stock
-	50.0 x 50.0	4.18	SCHOTT NG9	3.00	0.007	#14-102	£84.92 Volume Pricing	13 In Stock
25.00	-	0.14	SCHOTT NG11	1.00	72	#14-105	£38.52 Volume Pricing	11 In Stock
25.00	-	0.25	SCHOTT NG11	2.00	56	#14-107	£38.52 Volume Pricing	13 In Stock
25.00	-	0.35	SCHOTT NG11	3.00	44	#14-109	£38.52 Volume Pricing	16 In Stock
-	50.0 x 50.0	0.14	SCHOTT NG11	1.00	72	#14-104	£84.92 Volume Pricing	16 In Stock
-	50.0 x 50.0	0.25	SCHOTT NG11	2.00	56	#14-106	£84.92 Volume Pricing	14 In Stock
-	50.0 x 50.0	0.35	SCHOTT NG11	3.00	44	#14-108	£84.92 Volume Pricing	12 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 :
www.edmundoptics.com