


[All Products](#) / [Optomechanics](#) / [Motorized Translation Stages](#) / [Motorized Linear Stages](#)

TECHSPEC®

Crossed-Roller Bearing Piezo Tunable Linear Stages

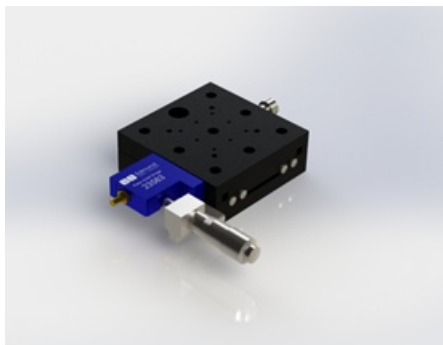

- Micrometer with Separate Piezo Actuator for Fine Adjustment
- 40 x 40mm and 70x70mm in English and Metric Hole Patterns Available
- Easily Assembled into X-Y and X-Y-Z Configurations

Common Specifications

Physical & Mechanical Properties

Type of Movement:	Linear (X)	Guide System:	Crossed Roller Bearing
Drive Orientation:	Side Drive	Construction:	Aluminium Stage
Straight Line Accuracy (µm):	2	Pitch (arcsec):	30
Yaw (arcsec):	25	Piezo Travel (mm):	0.03
Piezo Resolution (nm):	20.00		

Optical Properties

Resolution (µm):	10
-------------------------	----

Technical Information

Products

Stage Size (mm)	Type	Travel (mm)	Travel (inches)	Stock Number	Price	Buy
40 x 40	Metric	13	-	#23-582	£857.99	2 In Stock
70 x 70	Metric	13	-	#23-583	£954.30	3 In Stock
40 x 40	English	-	0.5	#23-584	£857.99	1 In Stock
70 x 70	English	-	0.5	#23-585	£954.30	4 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 :
www.edmundoptics.com