

Nikon 200mm Tube Lens

See More by [Nikon](#)



#58-520: Nikon 200mm Tube Lens

Stock **#58-520** **20+ In Stock**

-

1

+

£428⁰⁰

ADD TO CART

Volume Pricing	
Qty 1+	£428.88 each
Need More?	Request Quote

Prices shown are exclusive of VAT/local taxes

Product Downloads

SPECIFICATIONS

General

Type:

Tube Lens

Manufacturer:

Nikon

Physical & Mechanical Properties

Length (mm):

29.00


36.0	Maximum Diameter (mm):
Optical Properties	
200.00	Focal Length FL (mm):
1X	Magnification:
400 - 700	Wavelength Range (nm):
26.5	Field Number (mm):
32.0	Entrance Pupil Diameter (mm):
Threading & Mounting	
M88 x0.5	Mounting Threads:
Regulatory Compliance	
Compliant	RoHS 2015:
View	Certificate of Conformance:

PRODUCT DETAILS

- Superior UV Transmission
- High Numerical Aperture Designs
- Feature Low Auto-Fluorescence Materials

Nikon CFI Super Fluor Objectives are designed to provide superior transmission to ultraviolet applications operating down to 340nm, including for use with fluorochromes indo-1, fura-2, and fluo-3, or for photo-activation of caged compounds. Nikon CFI Super Fluor Objectives are designed using low auto-fluorescence materials along with high numerical apertures to guarantee sharp, bright fluorescence images. These microscope objectives have been optimized for improved signal-to-noise ratios at short wavelengths.

TECHNICAL INFORMATION

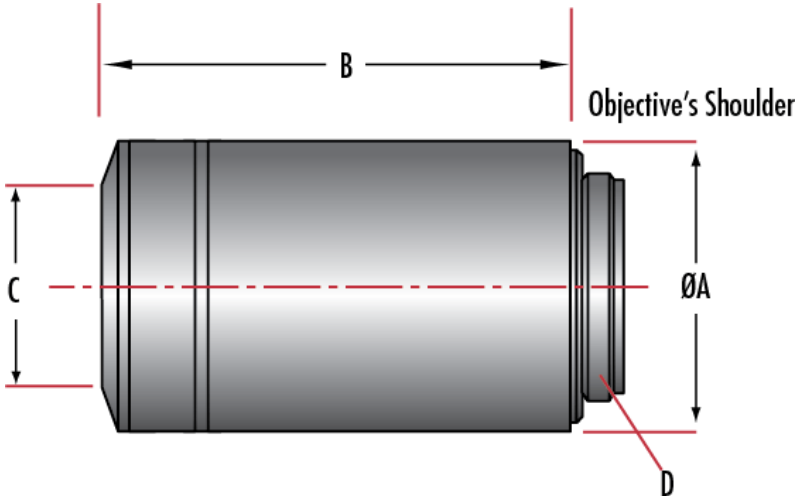

Dimensions (mm)						
Stock No.	Magnification	Parafoal Length	A	B	C	
#88-374	4X	60.06	30.0	44.4	19.7	
#88-375	10X	60.06	32.0	58.7	8.0	
#88-376	20X	60.06	33.5	58.9	9.0	
#88-377	40X	60.06	33.0	59.6	7.5	