


[All Products](#) / [Test Targets](#) / [Resolution Test Targets](#) / [Star Target](#)

[See all 4 Products in Family](#)

Siemens Star Target, 60mm Dia., 36 Sectors Chrome on Glass

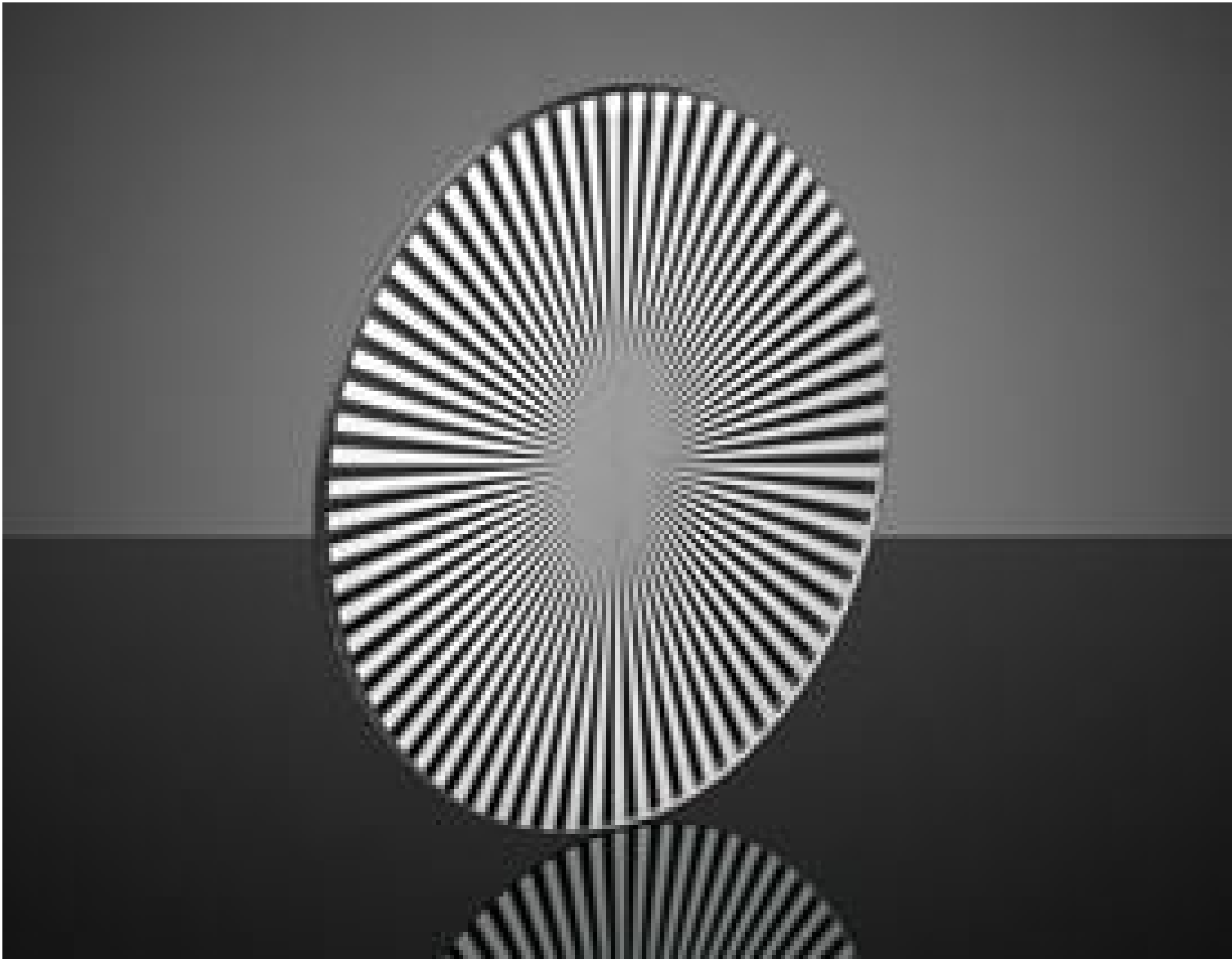

Glass Star Target

Stock **#58-832** 3-4 DAYS



1



£369.75

ADD TO CART

Qty 1-4

£369.75

Qty 5+

£351.56

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Coating:
Physical Vapor Deposition (Chromium Coating)

Diameter (mm):
60.00 ±0.1

Frequency (lp/mm):
0.229 - 114.6

Substrate: Float Glass
Line Width (mm): 2.2 - 0.004
Number of Sectors: 36
Optical Density OD (Average): >3.5
Pattern Diameter (mm): 50.00
Thickness (mm): 1.50 ±0.05
Wedge Angle: 10°
Unresolved Core Diameter (mm): 0.1
NIST Certification: No

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View