


10 x 10mm, 0.21mm Thick, Chemically Strengthened SCHOTT AS 87 eco Ultra-Thin Window

See More by [SCHOTT Optical Components](#)

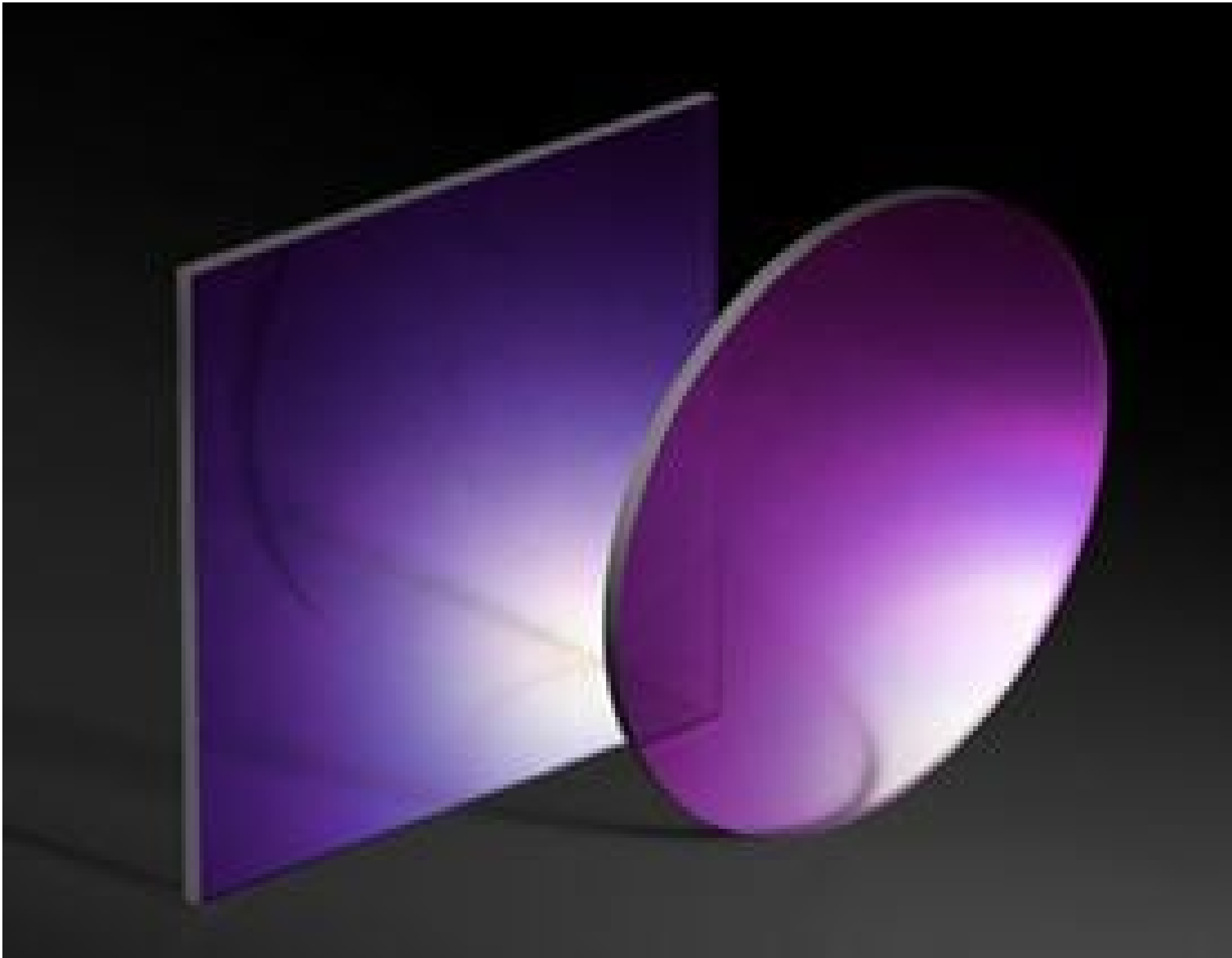

Stock #22-240

3-4 DAYS

-

1

+

£30.60

ADD TO CART

Qty 1-10
£30.60
Qty 11+
£24.44
Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Abbe Number (v_d):

59.5

Bevel:

Protective as needed

Clear Aperture (%) : 90
Clear Aperture CA (mm) : 9.00 x 9.00
Dimensions (mm) : 10.00 x 10.00 ±0.127
Thickness (mm) : 0.21 ±0.02
Coating : Uncoated
Coefficient of Thermal Expansion CTE (10⁻⁶/°C) : 8.7
Density (g/cm³) : 2.46
Index of Refraction n_d : 1.504
Knoop Hardness (kg/mm²) : 560
Poisson's Ratio : 0.216
Substrate : AS 87 ECO
Surface Quality : 80-50
Type : Protective Window
Wavelength Range (nm) : 200 - 3200
Young's Modulus (GPa) : 73.3
Length (mm) : 10.00
Width (mm) : 10.00

Regulatory Compliance

RoHS 2015 : Compliant
Certificate of Conformance : View
Reach 233 : Compliant