


100 x 100mm, Green 530nm, MicroBrite High Intensity Edge-Lit Backlights

See More by [Advanced Illumination](#)

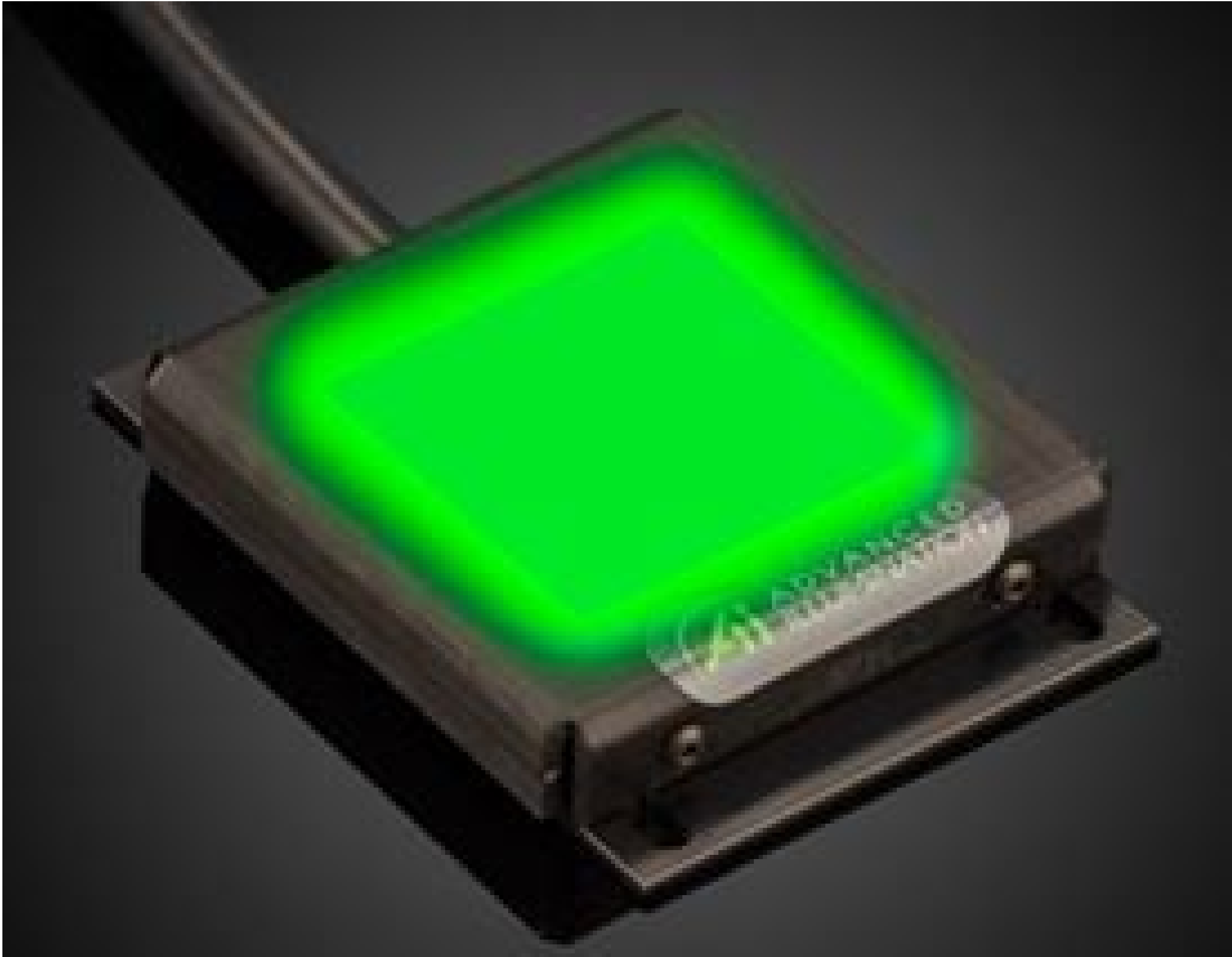

Stock #18-555 3-4 DAYS

⊖ 1 ⊕ **£802.40**

ADD TO CART

Qty 1+

£802.40

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Color:
Green

Input Voltage (V):
24V

Model Number:
BT100100-530IC

Operating Temperature (°C):
0 - 60

Dimensions (mm):

120.02 x 104.60 x 11.25
Wavelength (nm): 530.00
Weight (g): 195.04
LED Lifetime (hours): 50,000
Active Area (inches): 3.36 x 3.31
Type of Illumination: LED Illuminator
Note: Optional Manual Intensity Adjustment #86-887 and #89-555 are Available
Manufacturer: Advanced Illumination
Geometry: Backlight
Illumination Mode: Constant
Environmental Rating: IP50

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 233: Contains SVHC(s)