


TECHSPEC® 10mm Aperture, 75mm L High NA, Hexagonal Light Pipe

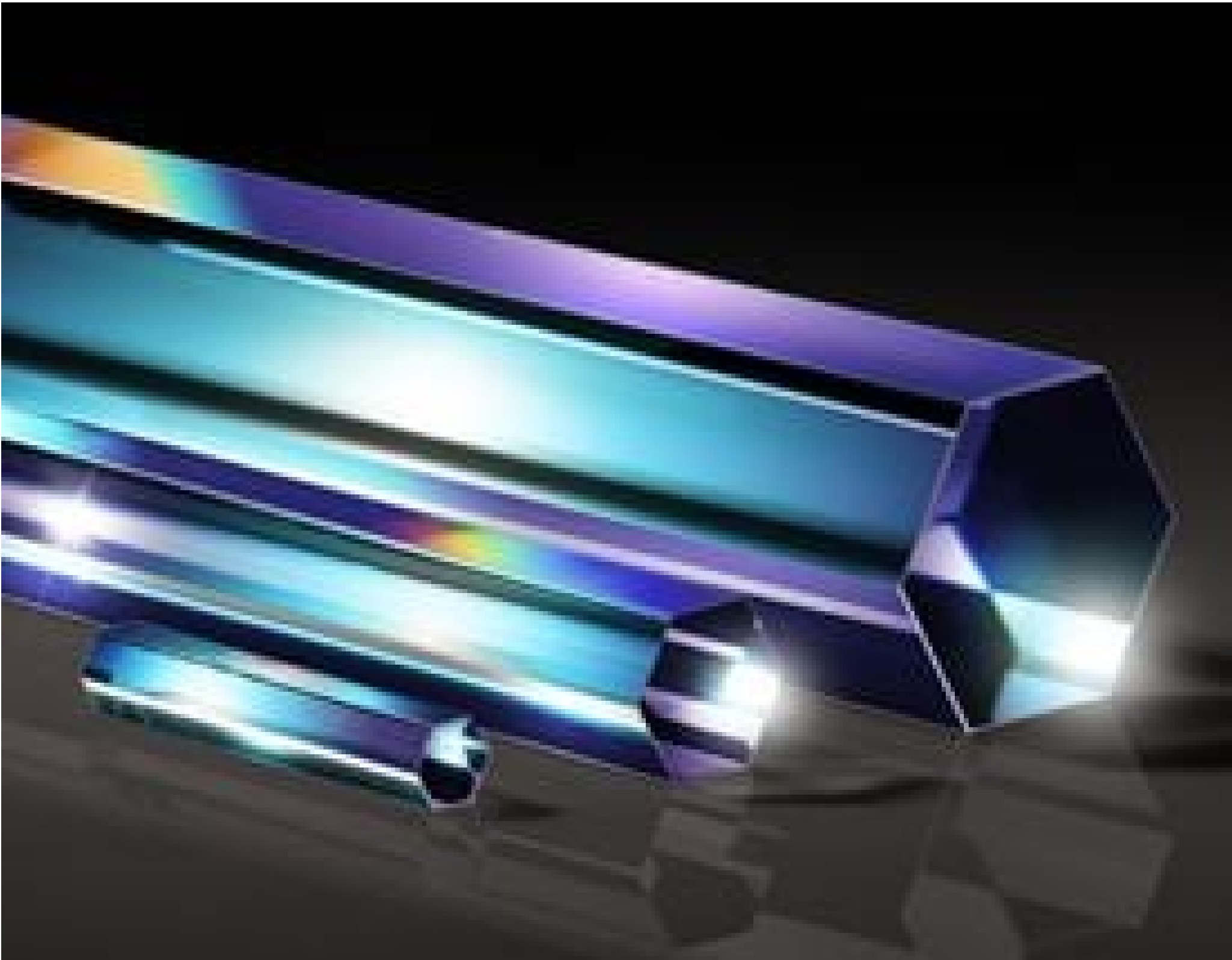

N-BK7 Light Pipe Homogenizing Rods



Stock **#63-090** 3-4 DAYS

⊖ 1 ⊕

£123.25

ADD TO CART

Qty 1-5	£123.25
Qty 6+	£98.60
Volume Pricing	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:
Uncoated

Substrate:

N-BK7
Length (mm): 75.00
Surface Quality: 60-40
Type: Light Pipe
Entrance and Exit Aperture (mm): 10.00
Parallelism (arcmin): 5.00
Length Tolerance (mm): ±0.3
Aperture Tolerance (mm): ±0.10
Image Orientation: Light Homogenization
Light Source NA: High
Wavelength Range (nm): 350 - 2200
Surface Flatness (P-V): 3λ

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant