


10mm Dia., 1.5mm Thick, Calcium Fluoride (CaF₂) Diffuser

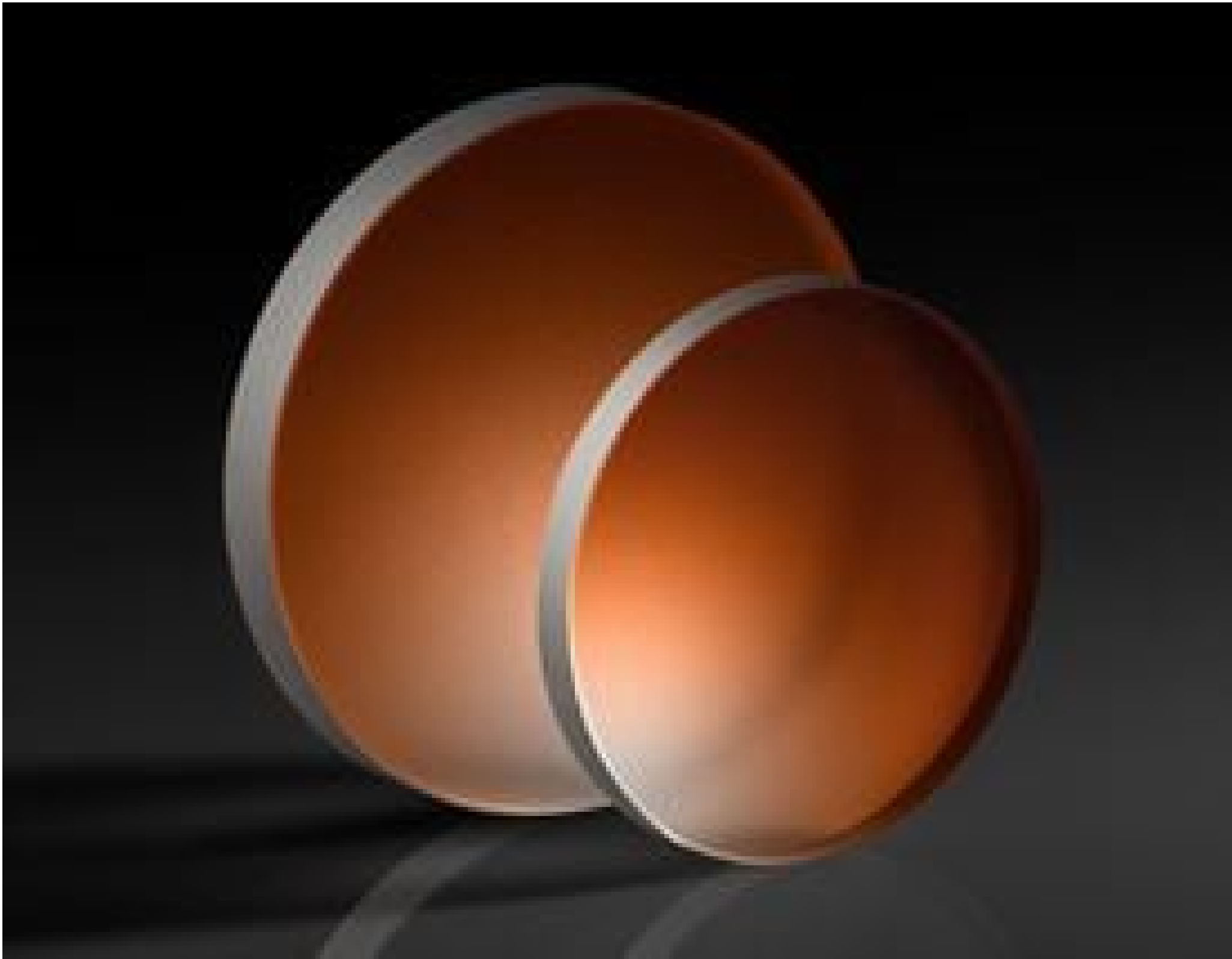

IR Calcium Fluoride (CaF₂) Diffusers

Stock #19-731 3-4 DAYS



1



£106.25

ADD TO CART

Qty 1-10

£106.25

Qty 11+

£95.63

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
10.00 +0.00/-0.10

Coating:
Uncoated

Edges:

Fine Grind
Substrate: ☐ Calcium Fluoride (CaF ₂)
Thickness (mm): 1.50 ±0.10
Type: IR Diffuser
Wavelength Range (nm): 300 - 7000
Note: Fine Grind first surface with a roughness (Ra) of ☐ 0.75 microns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View