


TECHSPEC® 12.5mm Dia x 10mm FL Acylinder Lens, Uncoated

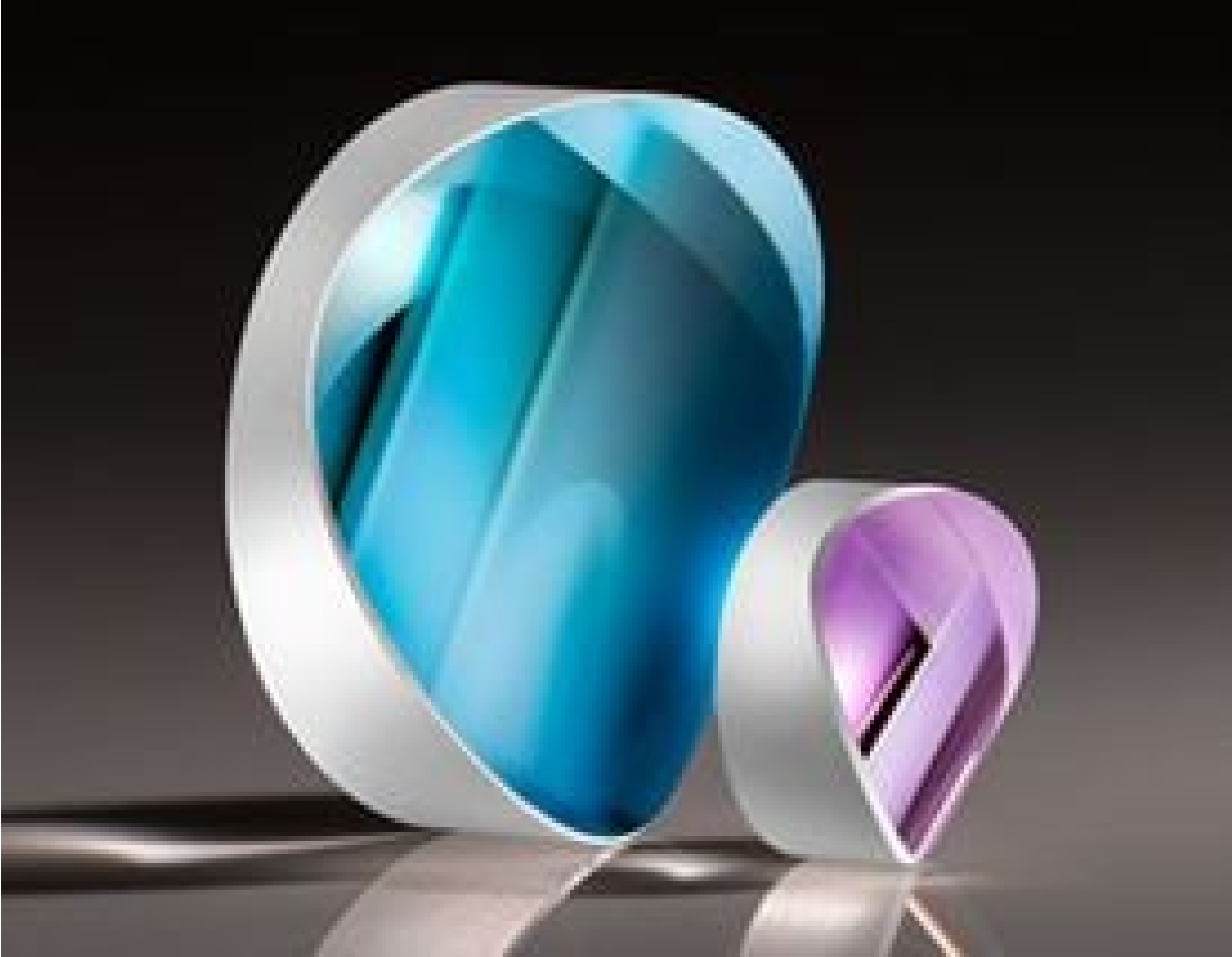

TECHSPEC Acylinder Lenses

Stock **#86-030** 3-4 DAYS



1



£510.00

ADD TO CART

Qty 1-5

£510.00

Qty 6+

£408.00

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
12.50 +0.0/-0.1

Effective Focal Length EFL (mm):
10.00

Substrate: ☐
NSF5

f/#: 0.8
Numerical Aperture NA: 0.63
Coating: Uncoated
Type: Acyliner Lens
Wavelength Range (nm): 380 - 2500
Back Focal Length BFL (mm): 6.4
Center Thickness CT (mm): 6.00
Center Thickness Tolerance (mm): ±0.1
Clear Aperture (%): 90.00
Edge Thickness ET (mm): 2.8
Focal Length Specification Wavelength (nm): 587.6
Surface Accuracy, RMS (µm): 1.0
Surface Quality: 60-40

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View