


12.5mm Diameter Float Glass Window

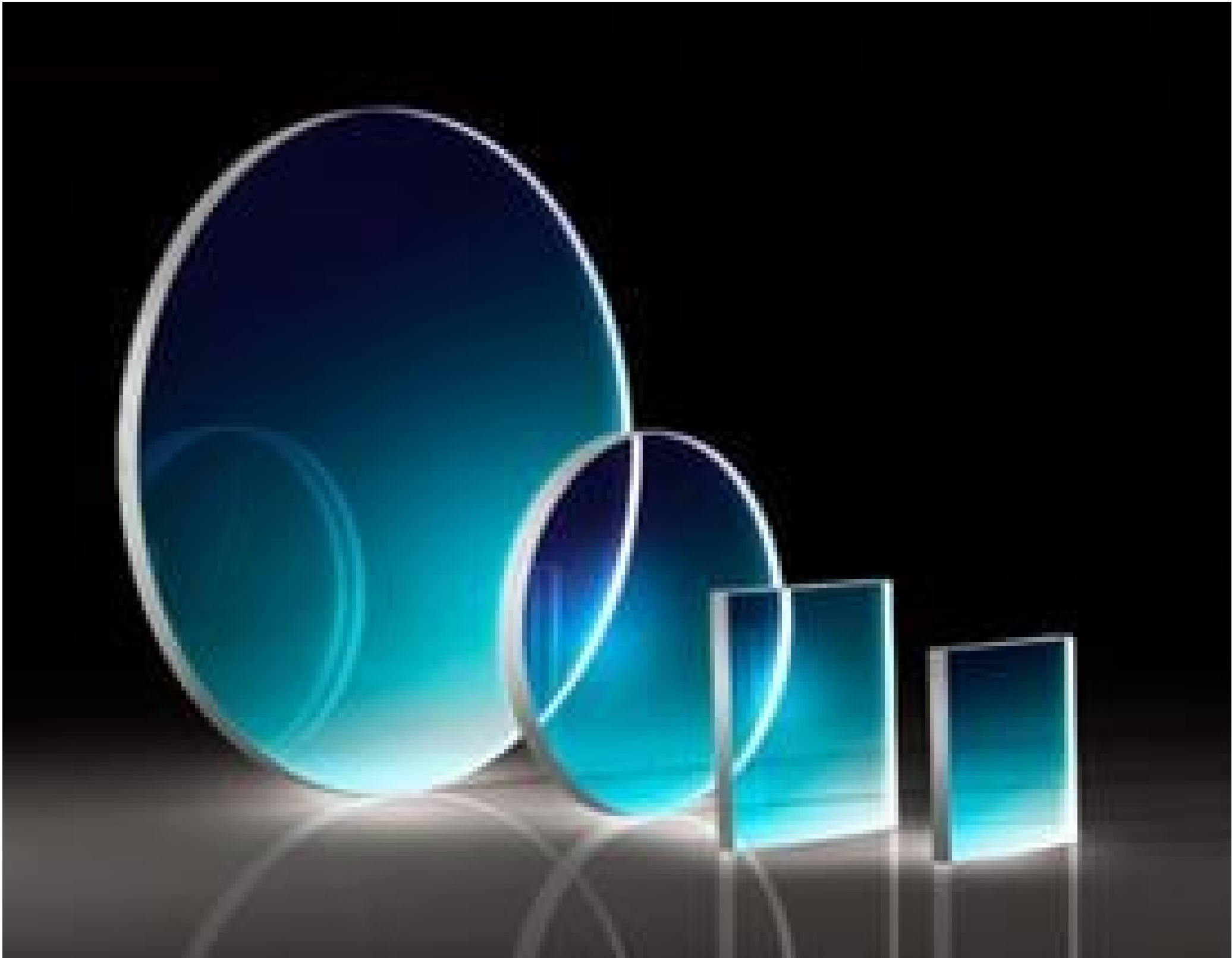

Stock **#02-105** 20+ In Stock

-

1

+

£11^{.81}

ADD TO CART

Volume Pricing	
Qty 1-5	£11.81 each
Qty 6-49	£10.72 each
Qty 50-99	£10.07 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

SPECIFICATIONS

General

Protective Window

Type:

Physical & Mechanical Properties	
12.50	Diameter (mm):
1.50	Thickness (mm):
Fine Ground	Edges:
Optical Properties	
Uncoated	Coating:
Float Glass	Substrate:
4 - 6λ	Surface Flatness (P-V):
80-50	Surface Quality:
350 - 2000	Wavelength Range (nm):
Regulatory Compliance	
Compliant	RoHS 2015:
Compliant	Reach 219:
View	Certificate of Conformance:

PRODUCT DETAILS

- Transmits Visible and Near Infrared Wavelengths
- Available Uncoated or with an Anti-Reflection Coating
- Variety of Sizes Available

Float Glass Optical Windows are optical glass with polished faces that are relatively parallel and are typically used as a protective element between two environments. Float glass readily transmits visible and near-infrared wavelengths and can be used in a wide variety of applications. Float Glass Optical Windows are versatile products offered in circular and rectangular options. They are available uncoated or with BBAR (Broadband Anti-Reflective) 400-700nm coating.

COMPATIBLE MOUNTS