


TECHSPEC[®] 125mm, Side Drive, Standard Top, English Micrometer Stage

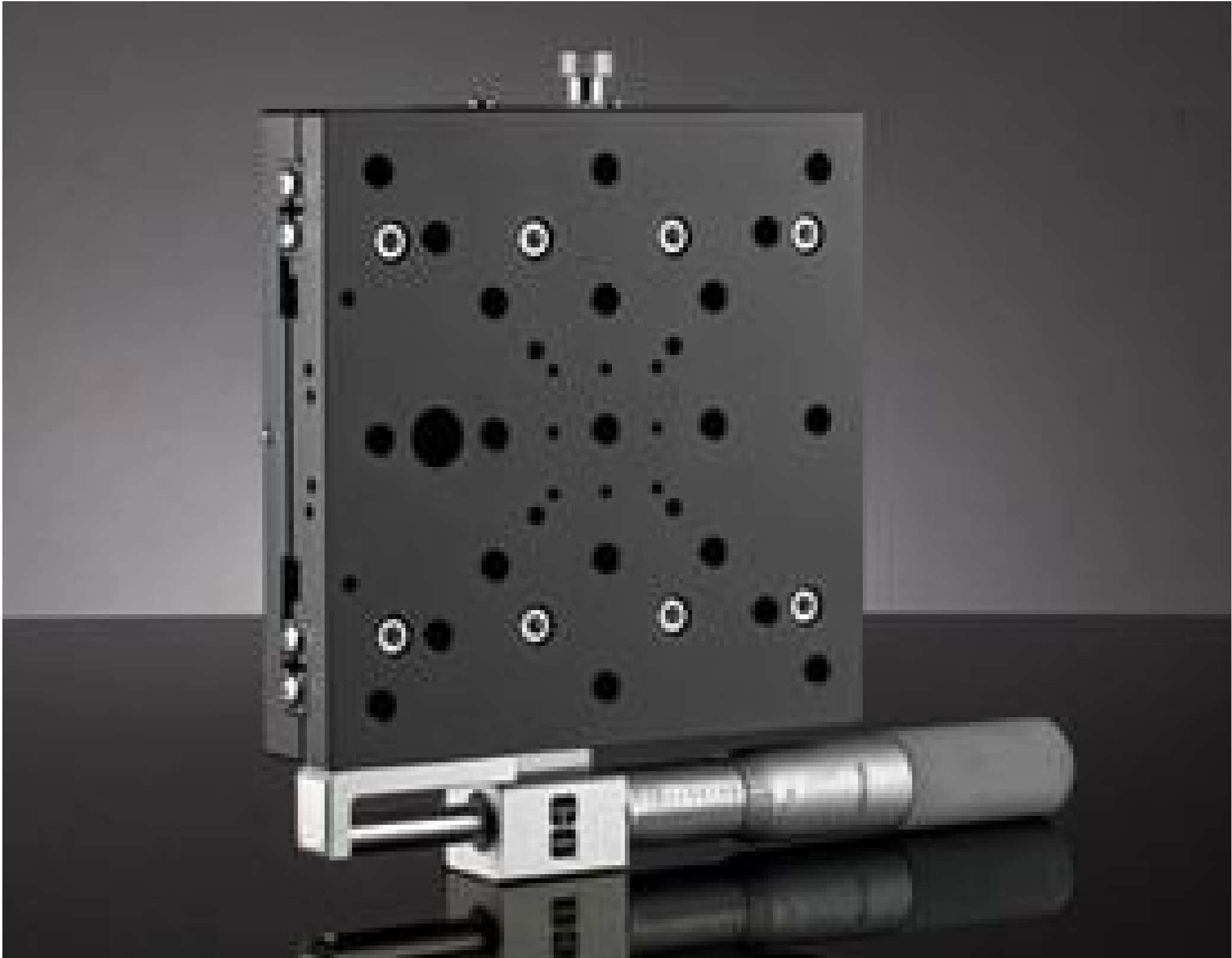

125mm Micrometer Drive Stage

Stock **#66-454** 1 In Stock

-

1

+

£564⁰⁰


ADD TO CART

Volume Pricing	
Qty 1-2	£564.00 each
Qty 3+	£492.08 each
Need More?	Request Quote


ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads


General	
English	Type:
Physical & Mechanical Properties	
Linear (X)	Type of Movement:
Crossed Roller Bearing	Guide System:

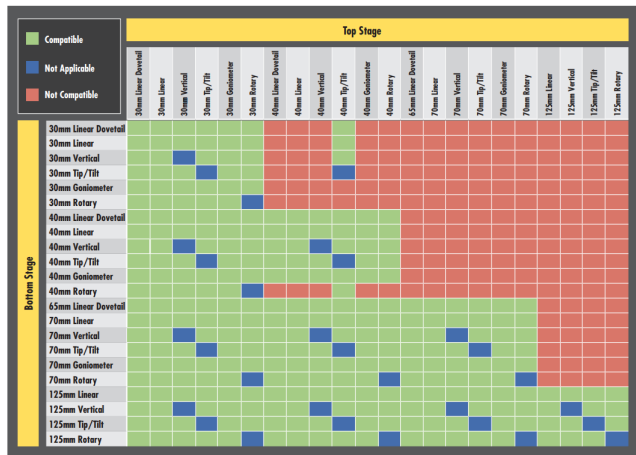


30mm Standard-Top Stages - Center Drive

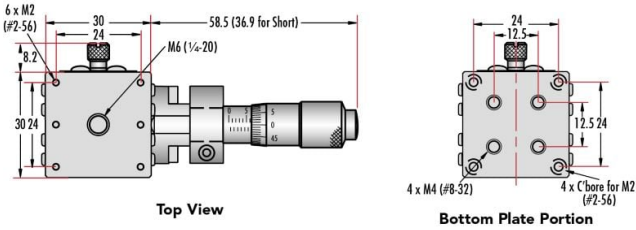


30mm Standard-Top Stages - Side Drive

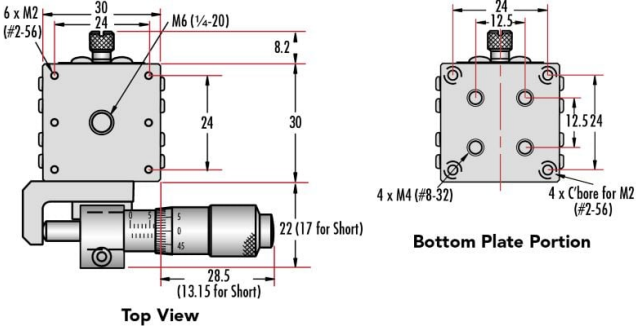


40mm Standard-Top Stages - Center Drive

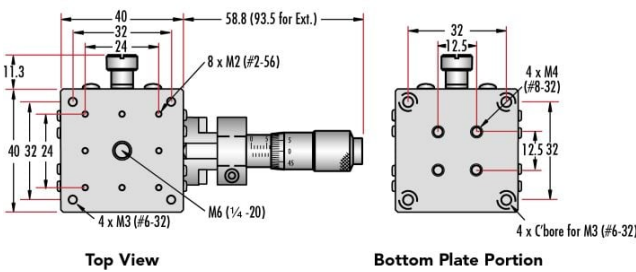


40mm Standard-Top Stages - Side Drive

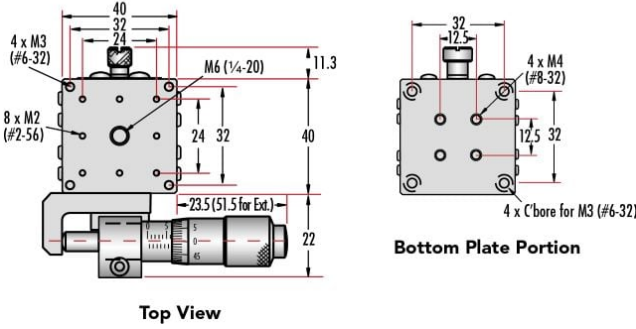


70mm Standard-Top Stages - Center Drive

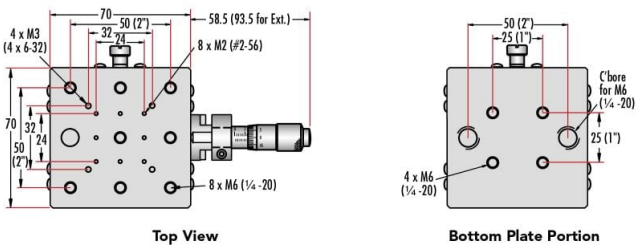

70mm Standard-Top Stages - Side Drive

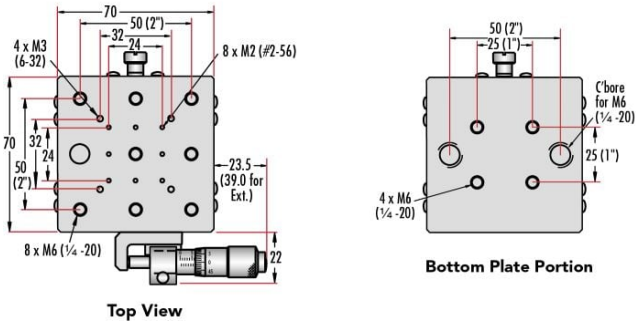

125mm Standard-Top Stages - Center Drive

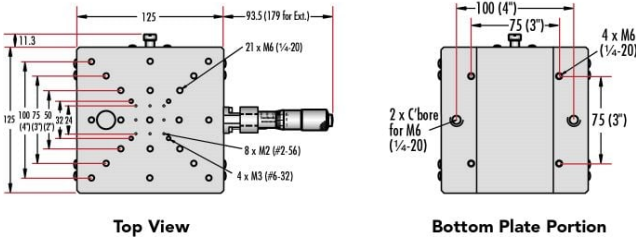

125mm Standard-Top Stages - Side Drive

