

12.5/12.7mm, Mounting Cell



12.7mm, Mounting Cell, #56-759

Stock **#56-759** **5 In Stock**

-

1

+

£21⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-9	£21.80 each
Qty 10-25	£19.68 each
Qty 26-49	£18.72 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

SPECIFICATIONS

General

Fixed

Type:

Circular	Type of Optics:
Physical & Mechanical Properties	
Black Anodized Aluminum	Construction:
3.2	Max. Thickness of Compatible Optics (mm):
30.0	Cell Diameter (mm):
Threading & Mounting	
12.5 - 12.7	Size of Compatible Optics (mm):
5.0	Cell Thickness (mm):
Regulatory Compliance	
Exempt	RoHS 2015:
View	Certificate of Conformance:
Contains SVHC(s)	Reach 247:

PRODUCT DETAILS


- Allows Stacking of 3 or 5 Filters
 - Black Anodized Aluminum
 - Posts and Post Holders Required for Mounting
- Fixed/Multiple Filter Mounts are ideal for use with neutral density filters in stacking applications. Mounting cell holds filter with diameter "F" in place with a retainer ring. Mounting cell sits securely in filter holder. Fixed/Multiple Filter Mounts can also hold unmounted filters with diameter "A". A filter holder and filter cell are required for a complete stacking system, such as the one illustrated in the product image. These mounts are constructed of black anodized aluminum and are optimal for mounting 3 or 5 circular optics.
- Posts and Post Holders are required for mounting to a breadboard.

TECHNICAL INFORMATION


Stock No.	A	B	C	D	No. of Slots	No. of Cell Slots
#55-006	30mm	50mm	34mm	5mm	4	3
#55-007	50mm	70mm	44mm	5mm	5	5

Stock No.	F	G	H
#56-759	12.7mm	10.2mm	30mm
#55-008	25mm	22.5mm	30mm
#56-760	25.4mm	22.9mm	30mm
#55-009	50mm	47mm	52mm

Multiple Filter Holder

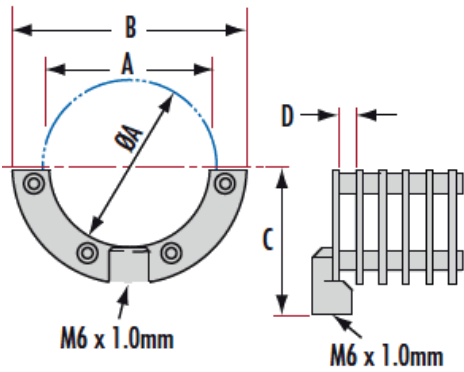

Mounting Cell

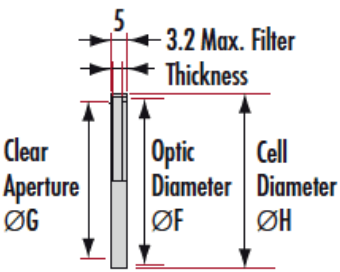

Units: mm