


TECHSPEC® 15mm Aperture, 300mm L Low NA, Hexagonal Light Pipe

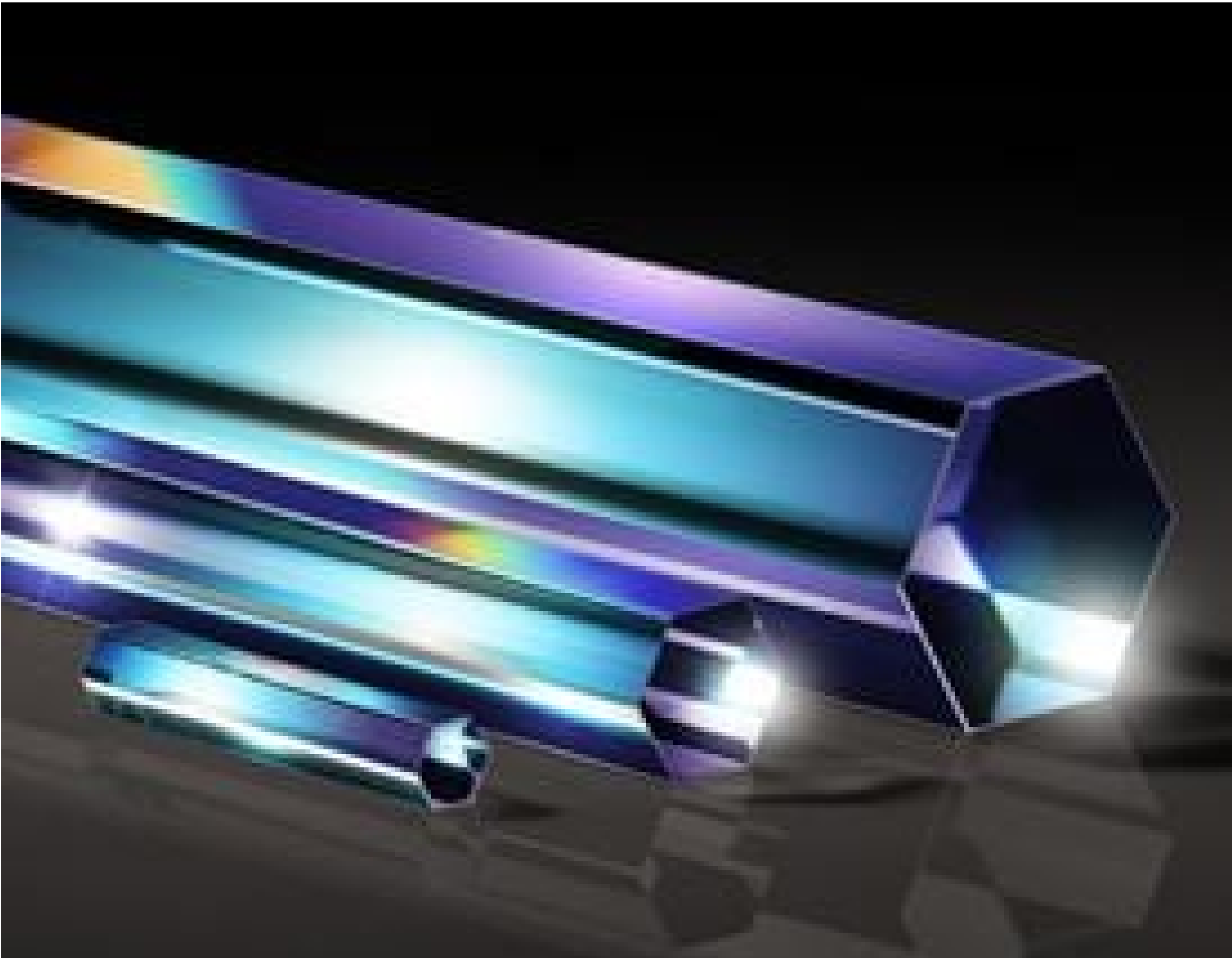

N-BK7 Light Pipe Homogenizing Rods



Stock **#84-534** 3-4 DAYS

- 1 +

£216.75

ADD TO CART

Qty 1-5
£216.75
Qty 6+
£173.40
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:

Uncoated

Substrate:

N-BK7
Length (mm): 300.00
Surface Quality: 60-40
Type: Light Pipe
Entrance and Exit Aperture (mm): 15.0
Parallelism (arcmin): 5.00
Length Tolerance (mm): ±0.3
Aperture Tolerance (mm): ±0.10
Image Orientation: Light Homogenization
Light Source NA: Low
Wavelength Range (nm): 350 - 2200
Surface Flatness (P-V): 5λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View