


## TECHSPEC® 15mm Enhanced Aluminum Coated, N-BK7 Right Angle Mirror

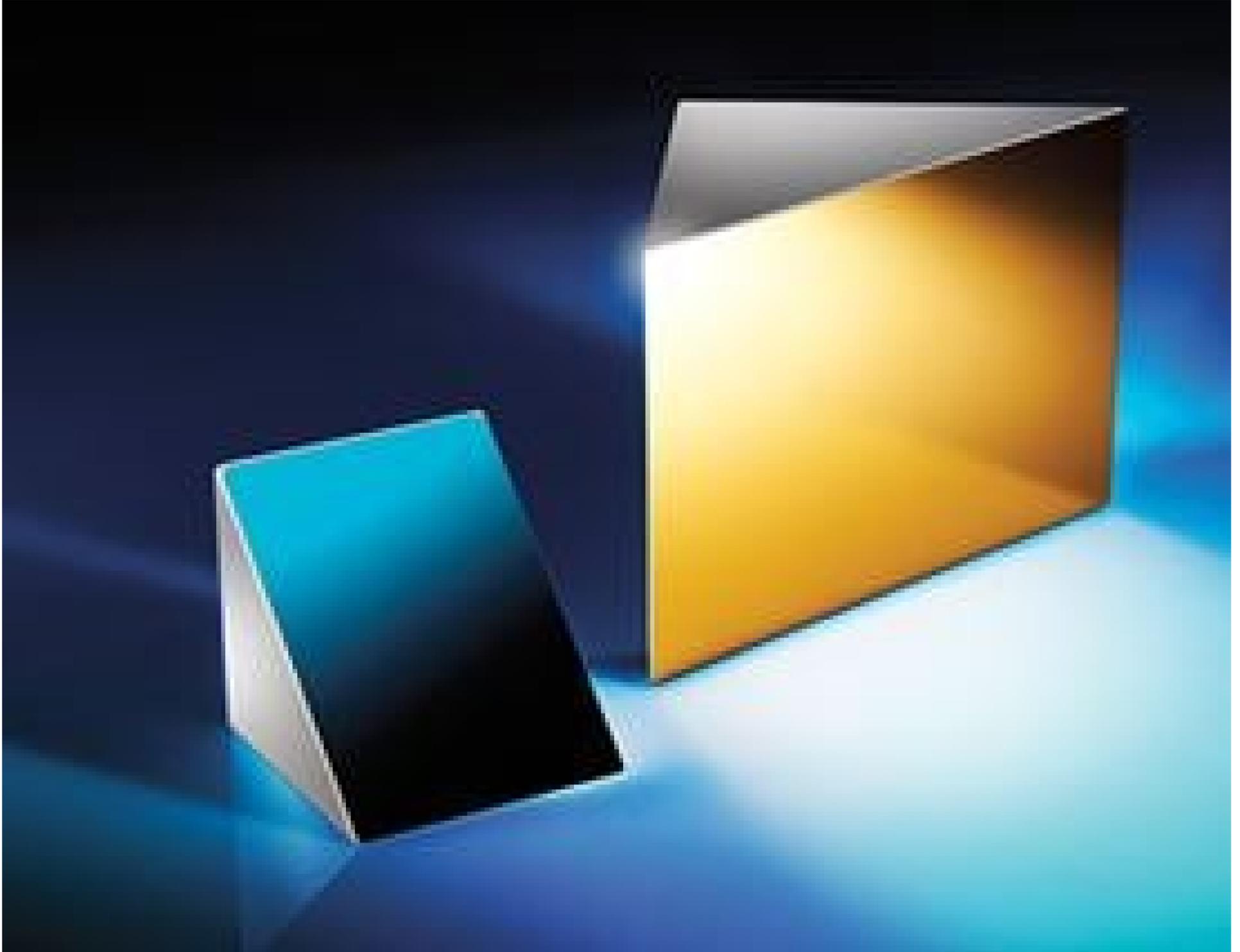

Stock #45-593  In Stock

1  **£82.88**

ADD TO CART

Qty 1-5

£82.88

Qty 6+

£66.30

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Flatness (P-V):  
λ/8

Substrate:   
[N-BK7](#)

Surface Quality:  
40-20

**Length of Legs (mm):**  
15.00

**Dimensional Tolerance (mm):**  
±0.1

**Coating Specification:**  
R<sub>avg</sub> >95% @ 450 - 650nm

**Coating:**  
Enhanced Aluminum (450-650nm)

**Coating Type:**  
Metal

**Angle Tolerance (arcmin):**  
±2

**Bevel:**  
Protective bevel as needed

**Clear Aperture CA (mm):**  
19.09 x 13.50

**Length of Hypotenuse (mm):**  
21.20

**Type:**  
Right Angle Mirror

**Wavelength Range (µm):**  
0.45 - 0.65

**Wavelength Range (nm):**  
450 - 650

**Damage Threshold, Reference:** □  
0.2 J/cm<sup>2</sup> @ 532nm, 10ns

## Regulatory Compliance

**RoHS 2015:**  
[Compliant](#)

**Reach 219:**  
[Compliant](#)

**Certificate of Conformance:**  
[View](#)

---