


[See all 6 Products in Family](#)

1mw, 635nm Laser Bat Power ZAT

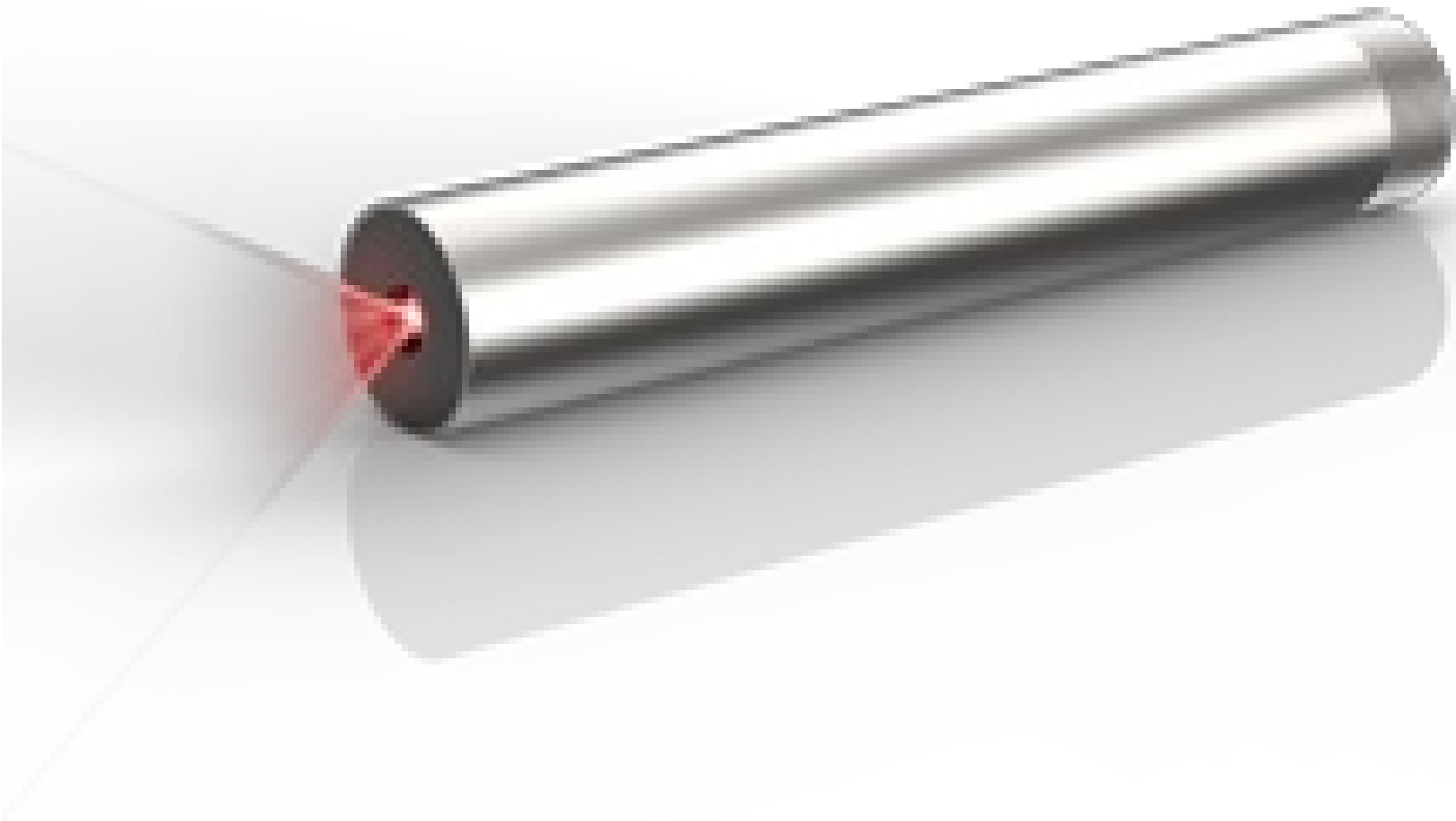

Stock **#19-443** 7 In Stock

-

1

+

£166^{.00}

ADD TO CART

Volume Pricing	
Qty 1-9	£166.00 each
Qty 10+	£150.00 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes



General

Elliptical Dot	Style:
2	Laser Class - CDRH:

Physical & Mechanical Properties

162	Weight (g):
124.00	Length (mm):

Optical Properties

635.00	Wavelength (nm):
Red	Color:
Up to 2,000mm	Focus Range (mm):

Electrical

1	Output Power (mW):
---	--------------------

Hardware & Interface Connectivity

1 AA Battery (Not Included)	Power Requirement:
Free Space	Output Type:

Environmental & Durability Factors

IP40	Environmental Rating:
------	-----------------------

Regulatory Compliance

View	Certificate of Conformance:
----------------------	-----------------------------

Product Details

- Bright Red 635nm Wavelength
- Line, Crosshair, or Dot Projection
- Battery Powered Operation with a Fixed Focus
- Sturdy, Metal Housing

Z-Laser ZAT Battery Powered Lasers are ideal for positioning and alignment applications. Their battery powered design provides maneuverability by removing the need for a fixed power supply. IP40 rated, shock proof, and vibration proof with a sturdy, metal housing makes these lasers excellent for harsh environments and repeated use. Z-Laser ZAT Battery Powered Lasers are suitable for use in industrial environments such as Automotive, Paper, Wood, Ceramic, and Metal. Available with 1 or 5mW output powers, the lasers utilize one AA battery (not included) ensuring easy maintenance and an extended lifetime.