
 


1" Travel, Eng Micrometer, Thru-Hole Ball Bearing Stage

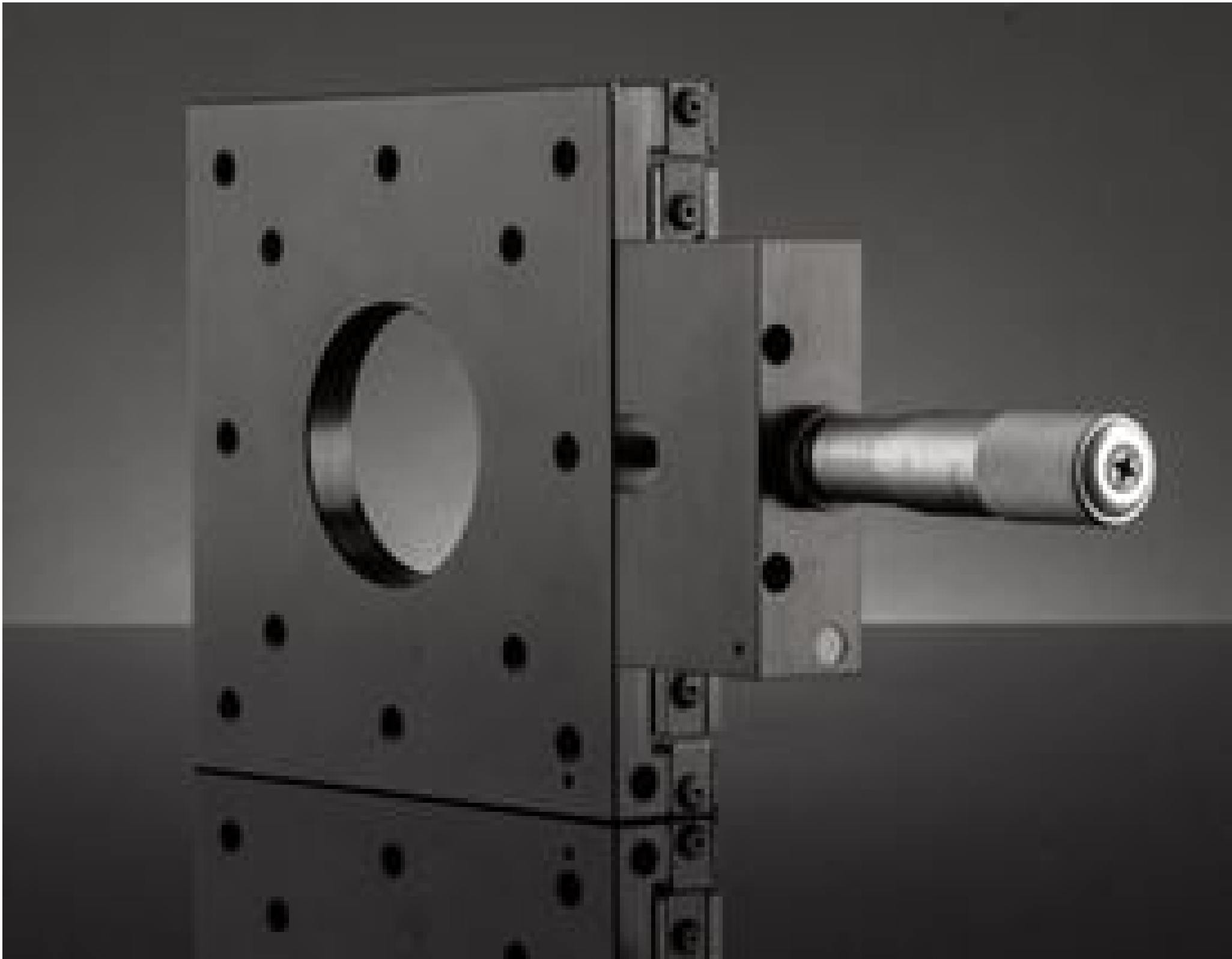

5" Center drive stage



Stock **#33-488** 3-4 DAYS

⊖ 1 ⊕

£787.95

ADD TO CART

Qty 1+

£787.95

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Type of Movement:
Linear (X)

Guide System:
Ball Bearing

Type of Drive:
English Micrometer

Drive Orientation:

Center Drive
Type: English
Stage Size (mm): 127 x 127
Travel (inches): 1
Construction: Aluminium Stage
Graduation (inches): 0.001
Height (inches): 1.00
Height (mm): 25.4
Load Capacity, Normal (lbs): 105
Note: Thru-Hole
Stage Size (inches): 5.00 x 5.00
Straight Line Accuracy (inches): 0.00008/inch of travel
Weight (lbs): 2.7
Thrust Capacity, T_a (lbs): 30
Thrust Capacity, T_b (lbs): 2.5

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View