
 


200 x 200mm Sheet of Metal Velvet Foil, Low Outgassing Adhesive

See More by [Acktar](#)

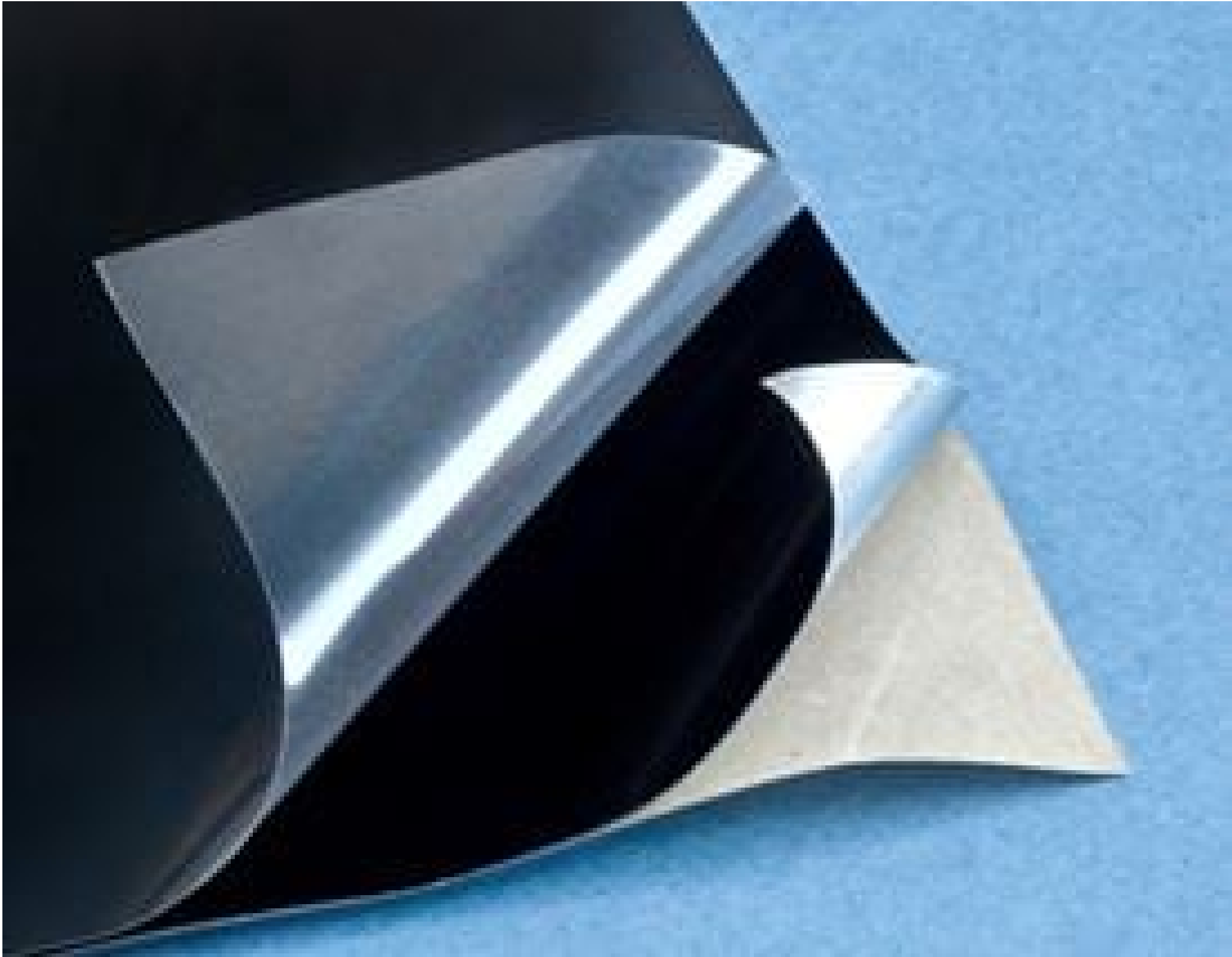

Acktar Light Absorbent Foil



Stock **#20-053** 3-4 DAYS

⊖ 1 ⊕

£99.88

ADD TO CART

Qty 1+

£99.88

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:
Metal Velvet™

Model Number:
MV-20X20-3

Operating Temperature (°C):

-40 to +150
Dimensions (mm): 200 x 200
Type: Low Outgassing Adhesive
Coating Thickness (µm): 5 - 7
Foil Thickness (µm): 115
Abrasion Resistance: Light, do not touch
Adhesive Thickness (µm): 60
Humidity Resistance: ML-C-48497A
Wavelength Range (µm): 0.3 - 14
Dimensions (cm): 20 x 20
Note: Typical Adhesive Outgassing Performance: 0.85% TML, 0% VCM per ASTM E595-77/84/90

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 240: Compliant