


TECHSPEC[®] 25mm Dia. X 25mm FL Uncoated, Double Sided Aspheric Lens

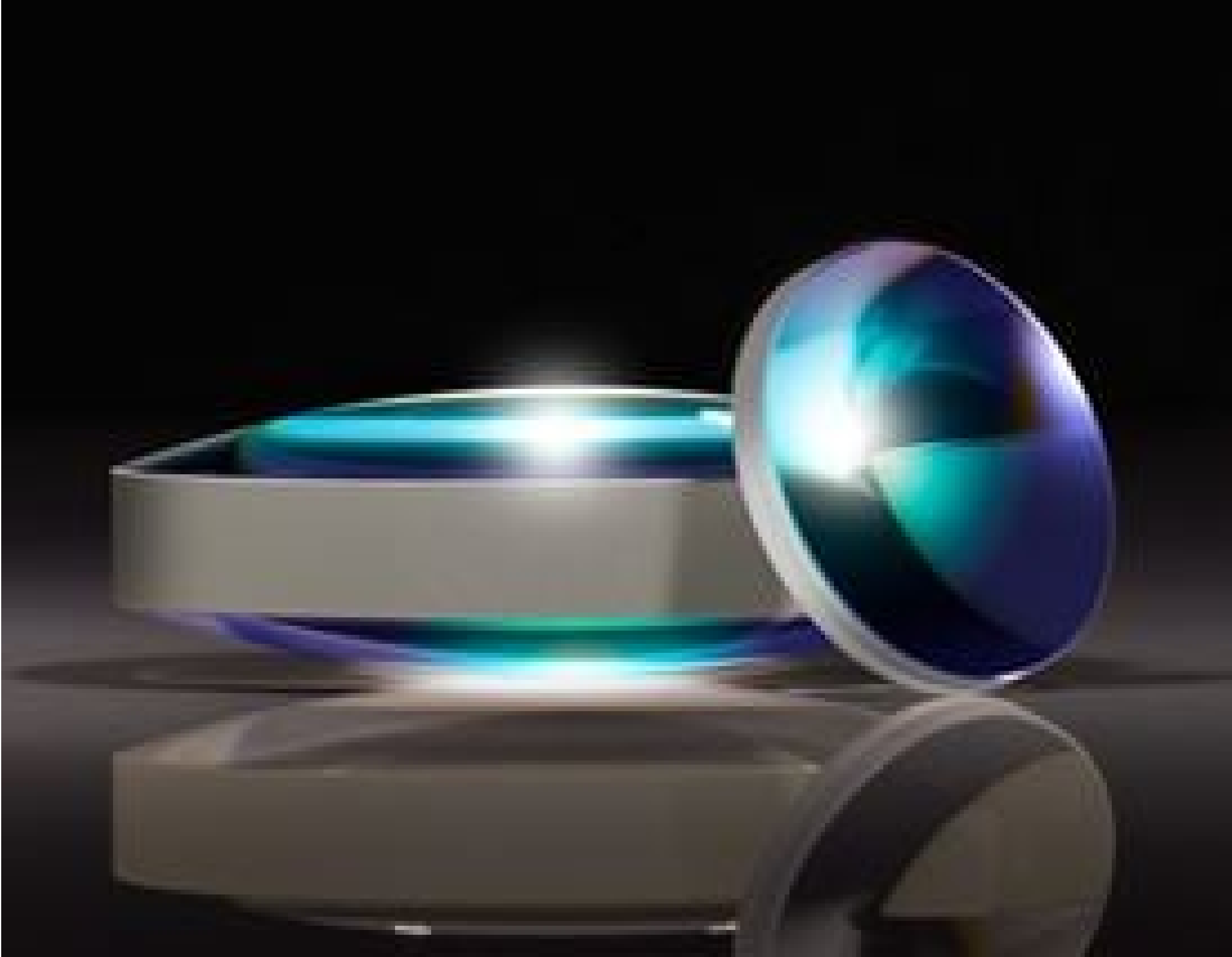

Stock #18-420 3-4 DAYS

-

1

+

£386.75

ADD TO CART

Qty 1-5

£386.75

Qty 6+

£309.40

Volume Pricing

[Request Quote](#)

ⓘ

 Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
25.00 +0.0/-0.025

Effective Focal Length EFL (mm):
25.00

Back Focal Length BFL (mm):
21.03

Substrate: N-BK7
Aspheric Design Wavelength (nm): 587.6
Asphere Figure Error, RMS @ 632.8nm: 0.4λ RMS and 2λ PV
Coating: Uncoated
Centering (arcmin): 3
Surface Quality: 40-20
Clear Aperture CA (mm): 22.5
Edge Thickness ET (mm): 5
Center Thickness CT (mm): 11.10 ±0.1
f#: 1.00
Bevel: None
Type: Aspheric Lens
Wavelength Range (nm): 330 - 2400
Radius R₁=−R₂ (mm): 23.786
Power (diopters): 40.00

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View