

## 25mm Dia. x 400mm FL Uncoated, DCX N-K5 Lens



Stock #32-904 CLEARANCE **20+ In Stock**

-
1
+
£19<sup>00</sup>

ADD TO CART

### Volume Pricing

|            |                               |
|------------|-------------------------------|
| Qty 1+     | £19.00 each                   |
| Need More? | <a href="#">Request Quote</a> |

ⓘ Prices shown are exclusive of VAT/local taxes

### Product Downloads

### General

Double-Convex Lens **Type:**

### Physical & Mechanical Properties

25.00 +0.00/-0.10 **Diameter (mm):**

<1 **Centering (arcmin):**

5.00 ±0.10 **Center Thickness CT (mm):**

|                           |                                     |
|---------------------------|-------------------------------------|
| 4.63                      | Edge Thickness ET (mm):             |
| 24                        | Clear Aperture CA (mm):             |
| Protective as needed      | Bevel:                              |
| <b>Optical Properties</b> |                                     |
| 400.00 @ 587.6nm          | Effective Focal Length EFL (mm):    |
| 398.75                    | Back Focal Length BFL (mm):         |
| Uncoated                  | Coating:                            |
| <a href="#">N-K5</a>      | Substrate: <input type="checkbox"/> |
| 40-20                     | Surface Quality:                    |
| 1.5λ                      | Power (P-V) @ 632.8nm:              |
| λ/4                       | Irregularity (P-V) @ 632.8nm:       |
| ±1                        | Focal Length Tolerance (%):         |
| 16.00                     | f#:                                 |
| 0.03                      | Numerical Aperture NA:              |
| 330 - 2500                | Wavelength Range (nm):              |


|                              |                             |
|------------------------------|-----------------------------|
| <b>Regulatory Compliance</b> |                             |
| <a href="#">View</a>         | Certificate of Conformance: |

## Product Details

- N-K5 Substrate
- Various Anti-Reflection (AR) Coatings
- PCX and DCX Options Available

N-K5 Lenses are available in various diameters, focal lengths, as well as Plano-Convex and Double-Convex form factors. Anti-reflective coatings covering the VIS to NIR make these ideal for multiple applications.

## Technical Information

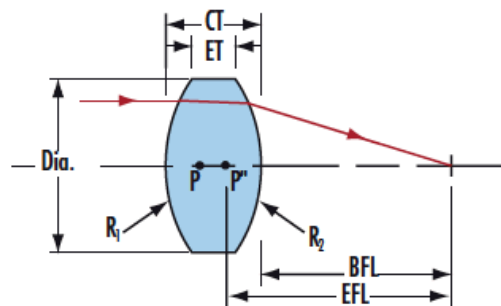

## Compatible Mounts