


27mm Diameter, Metric Hole Gauge, Contact Reticle

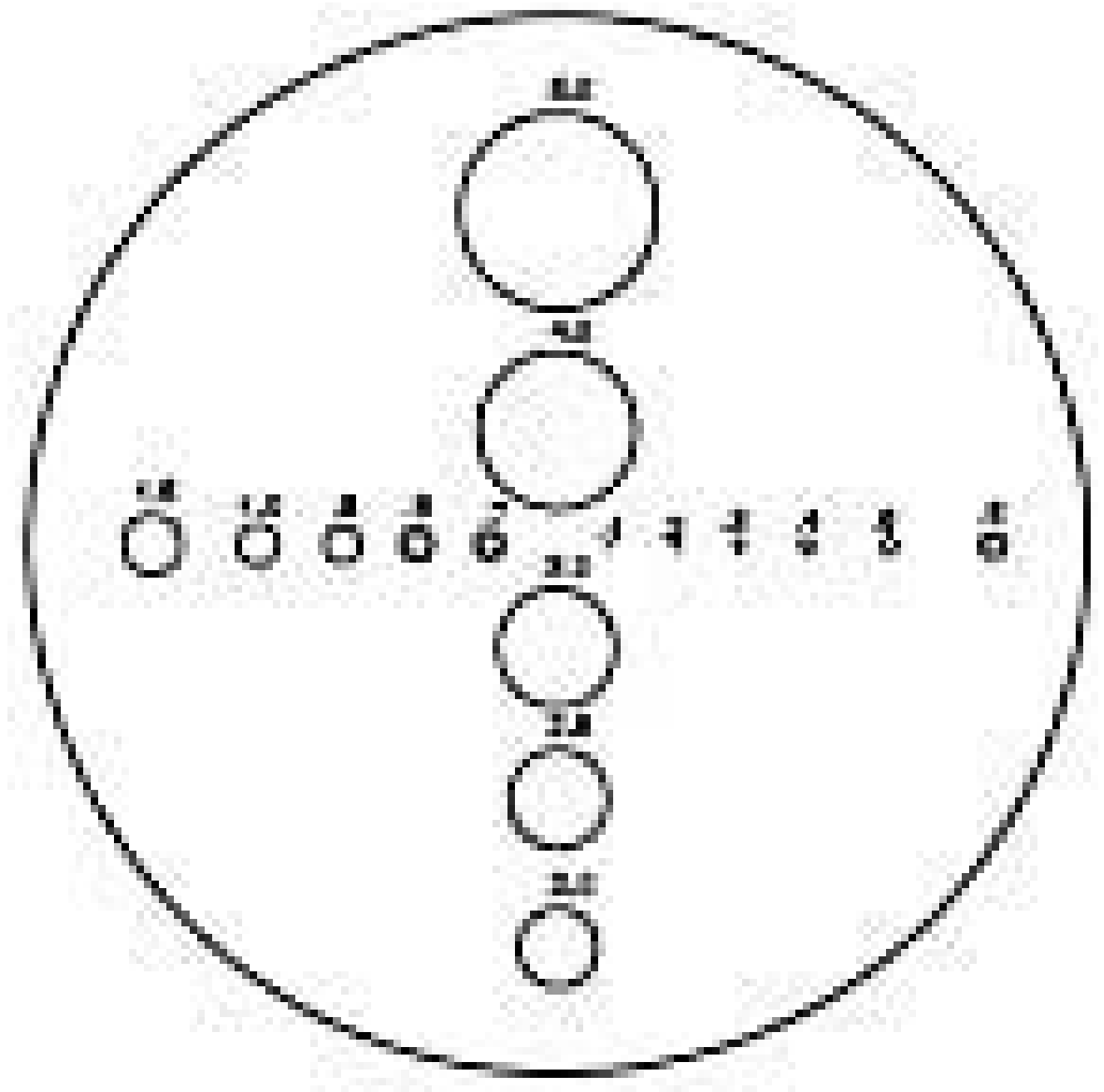

Hole Guage

Stock #39-457 3-4 DAYS



1



£56.95

ADD TO CART

Qty 1-4

£56.95

Qty 5+

£53.46

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
27.00 ±0.05

Angle Tolerance (arcsec):
±1

Line Thickness (µm):
25.00

Surface Quality: 60-40
Thickness (mm): 2.28
Thickness Tolerance (mm): ±0.127
Type: Metric Hole Gauge
Line to Line Accuracy (µm): ±2
Bevel: Protective bevel as needed
Parallelism (arcsec): <30
Centering (mm): 0.25
Line Thickness Tolerance (µm): ±13
Surface Flatness (P-V): 3 - 4λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 211: Compliant
Certificate of Conformance: View
