


TECHSPEC[®] 30 x 30mm Stabilized Wire Grid Polarizing Film

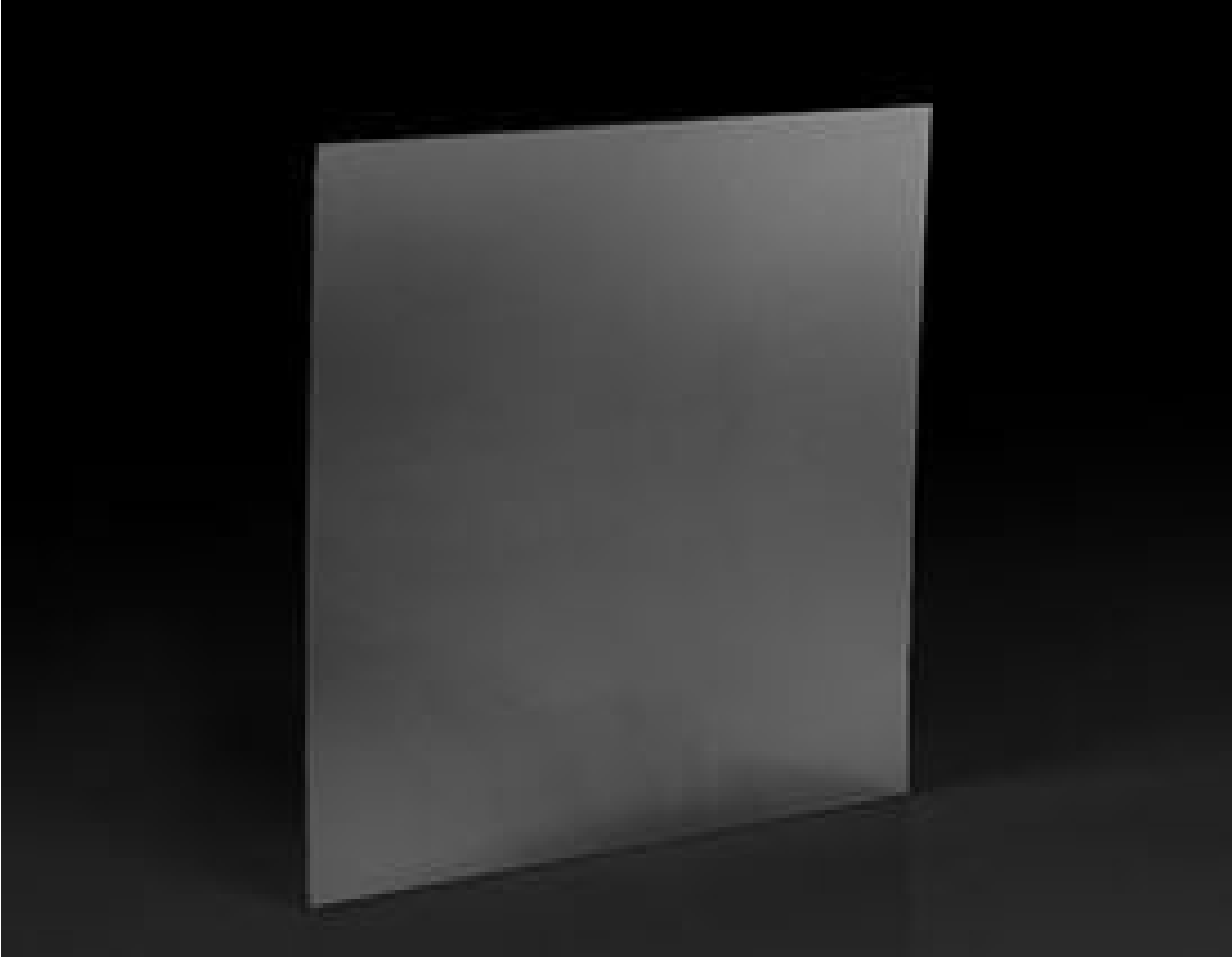

TECHSPEC[®] Wire Grid Polarizing Film

Stock #20-236 3-4 DAYS

-

1

+

£86.70

ADD TO CART

Qty 1-10

£86.70

Qty 11+

£73.95

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Angle of Incidence (°):
0 - 45

Extinction Ratio:
>1415:1 @ 0° AOI, 550nm

Substrate: ☐

Aluminium Wires on COP
Operating Temperature (°C): 60 Max @ 90% RH 105 in dry conditions
Dimensions (mm): 30 x 30
Thickness (mm): 0.19
Thickness Tolerance (mm): ±0.030
Transmission (%): 84.9 (typical @ 550 nm)
Type: Linear Polarizer
Dimensional Tolerance (mm): ±1
Construction: Wire Grid
Wavelength Range (nm): 400 - 1200
Axis Orientation: 0° ± 1.5°, marked by Notch

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant