


304.8 x 304.8 x 3mm High Efficiency Window

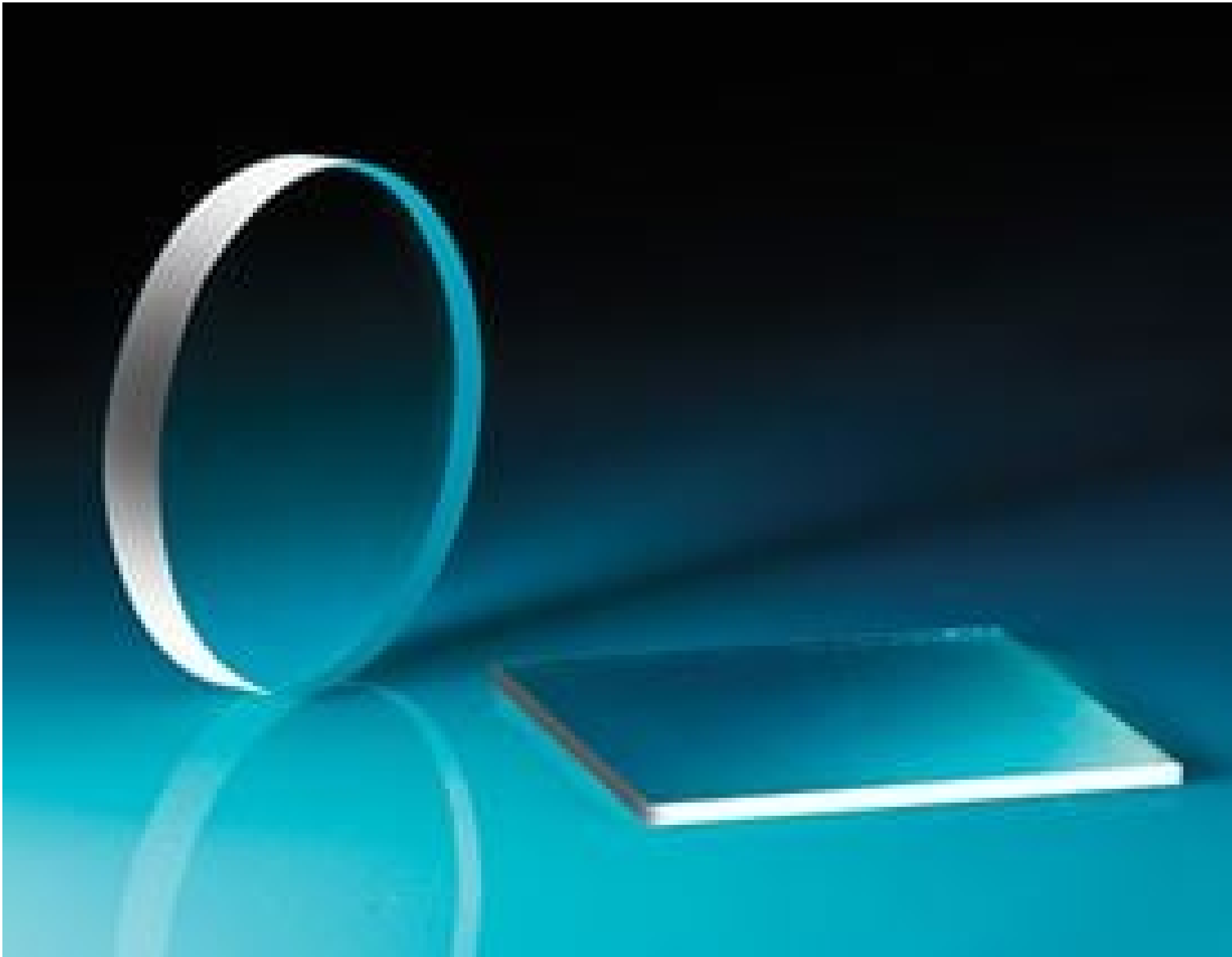

Stock #21-332 3-4 DAYS

-

1

+

£89.25

ADD TO CART

Qty 1-5
£89.25
Qty 6+
£71.40
Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Angle of Incidence (°):
0

Bevel:
Protective as needed

Clear Aperture (%):
≥90

Clear Aperture CA (mm): 274.32 x 274.32
Dimensions (mm): 304.80 x 304.80
Thickness (mm): 3.00 ±0.25
Coating: BBAR (425-700nm)
Coating Specification: Ravg ≤0.5% @ 425 - 700nm
Edges: Seamed
Substrate: Float Glass
Surface Quality: 80-50
Transmission (%): 95.6 Average (typical)
Type: Protective Window
Wavelength Range (nm): 425 - 700
Length (mm): 304.80
Width (mm): 304.80

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant