

TECHSPEC[®] 30mm, Center Drive, Standard Top, 0.5" Travel, English Micrometer



Stock #66-387 2 In Stock

-

1

+

£350⁴⁰

ADD TO CART

Volume Pricing	
Qty 1-2	£350.40 each
Qty 3+	£305.60 each
Need More?	Request Quote

Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Type:

English

Physical & Mechanical Properties


Type of Movement:

Linear (X)


Guide System:

Crossed Roller Bearing


30mm Standard-Top Stages - Center Drive

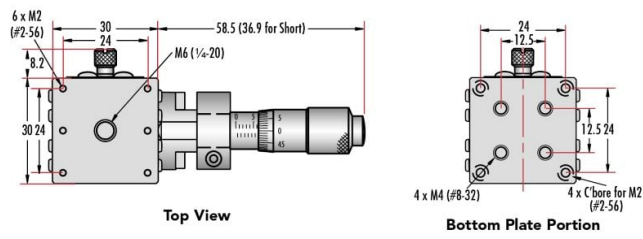

30mm Standard-Top Stages - Side Drive

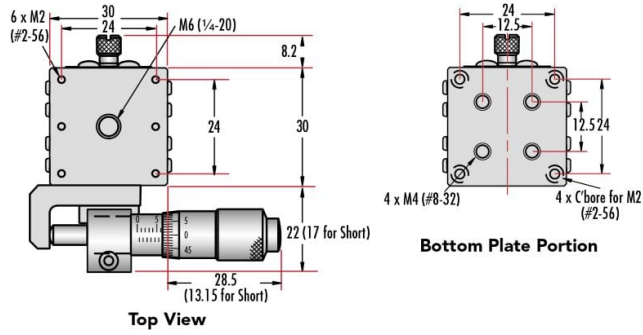


40mm Standard-Top Stages - Center Drive

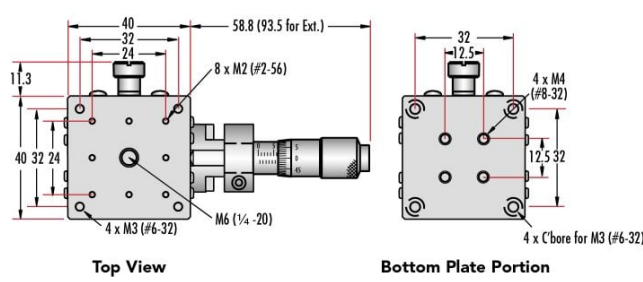


40mm Standard-Top Stages - Side Drive




70mm Standard-Top Stages - Center Drive

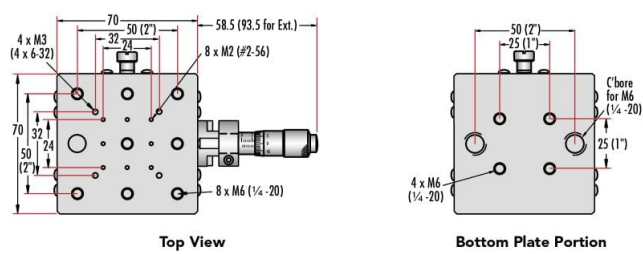

70mm Standard-Top Stages - Side Drive

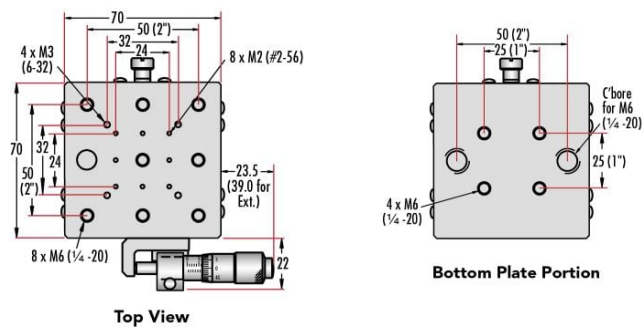

125mm Standard-Top Stages - Center Drive

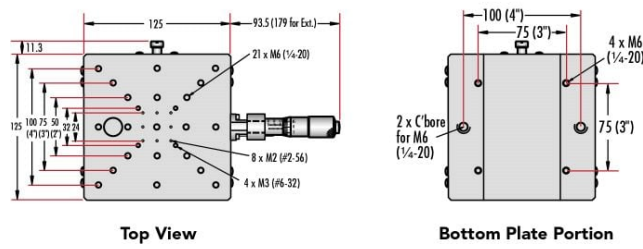

125mm Standard-Top Stages - Side Drive

