


TECHSPEC®

30mm Dia Protected Silver, λ/20 Mirror

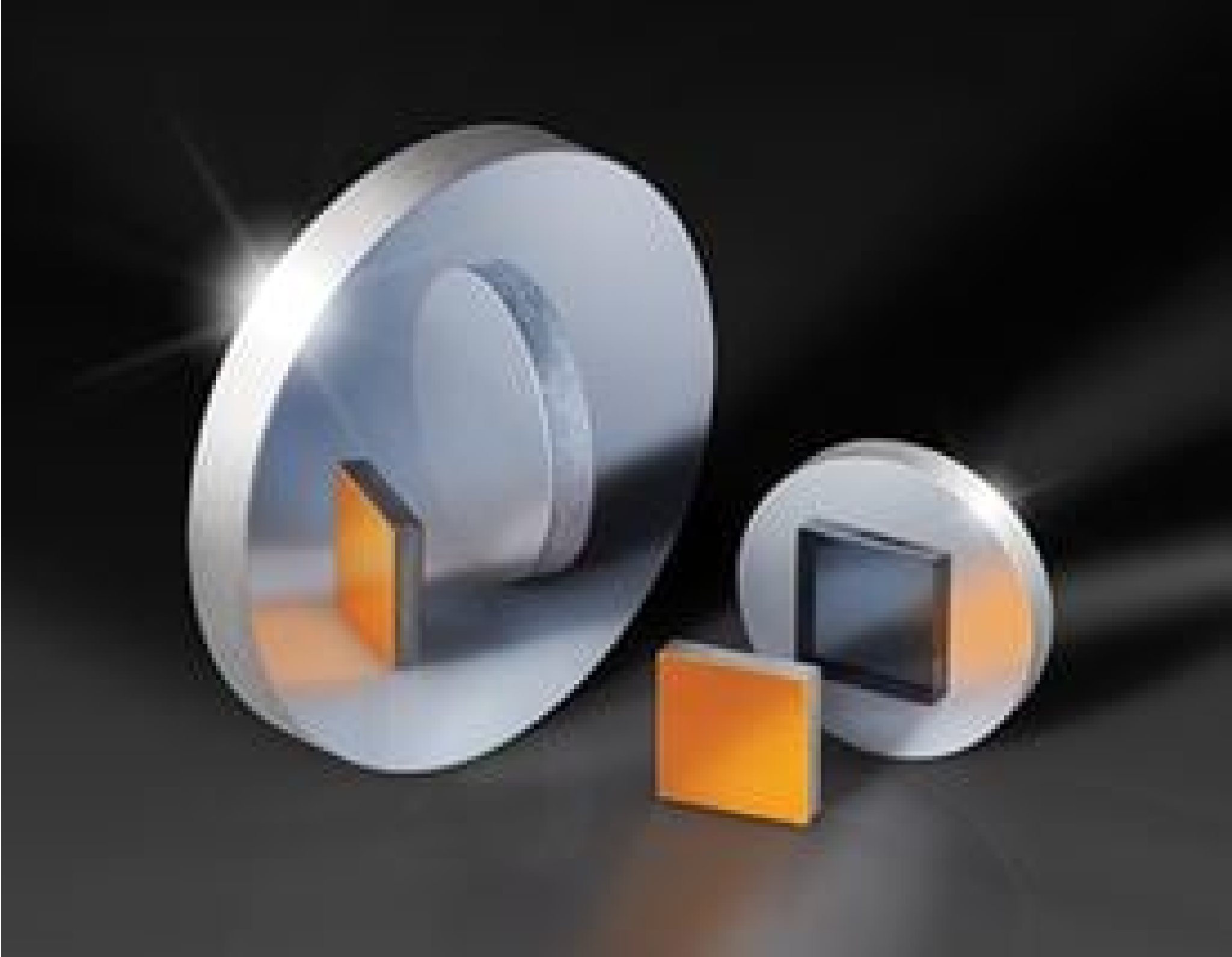

Stock #34-394 ☐ In Stock

-

1

+

£176.80

ADD TO CART

Qty 1-5

£176.80

Qty 6+

£141.10

Volume Pricing

[Request Quote](#)

!

 Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):

30.00 +0.00/-0.20

Surface Flatness (P-V):

λ/20 (flatness pre-coating)

Substrate: ☐

[Fused Silica](#) (Corning 7980)

Back Surface: Commercial Polish
Surface Quality: 20-10
Coating Specification: R _{avg} >98% @450 - 2000nm R _{avg} >98% @2000 - 10,000nm
Coating: Protected Silver (450-10000nm)
Coating Type: Metal
Clear Aperture (%): 90.00
Edges: Ground, protective bevel as needed
Parallelism (arcsec): 30.00
Thickness (mm): 5.00 ±0.20
Type: Flat Mirror
Wavelength Range (nm): 450 - 10000

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant