


TECHSPEC® 30mm Enhanced Aluminum Coated, N-BK7 Right Angle Mirror

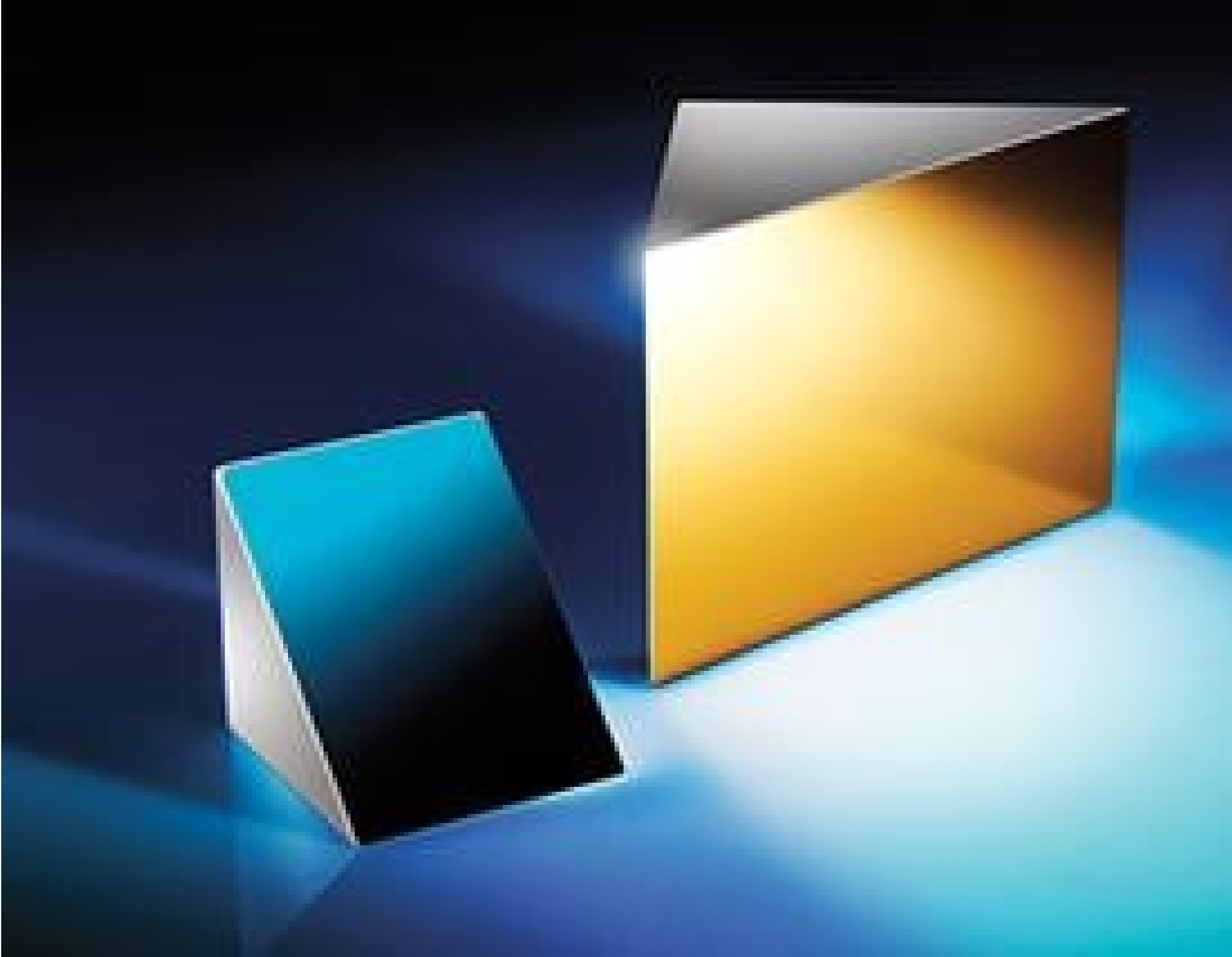

Stock **#45-687** ☐ In Stock

1 **£127.50**

ADD TO CART

Qty 1-5
£127.50

Qty 6+
£102.00

Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Flatness (P-V):
λ/4

Substrate:
[N-BK7](#)

Surface Quality:
40-20

Length of Legs (mm): 30.00
Dimensional Tolerance (mm): ±0.1
Coating Specification: R_{avg} >95% @ 450 - 650nm
Coating: Enhanced Aluminum (450-650nm)
Coating Type: Metal
Angle Tolerance (arcmin): ±2
Bevel: Protective bevel as needed
Clear Aperture CA (mm): 38.19 x 27.00
Length of Hypotenuse (mm): 42.40
Type: Right Angle Mirror
Wavelength Range (µm): 0.45 - 0.65
Wavelength Range (nm): 450 - 650
Damage Threshold, Reference: 0.2 J/cm² @ 532nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant