

34mm Diameter, UV Cut-Off Filter



Stock #54-049 CLEARANCE **5 In Stock**

⊖ 1 ⊕ £11⁹⁶

ADD TO CART

Volume Pricing

Qty 1+	£11.96 each
Need More?	Request Quote

! Prices shown are exclusive of VAT/local taxes

Product Downloads

General

UV Cut-Off Filter **Type:**

Physical & Mechanical Properties

34.00 +0.0/-0.2 **Diameter (mm):**

2.00 ±0.2 **Thickness (mm):**


Optical Properties

390.00	Cut-On Wavelength (nm):
L-39	Glass/Filter Number:
Hoya L-39	Substrate: <input type="checkbox"/>
AR Coating	Coating:
Clear, Green Tint	Color:
80-50	Surface Quality:
>80 (avg)	Transmission (%):
350 - 2200	Wavelength Range (nm):
4 - 6λ	Surface Flatness (P-V):
Environmental & Durability Factors	
-15 to 70	Operating Temperature (°C):
Regulatory Compliance	
View	Certificate of Conformance:

Product Details

- Ideal for UV Applications
- For use with Longpass and Bandpass Filters
- Various Sizes Available

Technical Information

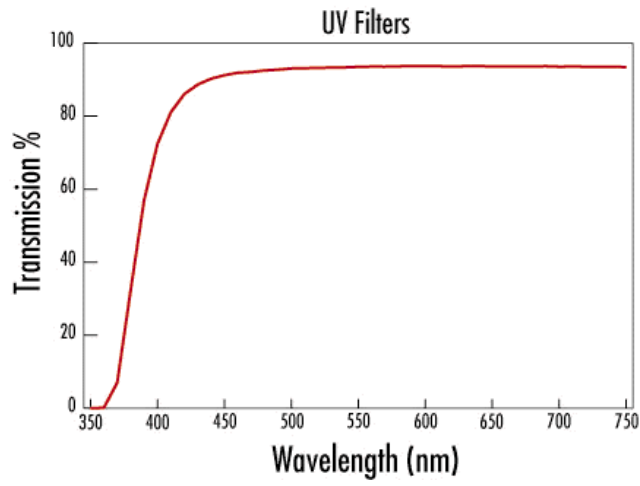

Compatible Mounts