

34mm Diameter, UV Cut-Off Filter



Stock **#54-049** CLEARANCE **5 In Stock**

-

1

+

£11^{.96}

ADD TO CART

Volume Pricing	
Qty 1+	£11.96 each
Need More?	Request Quote

i Prices shown are exclusive of VAT/local taxes

Product Downloads

General	
UV Cut-Off Filter	Type:
Physical & Mechanical Properties	
34.00 +0.0/-0.2	Diameter (mm):
2.00 ±0.2	Thickness (mm):
Optical Properties	

390.00	Cut-On Wavelength (nm):
L-39	Glass/Filter Number:

Hoya L-39	Substrate: ☐
AR Coating	Coating:

Clear, Green Tint	Color:
80-50	Surface Quality:

>80 (avg)	Transmission (%):
350 - 2200	Wavelength Range (nm):

4 - 6λ	Surface Flatness (P-V):
--------	-------------------------

Environmental & Durability Factors

-15 to 70	Operating Temperature (°C):
-----------	-----------------------------


Regulatory Compliance

View	Certificate of Conformance:
----------------------	-----------------------------

Product Details

- Ideal for UV Applications
- For use with Longpass and Bandpass Filters
- Various Sizes Available

Technical Information

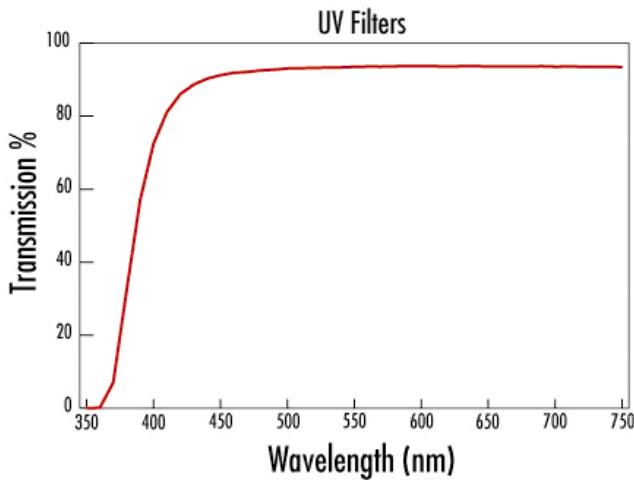

Compatible Mounts