

[See all 31 Products in Family](#)

12-pin Hirose I/O Cable, 3m (for Manta, Prosilica GT/GC, Guppy Pro and Stingray Series)

See More by [Allied Vision](#)



#63-757



Stock #63-757 [CONTACT US](#)

⊖ 1 ⊕ £44⁰⁰

ADD TO CART

| Volume Pricing | |
|----------------|-------------------------------|
| Qty 1+ | £44.00 each |
| Need More? | Request Quote |

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Camera Accessory **Type:**

Regulatory Compliance

RoHS 2015:
[Compliant](#)

Product Details

- Rugged PoE (Power Over Ethernet) Cameras for Extreme Environments
- Precise (P-Iris) and DC Auto Iris Control
- Up to 31.4 MegaPixel Resolution
- C-Mount, F-Mount, and TFL-Mount Options

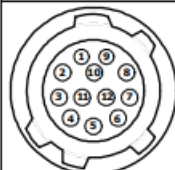
Allied Vision Prosilica GT Series GigE Cameras are designed for the harshest environments and fluctuating light conditions. Capable of operating in extreme temperatures ranging from -20° to 60°C, Allied Vision Prosilica GT Series GigE Cameras are ideal for ITS and traffic imaging, machine vision, industrial inspection, security, or surveillance applications. Allied Vision Prosilica GT Series GigE Cameras feature both P-Iris and DC auto iris control for maintaining image quality, and support power over Ethernet for easy implementation.

Note: PoE Injector (#68-469) or power supply and GigE cable, such as #63-431, are required for operation.

Technical Information

12-pin I/O connector

Bonito PRO, Goldeye and Goldeye Pro, Manta, and Prosilica GT

| Type HR10A-10P-12S | Pin | Color | Pin | Color |
|--|-----|--------|-----|-------------|
|  | 1 | Blue | 7 | Brown |
| | 2 | Red | 8 | White |
| | 3 | Violet | 9 | Black |
| | 4 | Gray | 10 | Orange |
| | 5 | Yellow | 11 | White/Black |
| | 6 | Green | 12 | White/Brown |