


3" Diameter, Optical Cast Plastic IR Longpass Filter

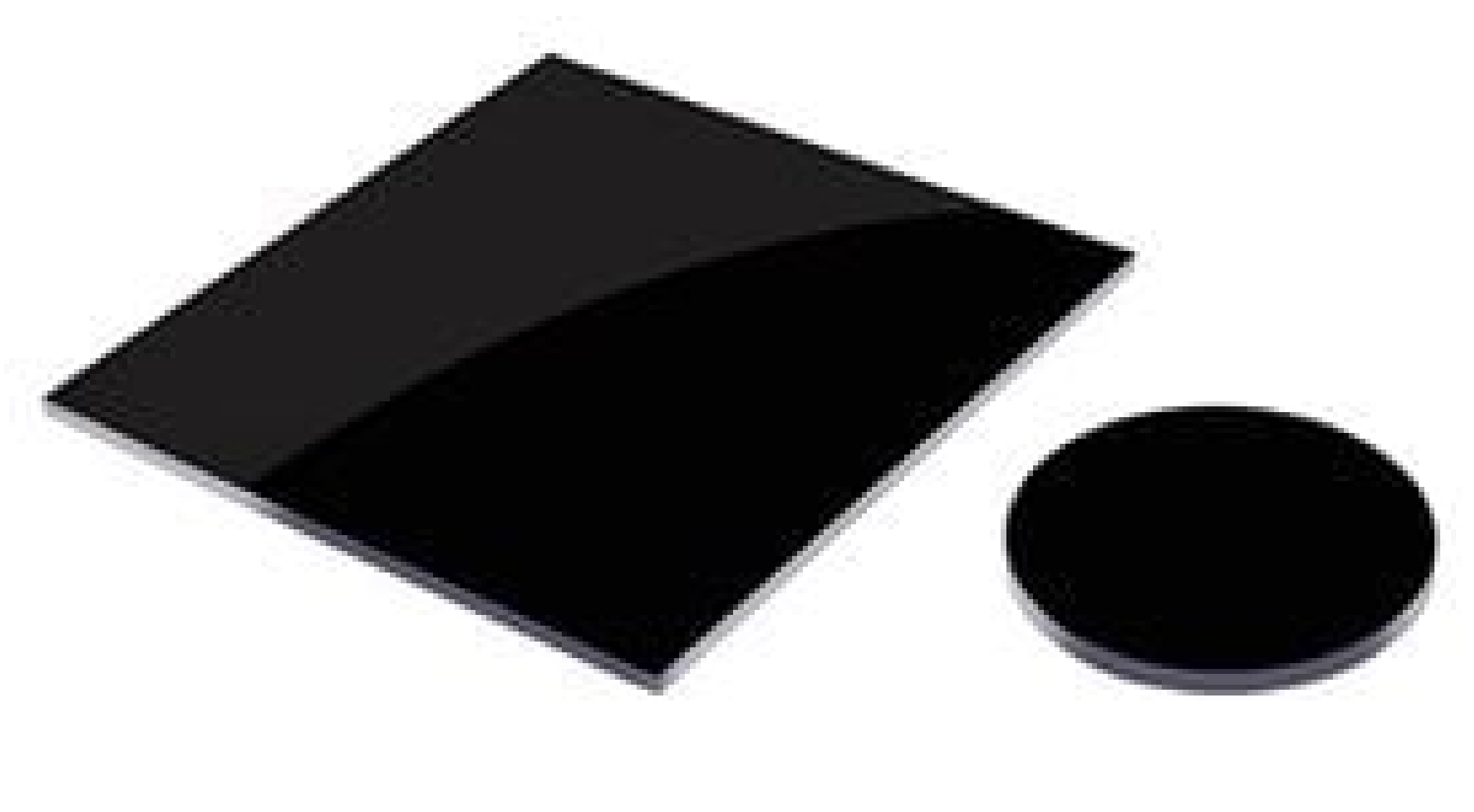

Stock **#43-950** 3-4 DAYS

- 1 + **£27.20**

ADD TO CART

Qty 1-49
£27.20
Qty 50+
£23.80
Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
76.20

Density (g/cm³):
1.320 at 20°C

Diameter (inches):
3.00

Substrate: ☐

Thermoset ADC (CR-39®)
Operating Temperature (°C): 100 Continuous, 130 One Hour Max
Coating: Uncoated
Color: Black
Index of Refraction n_d: 1.501 @ 20°C
Thickness (mm): 1.50 Nominal
Transmission (%): >90 (typical)
Type: Longpass Filter
Dimensional Tolerance (mm): ±0.3
Abbe Number (v_d): 57.00

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View